


Stellantrieb für Hahnen
Actuator for slipper valves
Servomoteur pour vannes à secteur
Ställdon för vridslidventiler
Servomotor voor kranen


Servocomando per valvole a settore
Venttiilien toimimoottori
Servoactuador de válvulas de sector
Forstillingsorgan sleidehaner
Motor for haner

SQK39.00V
VB.../VC...
DN20...50 (S 02)


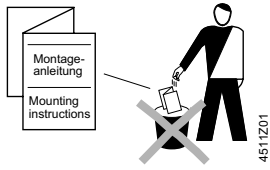





- de** Montageanleitung
- en** Mounting instructions
- fr** Instructions de montage
- sv** Monteringsinstruktion
- nl** Montage-aanwijzing

- it** Istruzioni di montaggio
- fi** Asennusohje
- es** Instrucciones de montaje
- no** Monteringsveiledning
- da** Monteringsvejledning

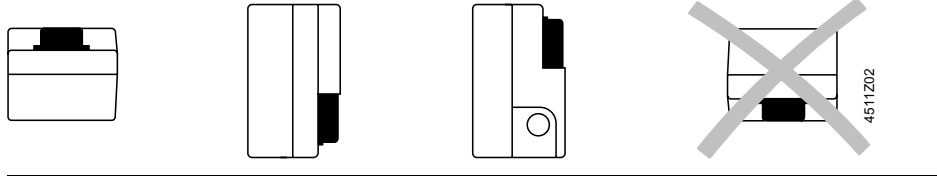

AC 230 V ± 15%
50 Hz / 60 Hz
IP42 IEC 529 / DIN 40 050
II IEC 730 / VDE 0631
-15°... +50°C

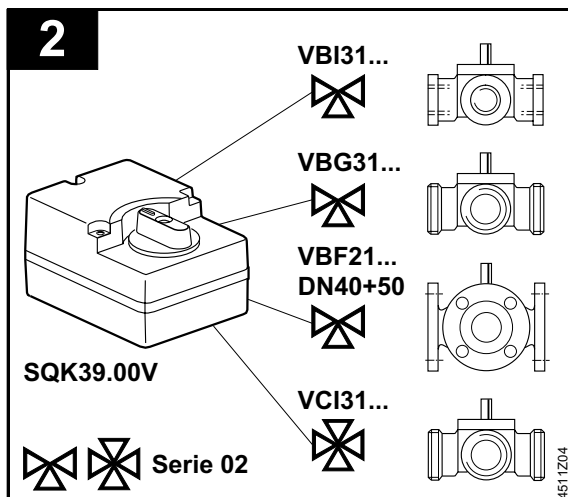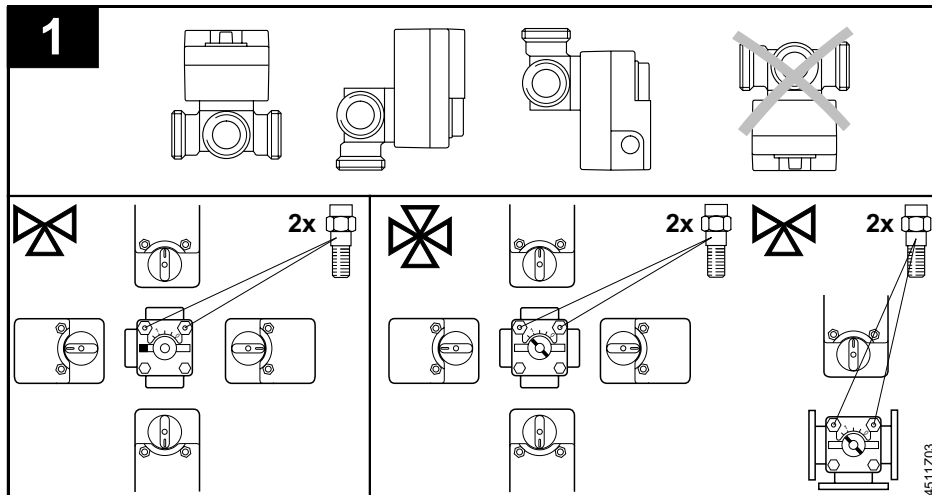

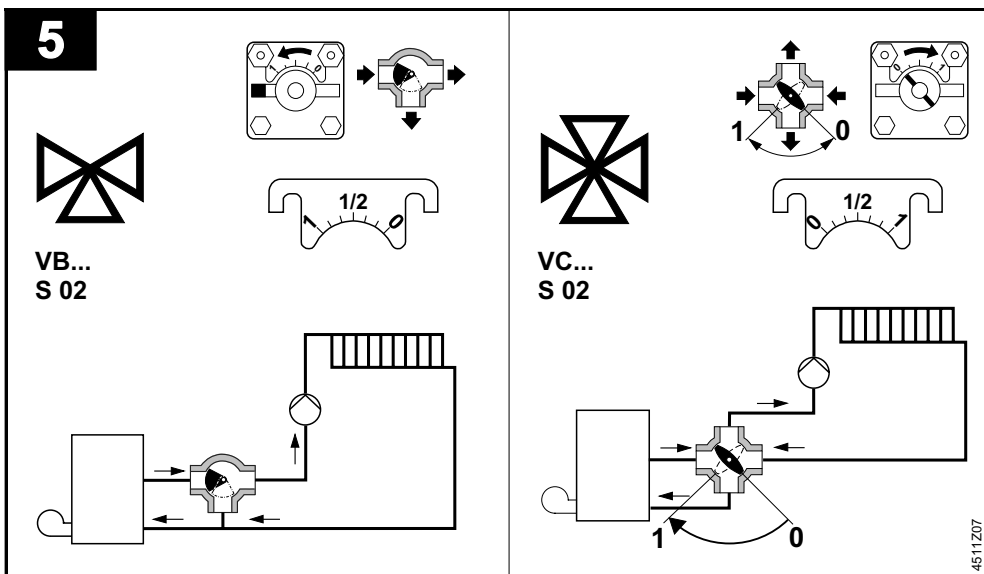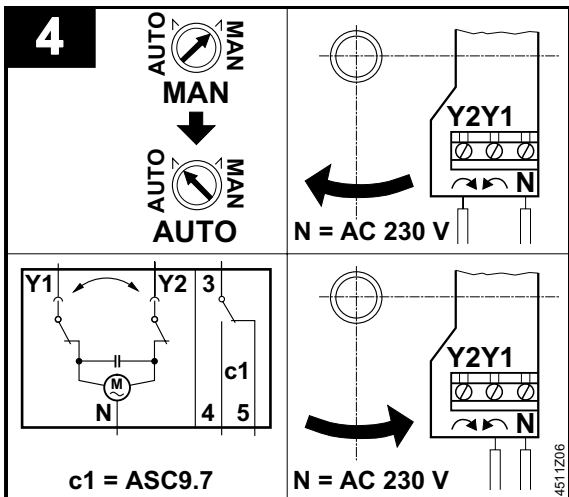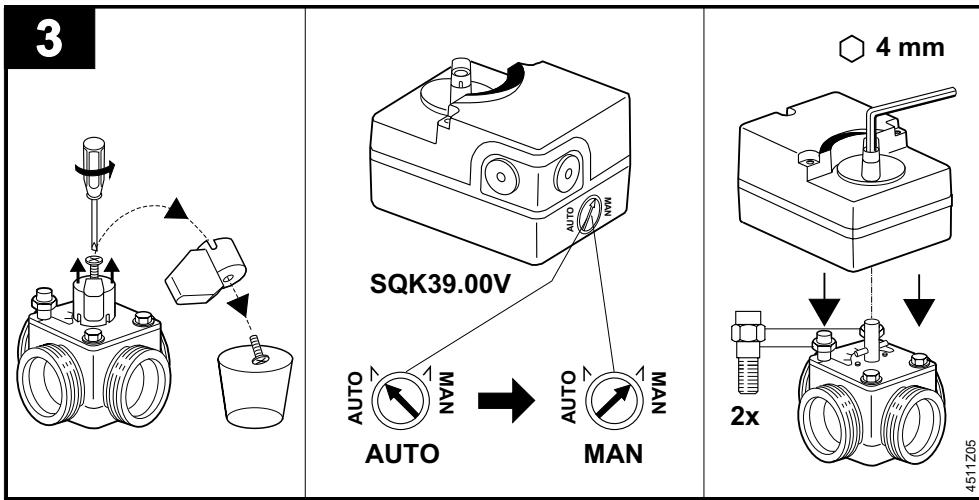

Nur für Verpackung!
Only for packing up!

