


de Montageanleitung
en Mounting instructions
fr Instructions de montage
sv Monteringsinstruktion
nl Montage-handleiding
it Istruzioni di montaggio
fi Asennusohje
es Instrucciones de montaje
da Monteringsvejledning
pl Instrukcja montażu
cz Montážní návod
hu Szerelési útmutató
ru Инструкция по установке
el Οδηγίες εγκατάστασης
zh 安裝指導



Stellantriebe für Hähne
Actuators for slipper valves
Servomoteurs vanne à secteur
Ställdon för vridslidventiler
Sevomotoren voor kranen
Servomandi per valvola a ettore
Venttiilin toimimootorit
Forstillingsorganer sleidehaner
Motorer for haner
Siłowniki do zaworów obrotowych
Pohony pro kohouty
Állítómotorok csapokhoz
Приводы для поворотных клапанов
Κινητήρες για περιστροφικές βάνες
滑阀执行器












SQK34.00S
SQK84.00S
 (+ ESBE)




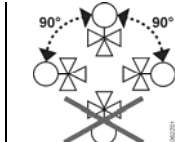


1	Q	DN15..25		DN20..50		DN15..25		DN20..50						
		3MG15 3MG25 3MG28 3MG20 3MG22	G119 G125 G132 G138 G151	4 173 5505 0	4511Z35	20	4 173 5502 0	00116	8	4 173 5505 0	4511Z35	20	4 173 5502 0	00116
SQK34..S	+					+			+			+		
							FRONT							

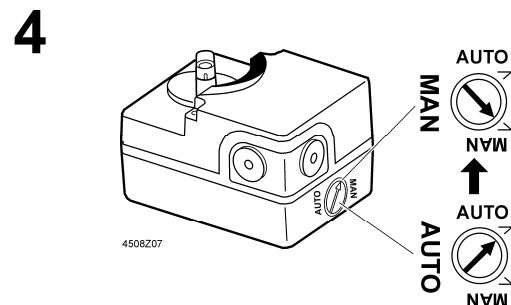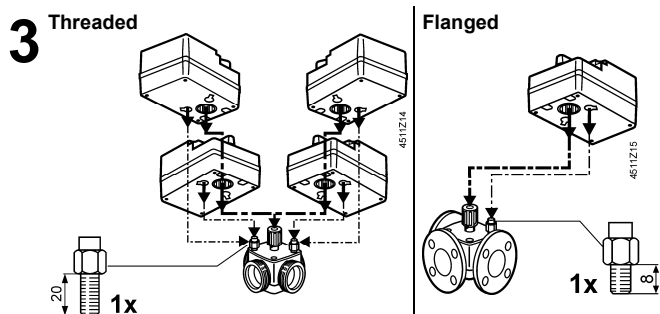


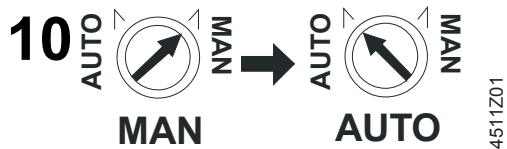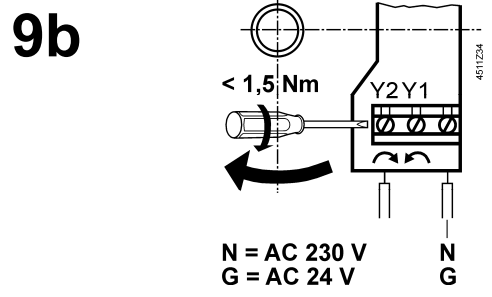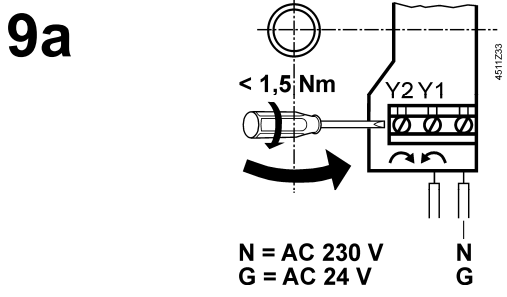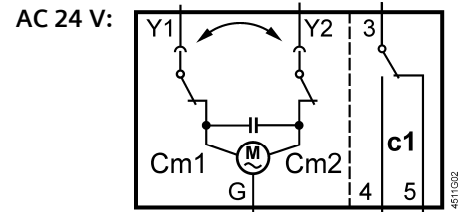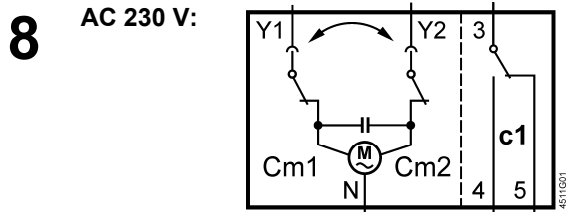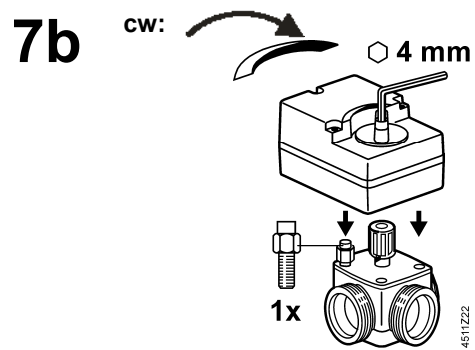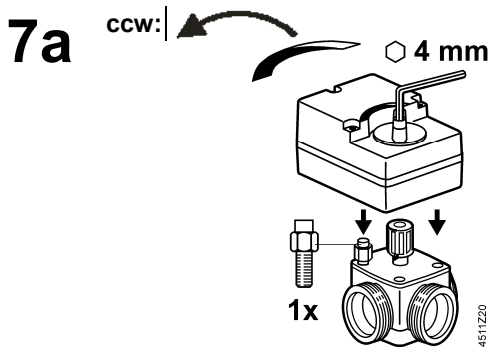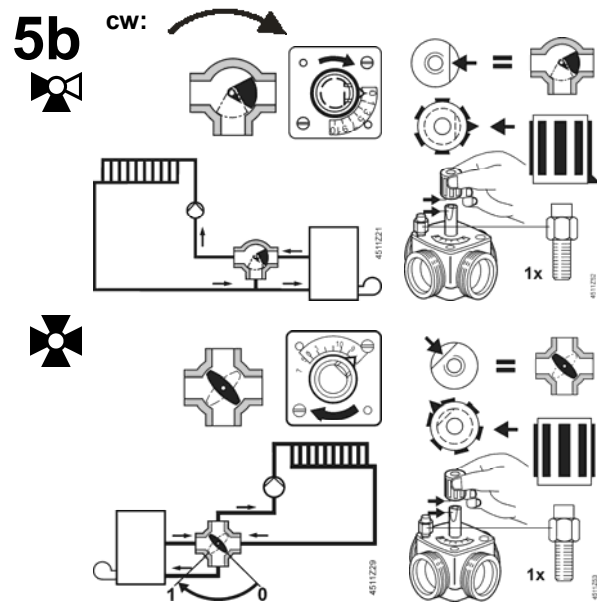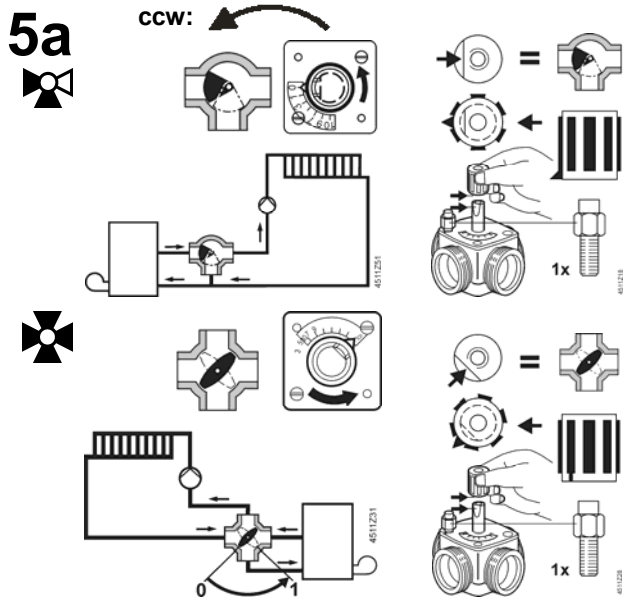


1													
	SQK34..S	+	VRG131 VRG132 VRG133	+	VRG141 VRG142 VRG143	+		+		+	2 x	+	

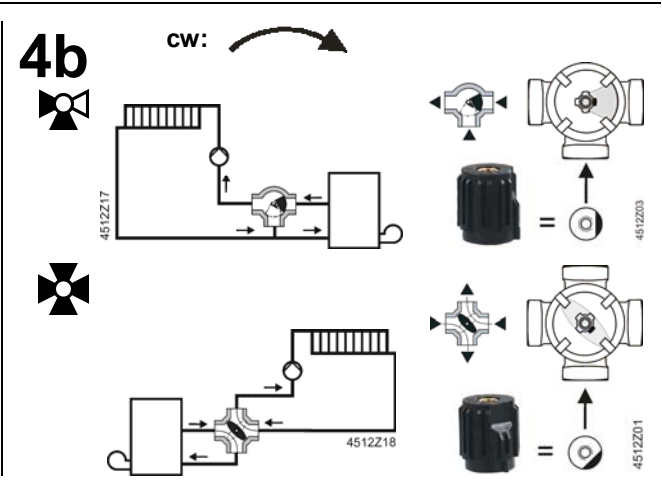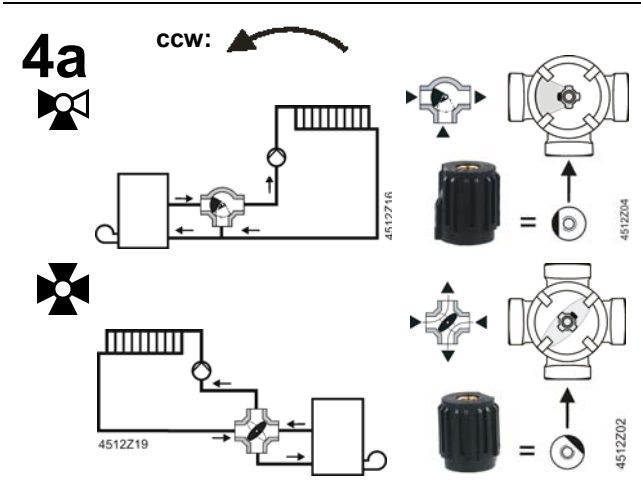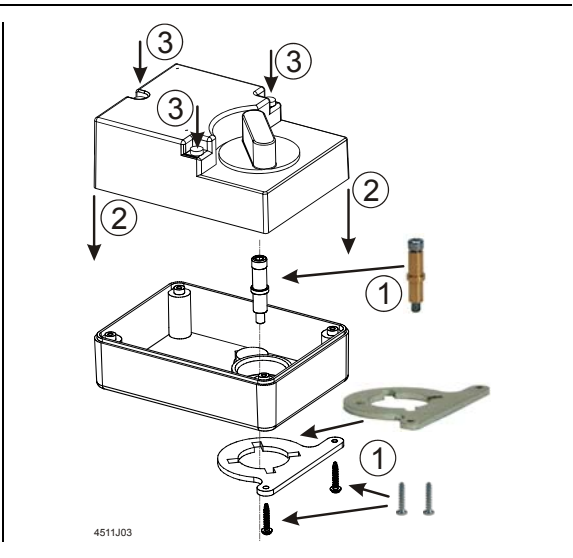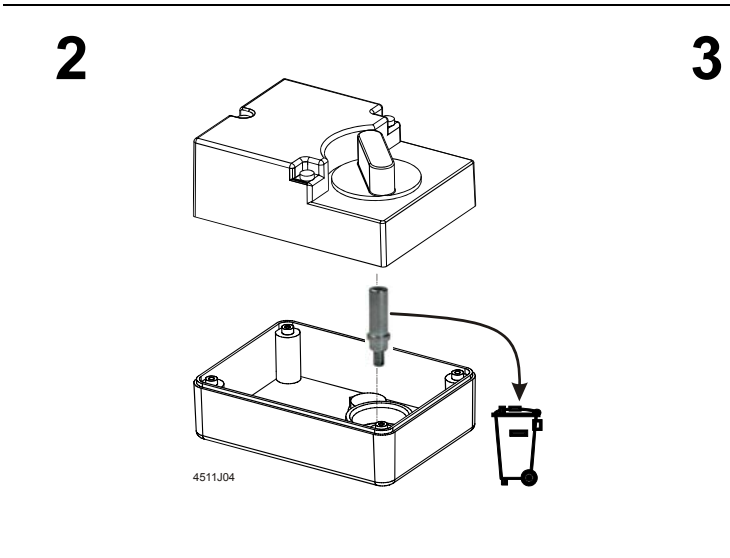


4 AC 230 V:

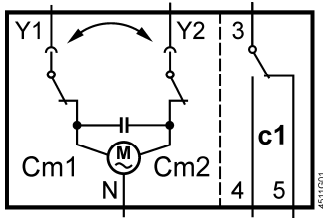



AC 24 V:

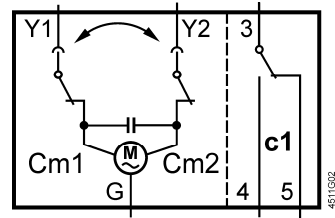

5a

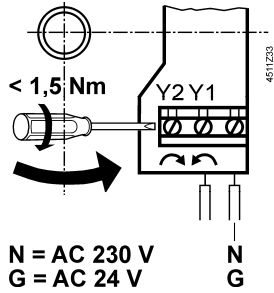

5b

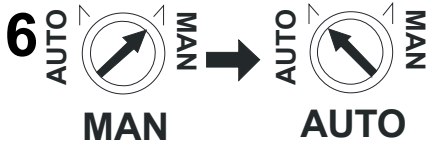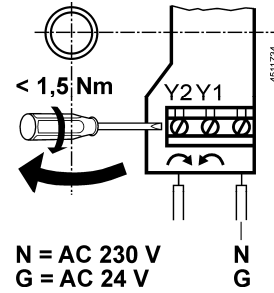

4511Z01