
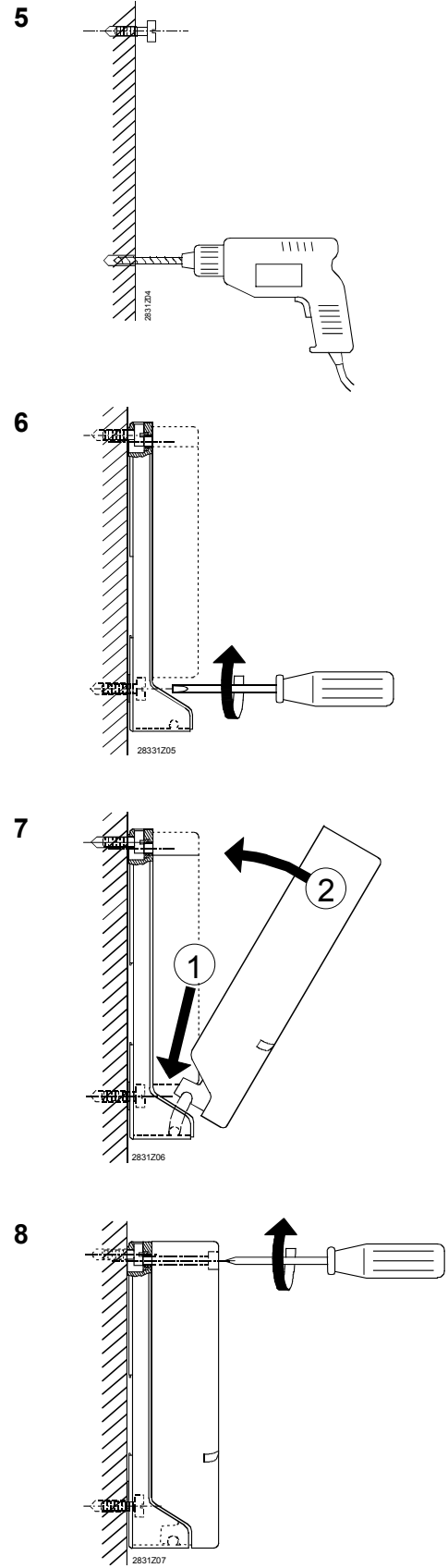



**Montageanleitung**  
**Mounting instructions**  
**Instruction de montage**  
**Istruzione di montaggio**

**AEK84**  
**ALW30**  
**QAB30**


**AEW2.1**  
**ALW84**  
**WRI80**

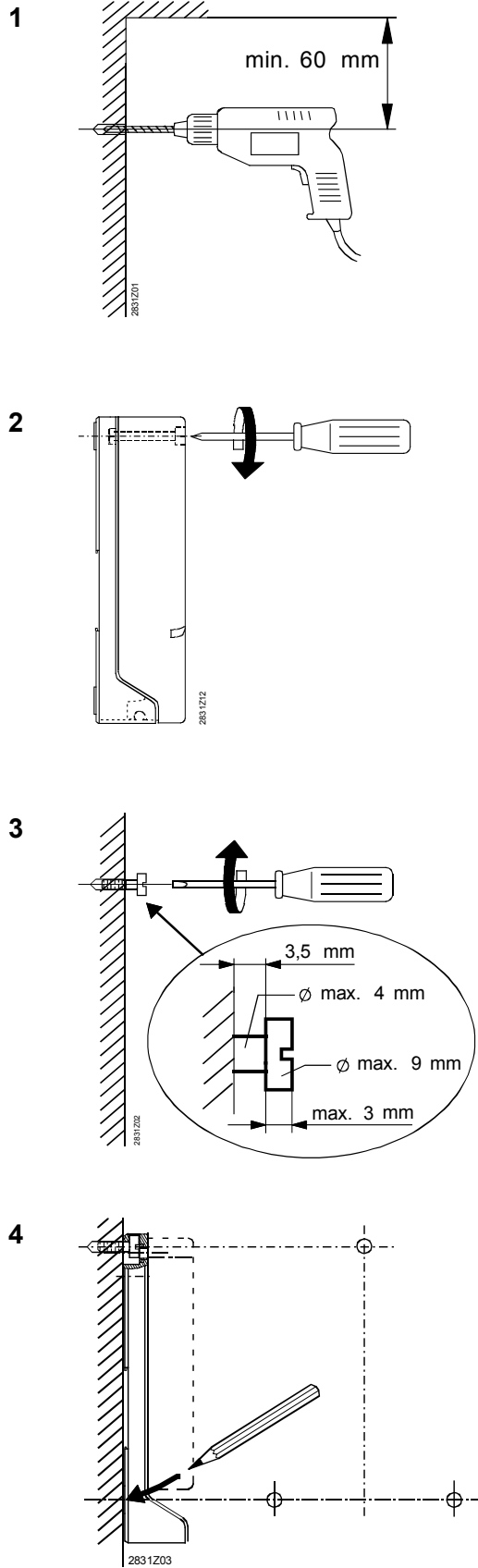


DIN-Schiene: Montage  
 DIN rail: mounting  
 Rail DIN: Montage  
 Profilati DIN: montaggio

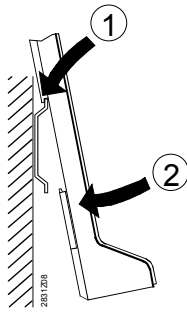

DIN-Schiene: Demontage  
 DIN rail: removal  
 Rail DIN: démontage  
 Profilati DIN: smontaggio


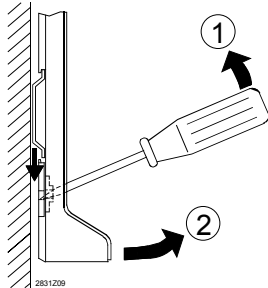


## QAB30

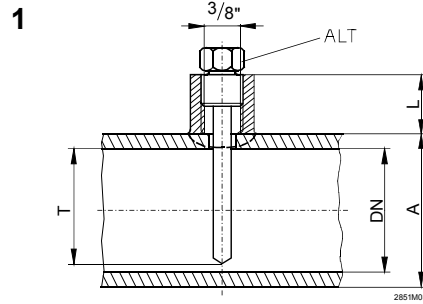


DN	A [Ø mm]	T [mm]	L [mm]	Type
3/4"	26,9	22,4	<b>20</b>	ALT35
1"	33,8	25,8	<b>16</b>	ALT35
DN32	42,4	30,4	<b>12</b>	ALT35
DN40	48,3	30,4	<b>12</b>	ALT35
DN50	60,3	53,1	<b>20</b>	ALT65
DN65	76,1	53,1	<b>20</b>	ALT65
DN80	88,9	52,8	<b>20</b>	ALT65

## ALW30 ALW84

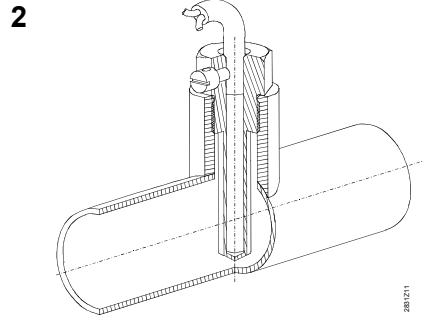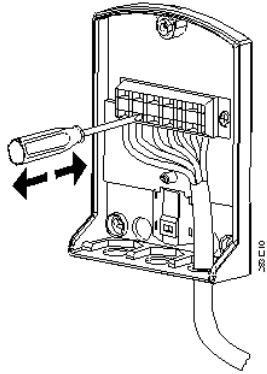

	Kabel- farben	Cable colors	Couleur des fils	Colori di cavo
G1	weiss	white	blanc	bianco
G2	braun	brown	brun	bruno
MB	blau	blue	bleu	blu
DB	rosa	pink	rose	rosa
D1	grau	grey	gris	grigio
MD	grün	green	vert	verde
P1	gelb	yellow	jaune	giallo
R1	rot	red	rouge	rosso

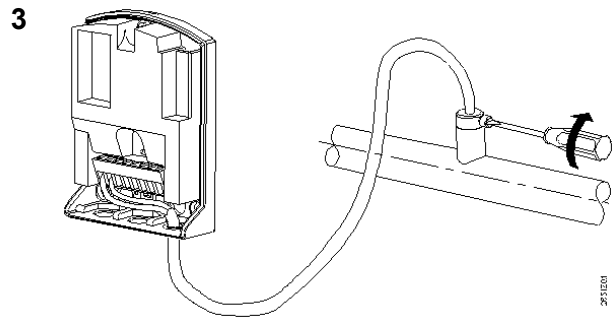

## Massbild Dimensions Encombrement Ingombro

