


- de** Montageanleitung
- en** Mounting instructions
- fr** Instructions de montage
- sv** Monteringsinstruktion
- nl** Montage-aanwijzing
- it** Istruzioni di montaggio
- fi** Asennusohje
- es** Instrucciones de montaje
- da** Monteringsvejledning


## QPM11... QPM21...

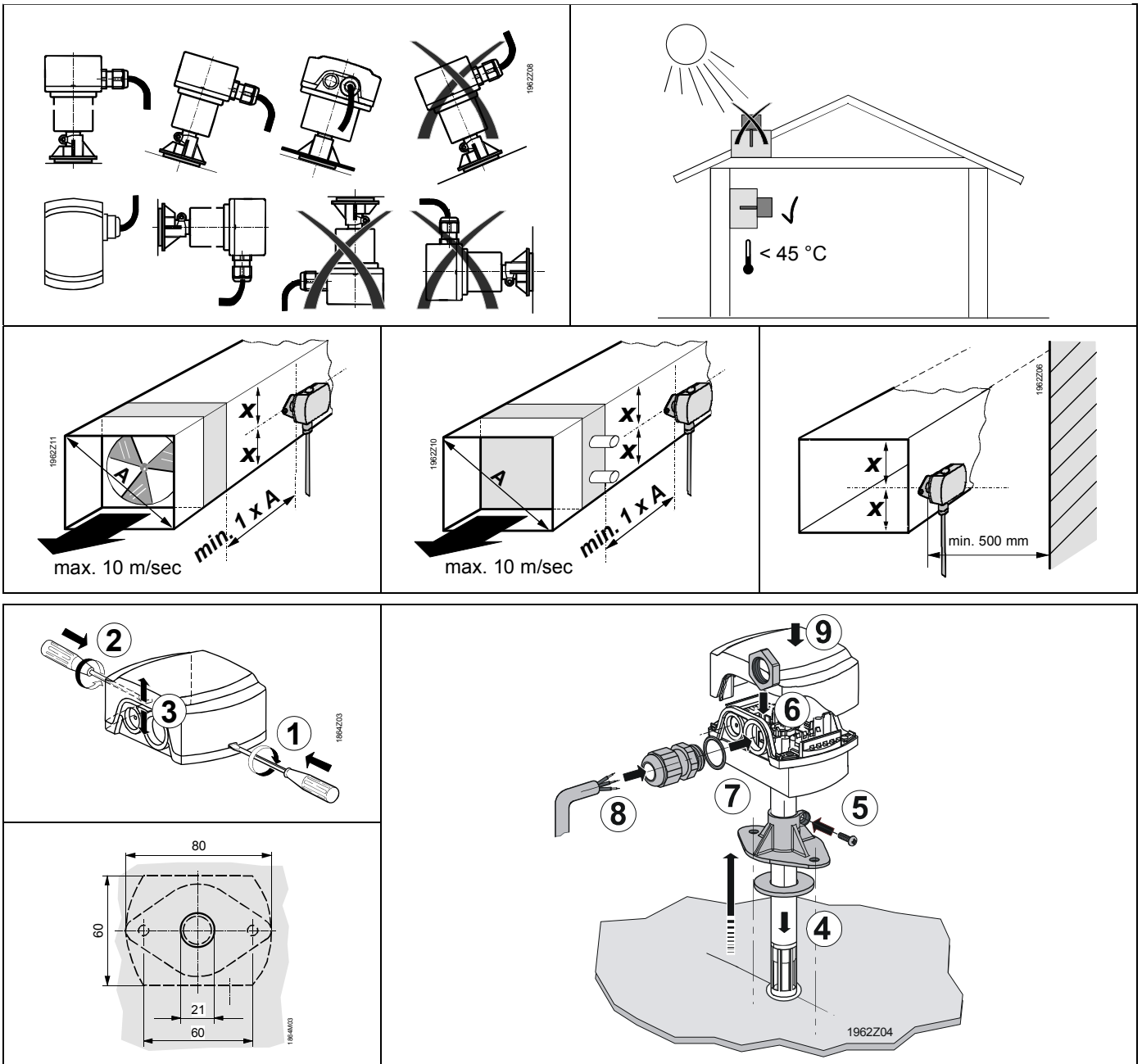


<b>G</b>	AC 24 V $\pm 20\%$ / DC 15...35 V	<b>B</b>	
<b>G0</b>	GND	<b>M</b>	
<b>U...</b>	DC 0...10 V / 0...5	<b>BS</b>	
<b>I...</b>	DC 4...20 mA	<b>MS</b>	
<b>G...</b>	DC 13,5...35 V		
<b>C +</b>	com		
<b>C -</b>	com		

1761208


**QPM1100**

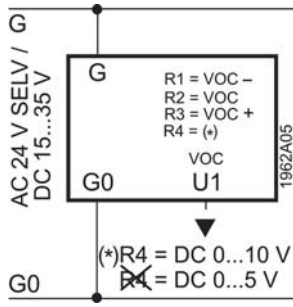


**QPM2100**

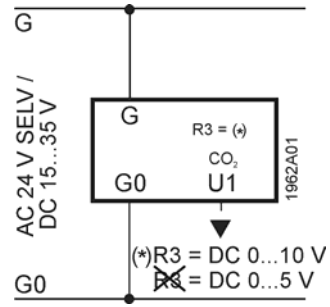


**QPM2102  
QPM2102D**

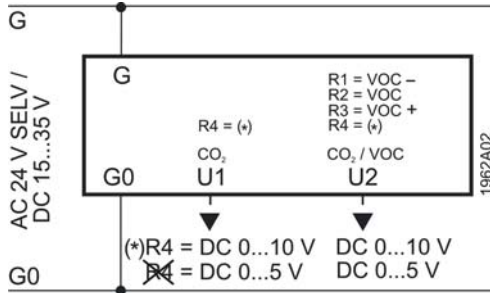




**QPM2160  
QPM2160D**

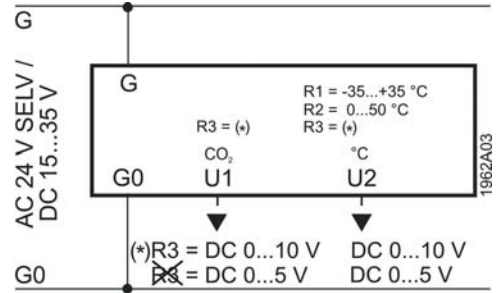

**QPM2162  
QPM2162D**

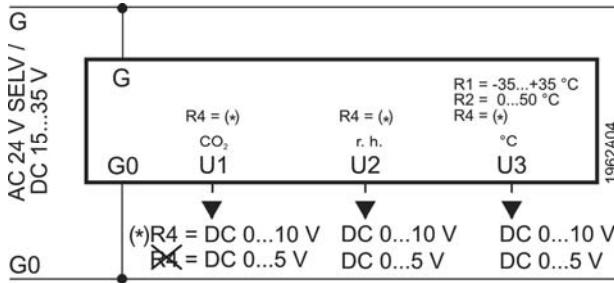


**QPM2180**

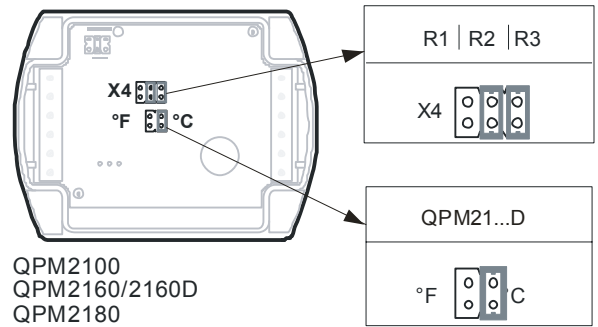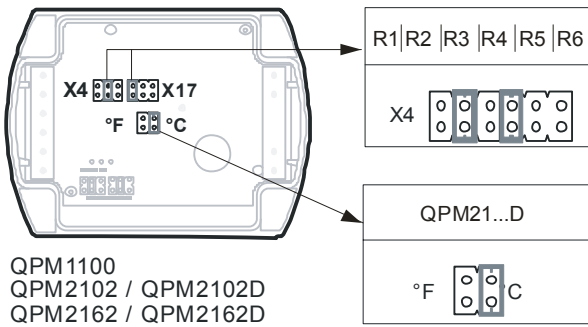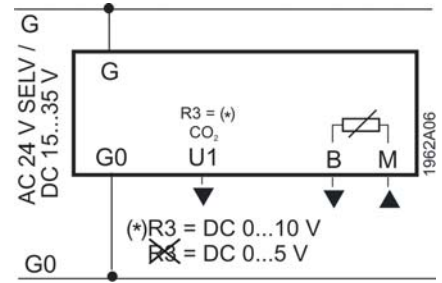

QPM1100  
QPM2102 / QPM2102D  
QPM2162 / QPM2162D

QPM2100  
QPM2160/2160D  
QPM2180

1962Z14

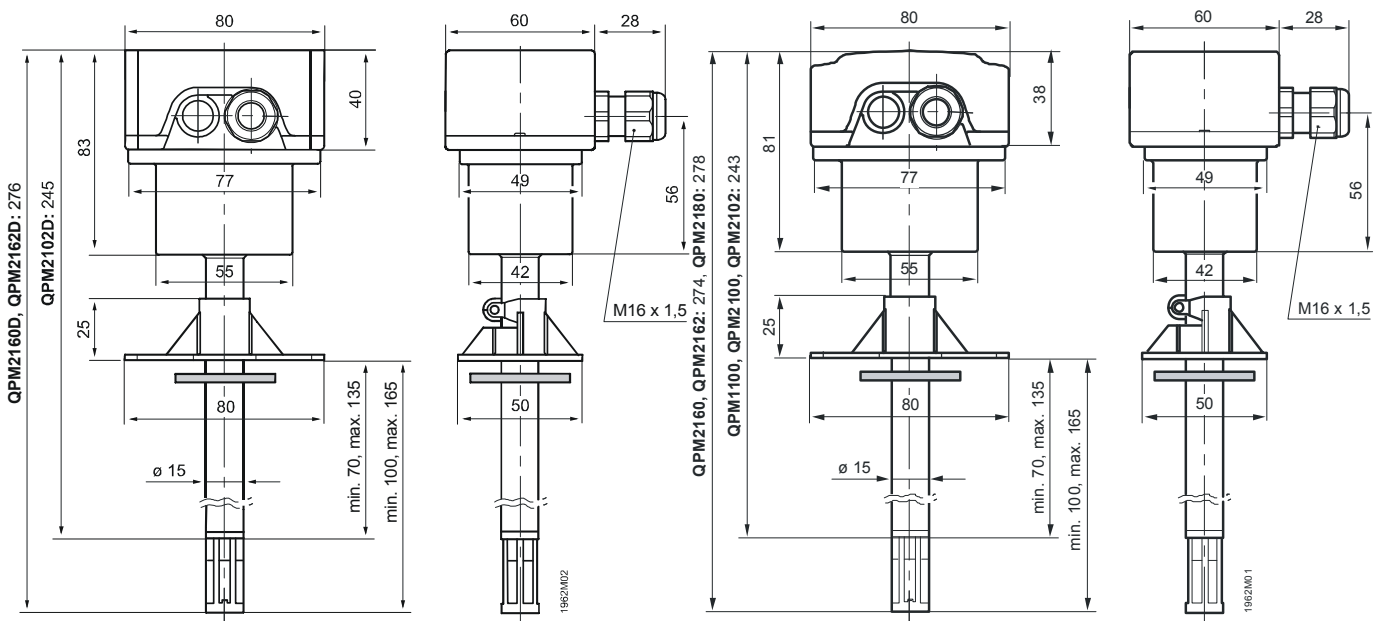

Masse in mm    Dimensions en mm    Mål i mm    Afmetingen in mm    Mitat mm  
Dimensions in mm    Dimensiones en mm    Mått i mm    Dimensioni in mm