


- de** Montageanleitung
- en** Mounting instructions
- fr** Instructions de montage
- sv** Monteringsinstruktion
- nl** Montage-aanwijzing
- it** Istruzioni di montaggio
- fi** Asennusohje
- es** Instrucciones de montaje
- da** Monteringsvejledning


QPM11... QPM21...

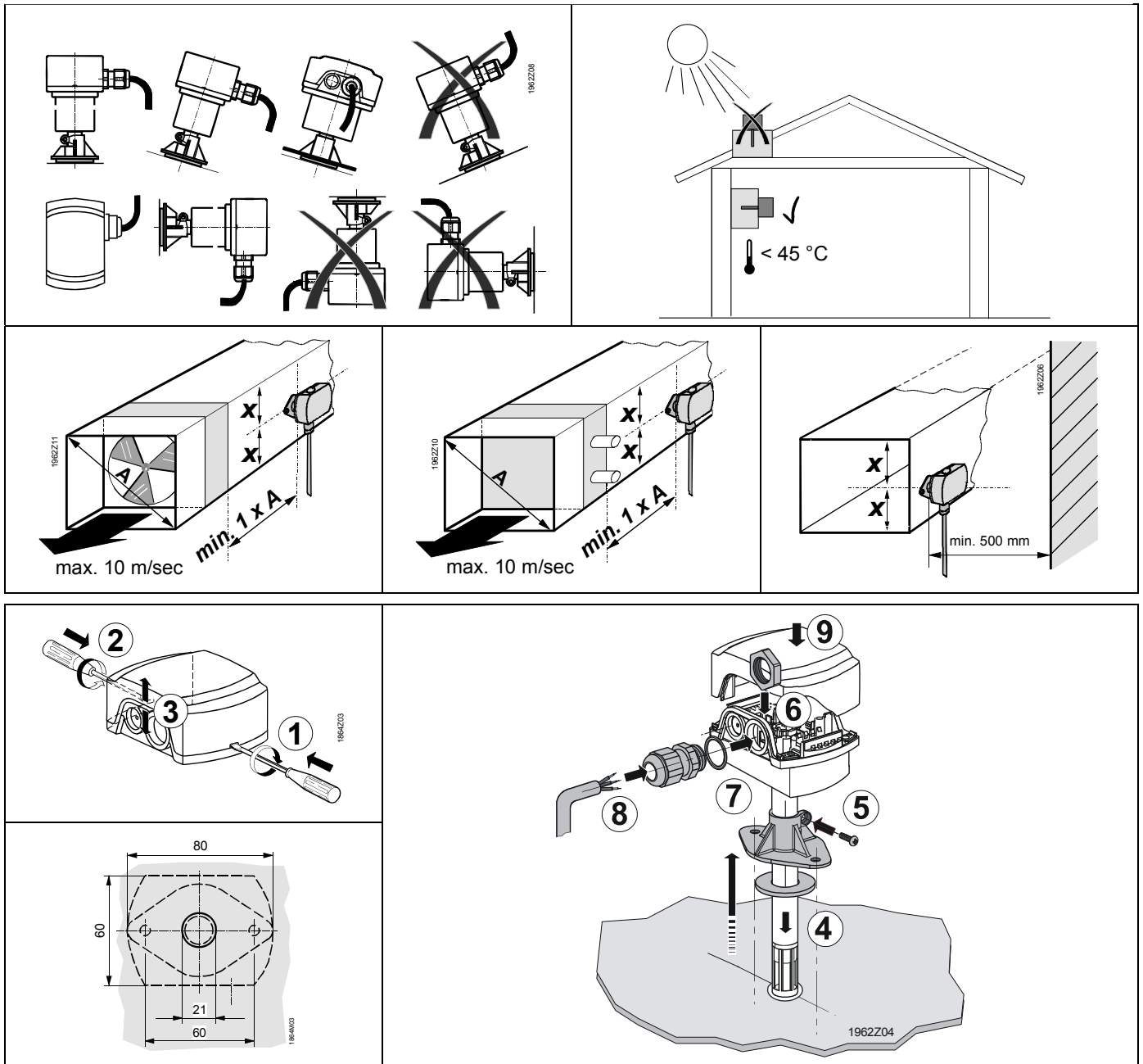


G	AC 24 V \pm 20 % / DC 15...35 V	B	
G0	GND	M	
U...	DC 0...10 V / 0...5	BS	
I...	DC 4...20 mA	MS	
G...	DC 13,5...35 V		
C +	com		
C -	com		

1761208


QPM1100

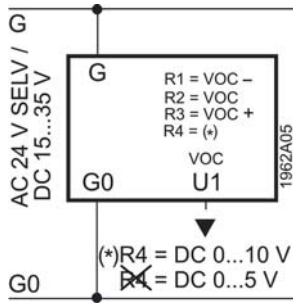


QPM2100

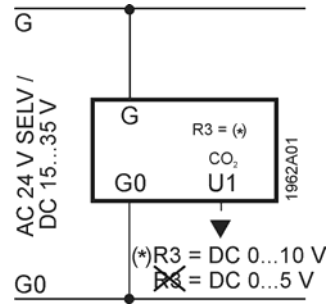


**QPM2102
QPM2102D**

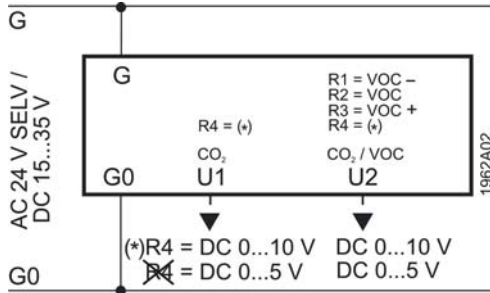








**QPM2160
QPM2160D**

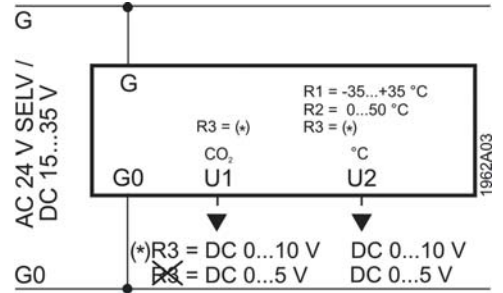

**QPM2162
QPM2162D**

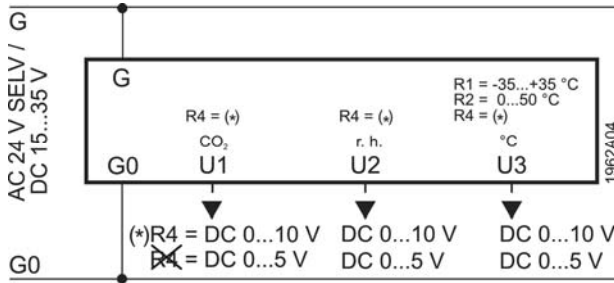

QPM2180

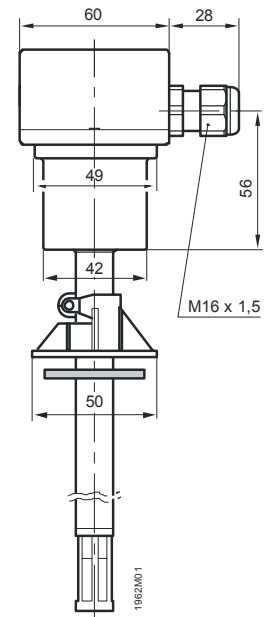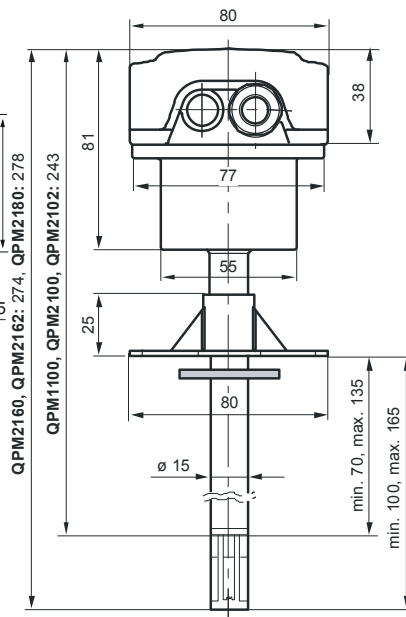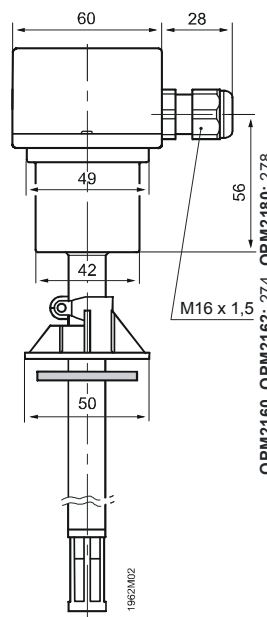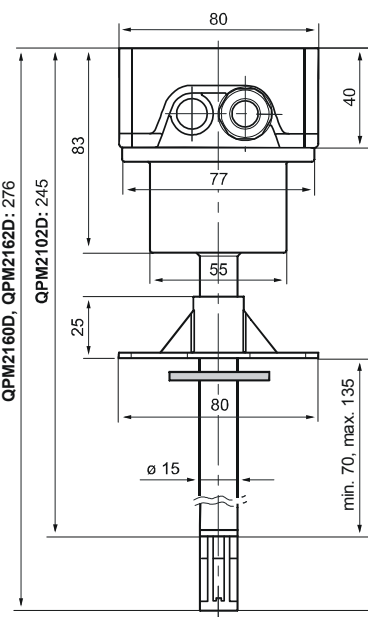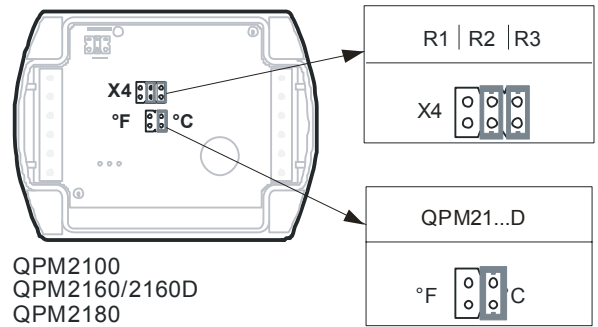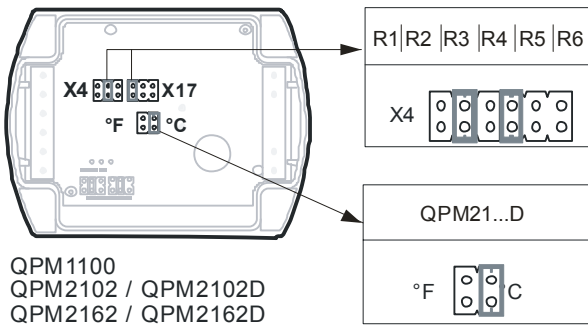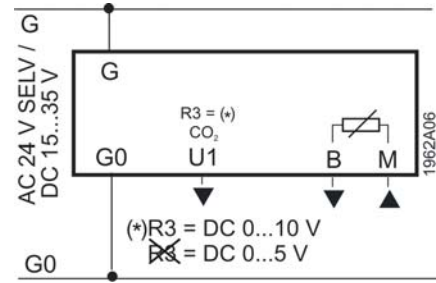

Masse in mm Dimensions en mm Mål i mm Afmetingen in mm Mitat mm
Dimensions in mm Dimensiones en mm Mått i mm Dimensioni in mm