

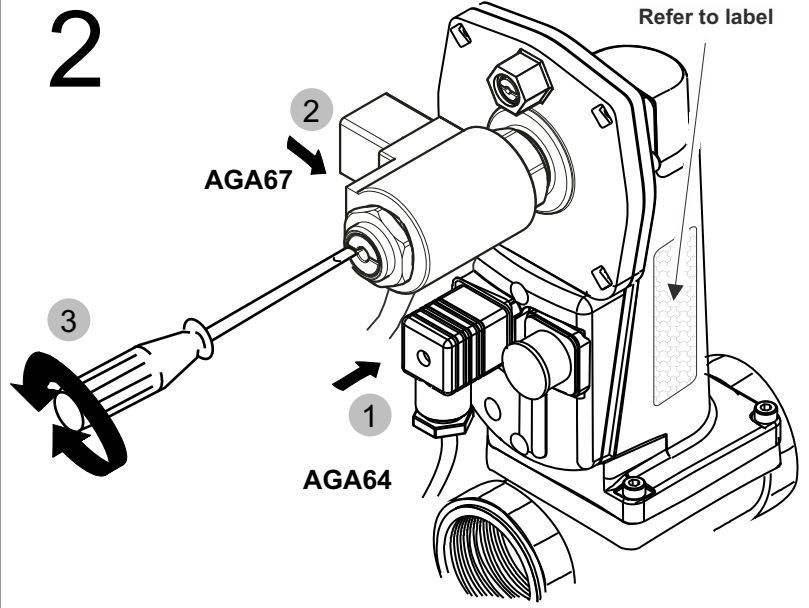



SKP25.2...

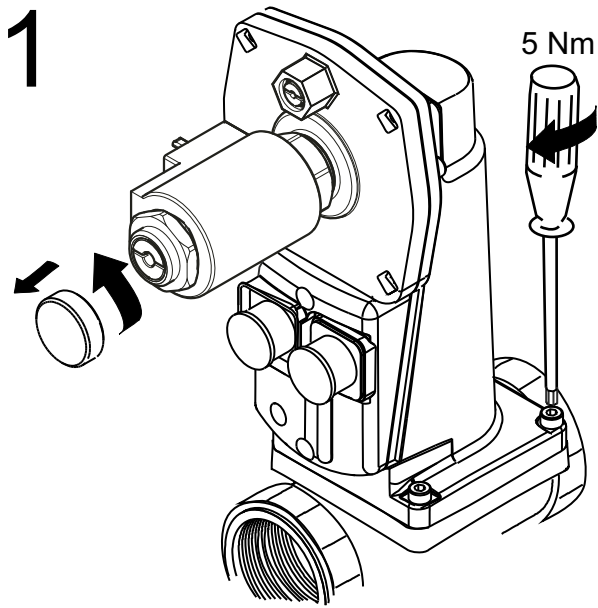

2a Low fire setting



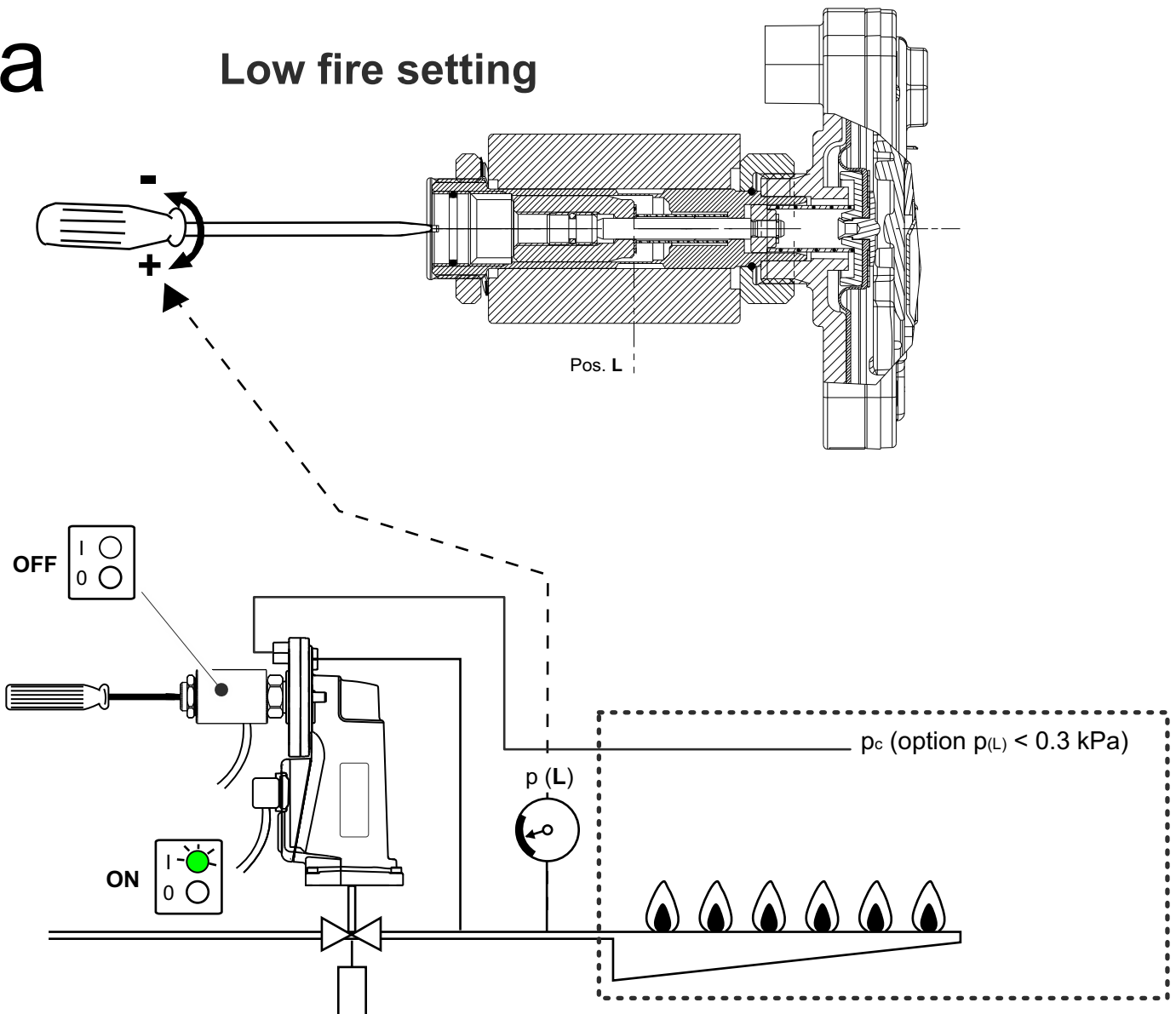


3

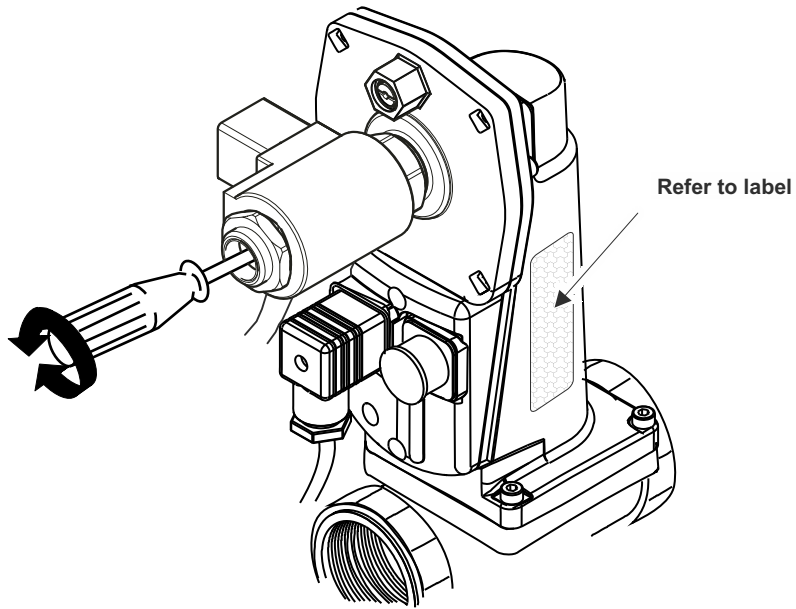


3a

 High fire setting

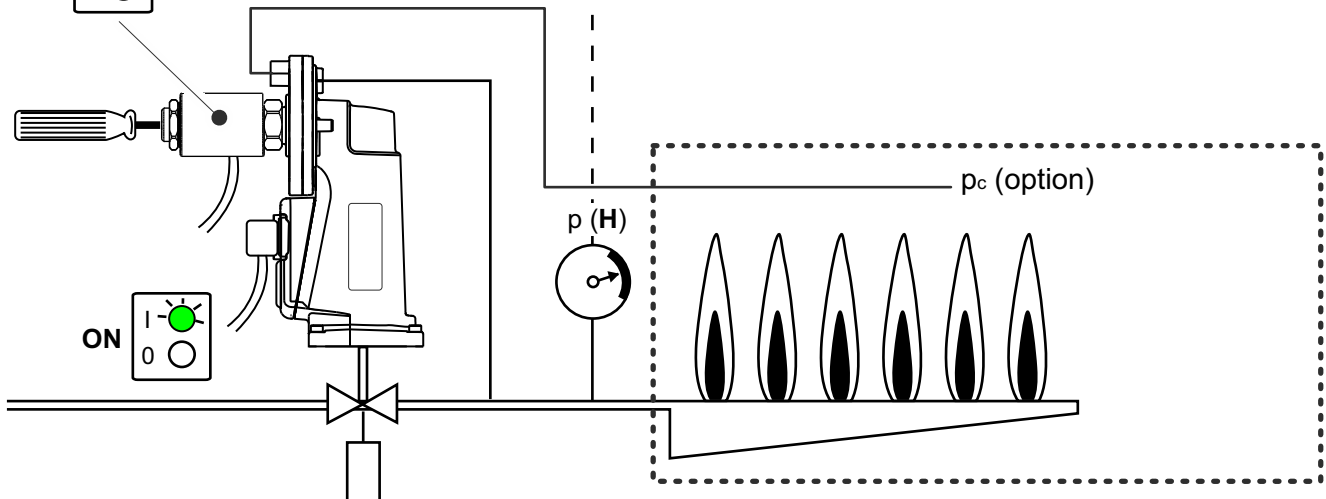
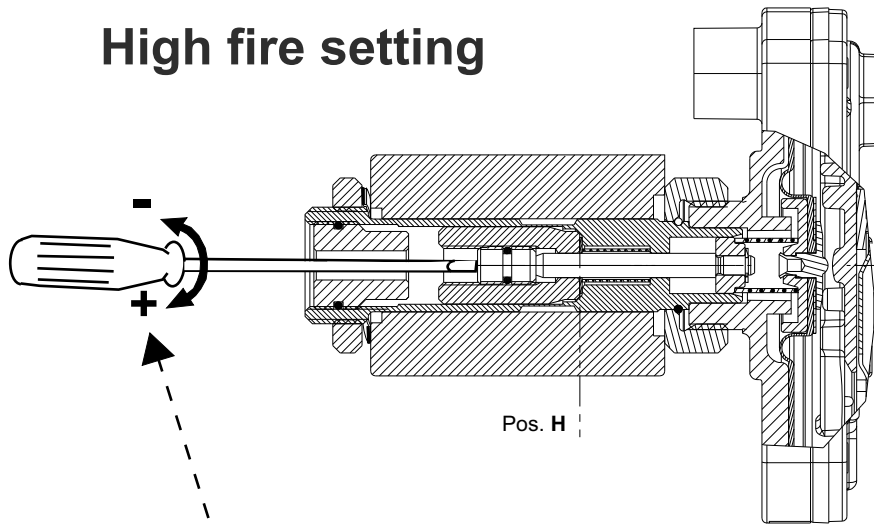


4

2nd low fire setting

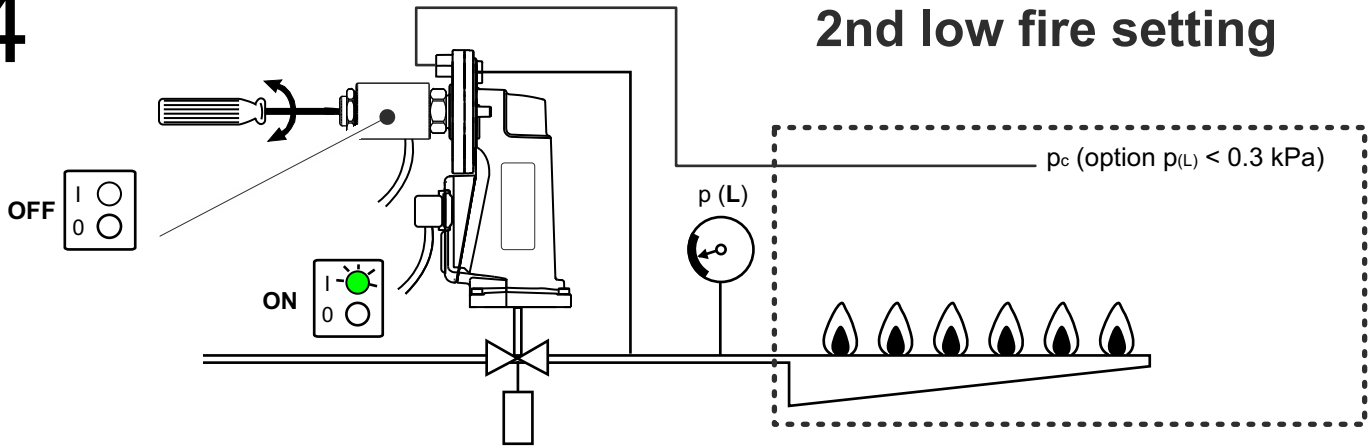

5 Operation

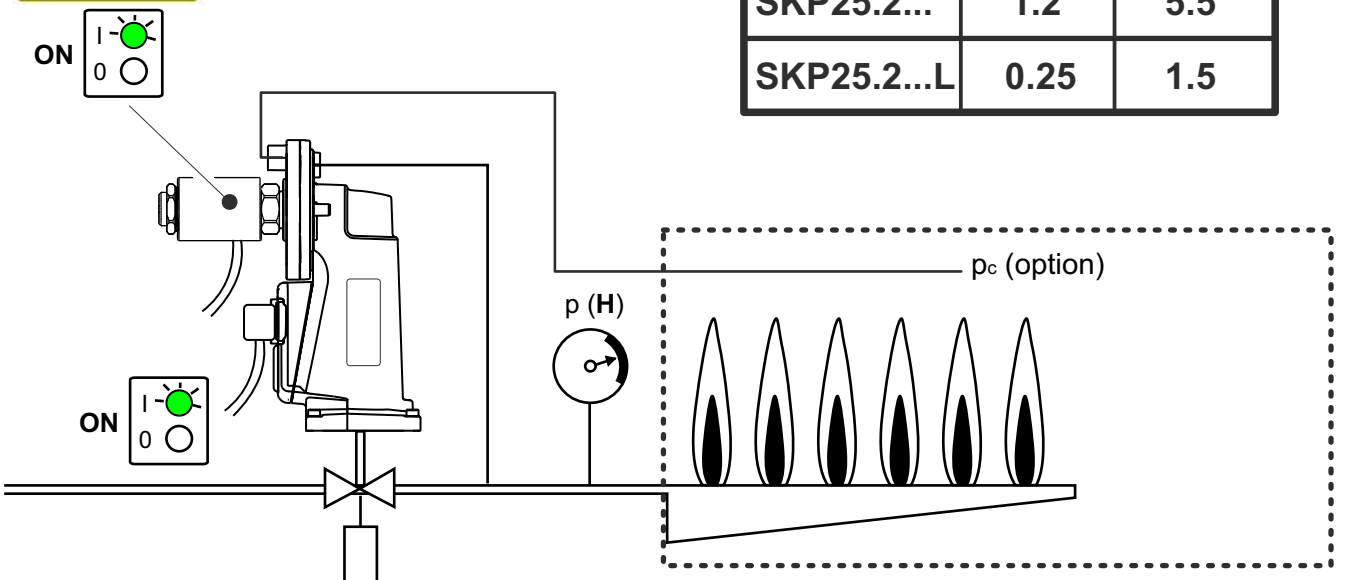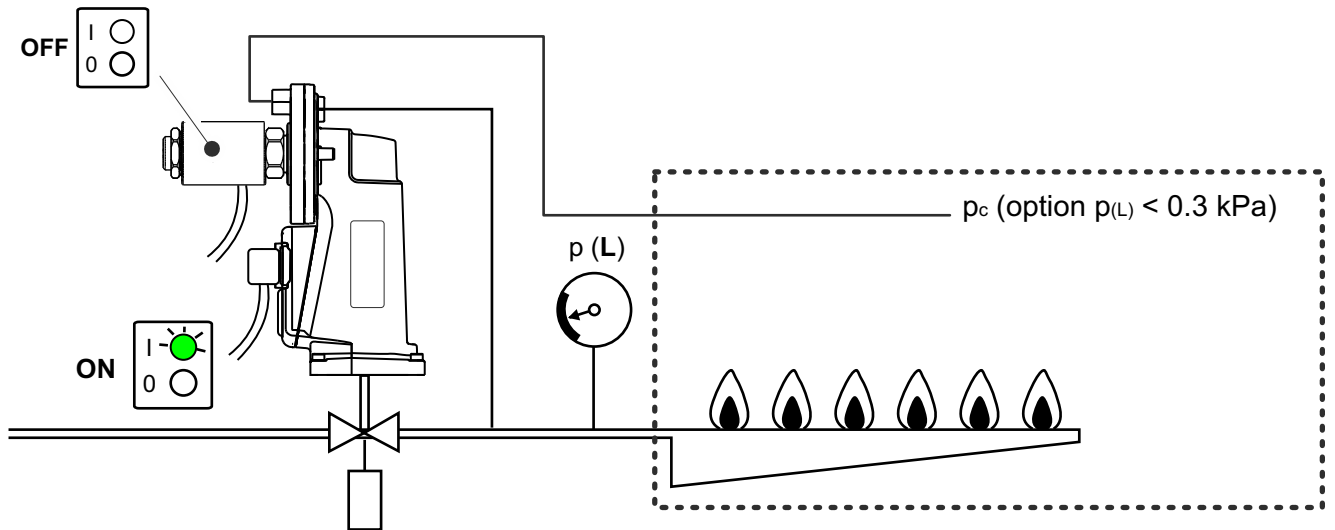

Default settings (kPa)	Flame	
	(L)	(H)
SKP25.2...	1.2	5.5
SKP25.2...L	0.25	1.5

6

