

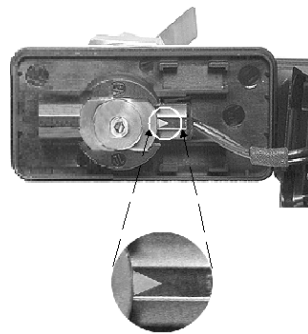
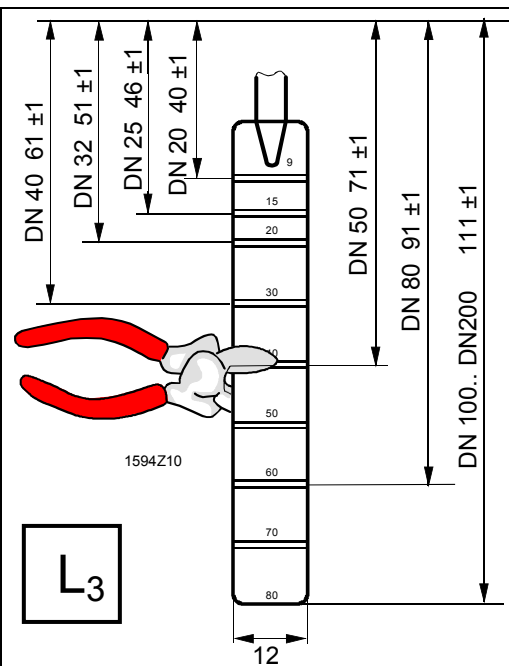
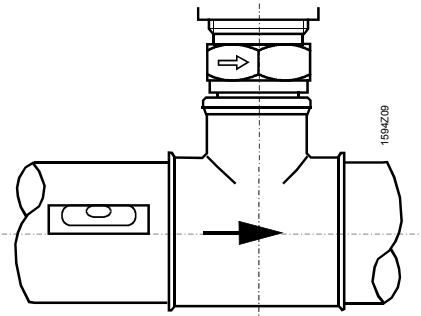
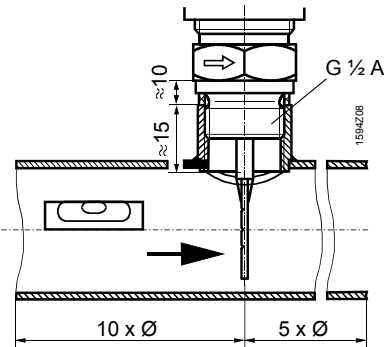


- de** Montageanleitung
- en** Mounting instructions
- fr** Instructions de montage
- sv** Monteringsinstruktion
- nl** Montage-aanwijzing
- it** Istruzioni di montaggio
- fi** Asennusohje
- es** Instrucciones de montaje
- da** Monteringsvejledning





QVE1901

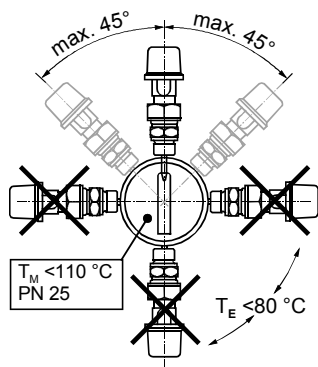

rot, red, rouge, röd, rood,
rosso, punainen, rojo, rugha

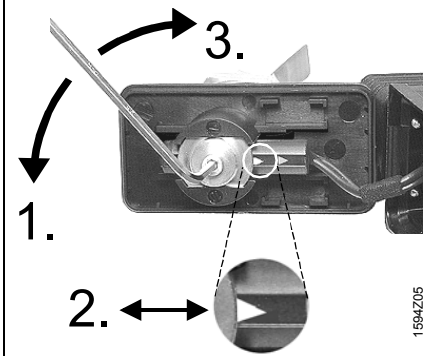

weiss, white, blanche, vit, wit,
bianco, valkoinen, blanco, hvid

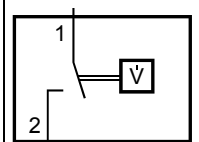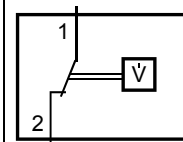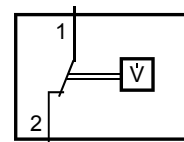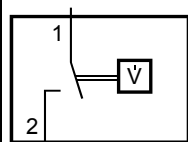

DN	L ₃ (mm)	Q _{max.} (m ³ /h)	(m ³ /h)	(m ³ /h)	(m ³ /h)	(m ³ /h)
20	40 ±1	4	≤0.9	≥1.1	≤0.9	≥1.1
25	46 ±1	5	≤1.1	≥1.3	≤1.1	≥1.3
32	51 ±1	8	≤1.6	≥1.9	≤1.6	≥1.9
40	61 ±1	10	≤1.8	≥2.1	≤1.8	≥2.1
50	71 ±1	14	≤2.4	≥2.7	≤2.4	≥2.7
80	91 ±1	30	≤4.7	≥5.1	≤4.7	≥5.1
100	111 ±1	40	≤5.8	≥6.4	≤5.9	≥6.4
150	111 ±1	100	≤14.2	≥15.5	≤14.2	≥15.5
200	111 ±1	180	≤29.0	≥30.0	≤29.0	≥30.0

