






en Operating Instructions

RDH10M

The RDH10M is a room thermostat with OpenTherm bus interface that allows you to set the desired room temperature (setpoint) at the time you want. The unit features an ergonomic setting knob for ease of temperature control.

Display

	Actual room temperature in °C
	The unit controls to the selected Comfort temperature
	Indicates when there is demand for heat / BMU reports "Burner on"
	Replace batteries

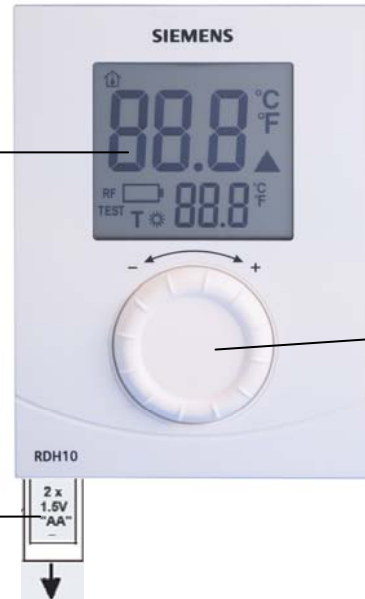

Rotary knob

Warmer / colder knob for selecting the room temperature setpoint


Battery compartment

2 alkaline batteries type AA, 1.5 V




Commissioning (optional when powered by OpenTherm bus)

- To prevent the room thermostat from powering itself off when Boiler Management Unit (BMU) is switched off
- Remove the black transit tabs from the 2 alkaline batteries. Check to see if the battery holder is in its correct position
- If no batteries are inserted, fit 2 alkaline batteries type AA in the battery compartment

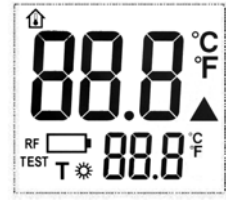



Initial power-up

After initial power up, all symbols appear on the display for about 2 seconds.



Selecting the required temperature

- Turn the rotary knob counterclockwise to decrease the setpoint, or clockwise to increase it in increments of 0.5 °C
- The required room temperature is displayed next to the Comfort temperature symbol 



Error of Boiler Management Unit (BMU)

If the display shows constantly **Err**, please contact your nearest heating specialist.

Changing the batteries

1. Use 2 new alkaline batteries type AA, 1.5 V.
2. Within 1 minute: Remove the battery holder, then the batteries, insert the new batteries and replace the battery holder.
3. Make certain the old batteries are disposed of properly, in compliance with environmental requirements.

Energy saving tips without sacrificing comfort

- Never allow room temperatures to exceed 21 °C
- Air out rooms for short periods of time only, but properly, with the windows wide open