

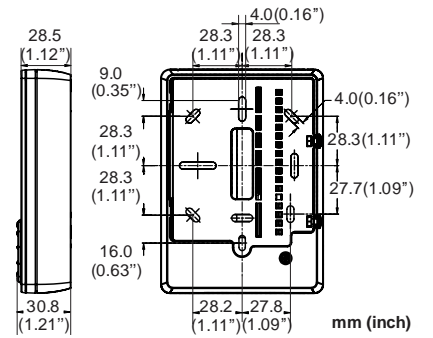
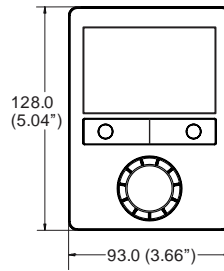
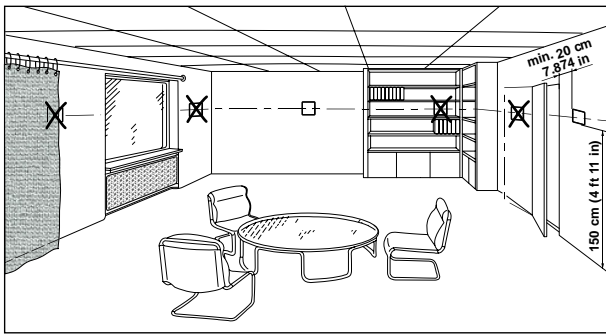


RDG400KN

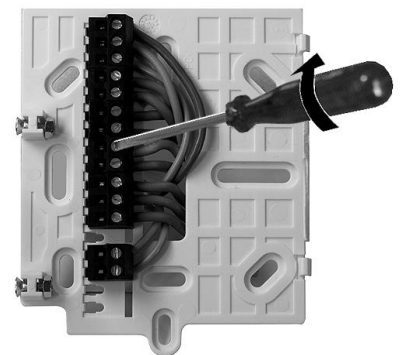

 
 
 
mm (inch)

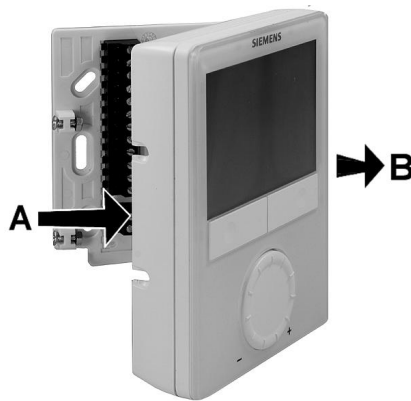

Max. 1 x 2.5 mm² (1 x 14 gauge)
Max. 2 x 1.5 mm² (2 x 16 gauge)






Max. 80 m (262 feet)



Feedback



3192Z112

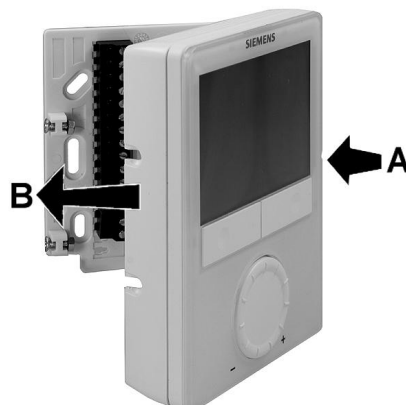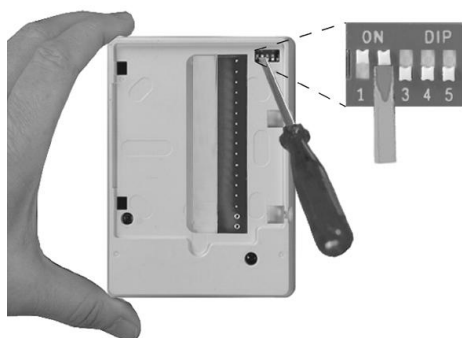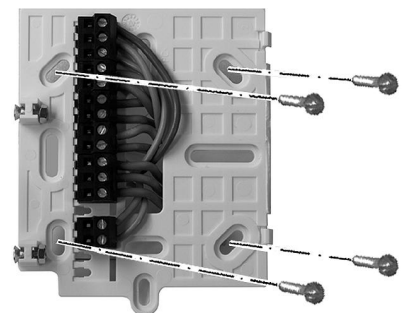

1) ① ④
2) a Outputs → DC 0...10 V / DC 10...0 V / 3-pos

3) ON OFF 1 2 3 and ON OFF 4 5

4)

5) G, G0 / 24 VAC: → P01...Pn

a Outputs

DC 10..0 V DIP 4 ON **3-pos**
 DC 0..10 V DIP 4 OFF **4**

VAV **Y10** **▲Y1/▼Y2**

① Single duct

ON OFF 1 2 3 4 5 ON OFF 1 2 3 4 5

a Outputs

Y10 DC 10..0 V DIP 4 ON **VAV V1**
 DC 0..10 V DIP 4 OFF **VAV V1**

Y1 / Y2 **V2 2-pos (PWM) Y1** **V2 3-pos ▲Y1/▼Y2** **VAV V1 3-pos ▲Y1/▼Y2**

② Single duct & el. heater

③ Single duct & radiator

④ Single duct & heat-cooling

KNX Programming mode

ACS Tool **KNX Bus**

P01=0, **P01=1**, **P01=2**, **P01=3**

i → P3182

	en	de	fr	it	es	nl	tr
①	Single duct	Einkanal	Monogaine	Monocondotto	Un conducto	Eénkanaals	Tek kanal
②	Single duct & el. heater	Einkanal & elektr. Heizung	Monogaine & chauffage électrique	Monocondotto & batteria elettrica di riscaldamento	Un conducto & batería eléctrica	Eénkanaals + elektr. verwarmers	Tek kanal & Elektr. Isıtıcı
③	Single duct & radiator	Einkanal & Radiatorventil	Monogaine & radiateur	Monocondotto & radiatori	Un conducto & radiadores	Eénkanaals + radiator	Tek kanal & radyatör
④	Single duct & heating / cooling	Einkanal & Heizen / Kühlen	Monogaine & chauffage / refroidissement	Monocondotto & riscaldamento / raffreddamento	Un conducto & calefacción / refrigeración	Eénkanaals + verwarmen / koelen	Tek kanal & ısıtma soğutma bataryası