

SIEMENS


Landis & Staefa Division

ZM1.., ZM1../A ZM2.., ZM2../A


35541F




1

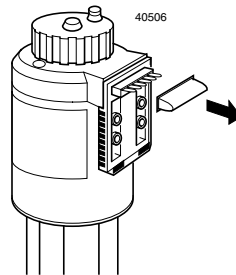


2

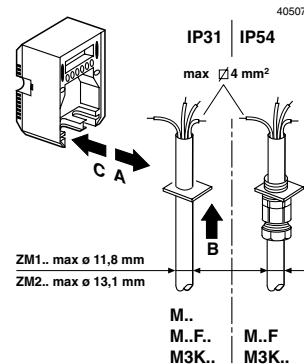


2.1

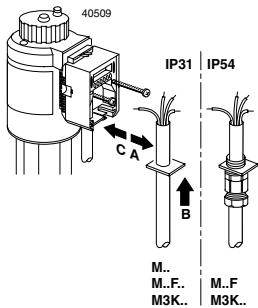


2.2





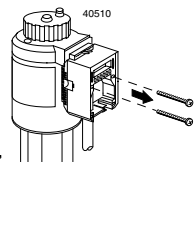


2.3

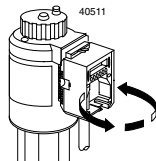


3

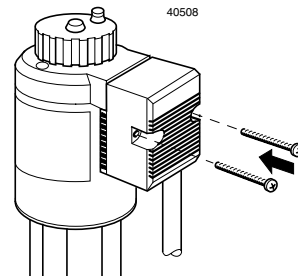

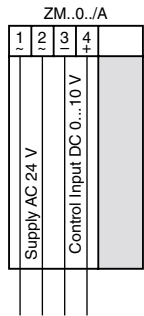    


DC 0 ... 10 V
ZM100/A, ZM101/A,
ZM200/A

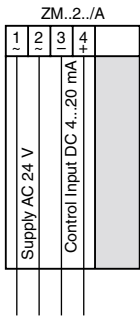

DC 4 ... 20 mA
ZM120/A, ZM121/A,
ZM220/A

AC 24 V, +15/-10 %

Speisespannung
Tension d'alimentation
Supply voltage
Tensione d'alimentazione
Voedingsspanning
Fødespænding
Tensión de alimentación

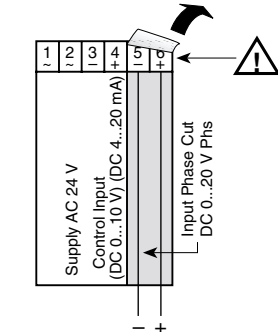





DC 0 ... 20 V Phs
ZM100/A, ZM101/A, ZM200/A
ZM120/A, ZM121/A, ZM220/A

DC 0 ... 20 V Phs

**Verboten
Interdit
Prohibited**



 **Vietato
Verboten
Prohibido**

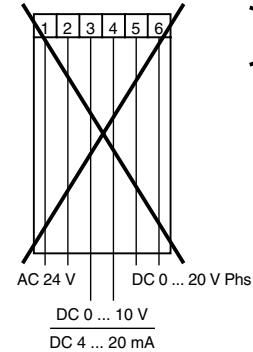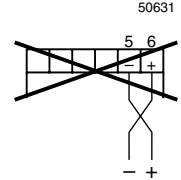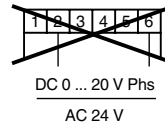

**Wichtig
Important**



**Importante
Gewichtig**

