



## RE8ST, RE8STCO

Sinteso™  
Cerberus™ PRO

Testfire 1001-101 ST test kit

Testfire 2001-101 RTCO test kit

---

- **The test kit RE8ST tester kit is composed of:**

- 1 Testfire 1001-101 tester
- 1 RE8-S smoke capsule
- 2 batteries
- 1 charger (incl. 12V connection cable)
- 2 mains cables (110 / 120-220 / 240 VAC)
- 1 USB cable

- **The test kit RE8STCO tester kit is composed of:**

- 1 Testfire 2001-101 tester
- 1 RE8-S smoke capsule
- 1 RE8-CO CO capsule
- 2 batteries
- 1 charger (incl. 12V connection cable)
- 2 mains cables (110 / 120-220 / 240 VAC)
- 1 USB cable

- **Battery powered**

- **Rapid activation**

- **Lightweight and simple to use**

- **Universal: suitable for use on most detectors**

- **Detectors can also be tested in high rooms or at angles by using telescopic rods and adaptor.**



---

**Forbidden** in electrical switching stations or areas where there is a danger of explosion!

---

Comply with the operating instructions on the detector tester.

### RE8ST: Kit and accessories

---



- Testfire tester (1 piece): part of the kit



- RE8-S smoke capsule (1 piece): part of the kit



- Battery (2 pieces): part of the kit



- Charger (1 piece) : part of the kit



- Heat detector adaptor (accessory) for telescopic rods FDUM29x:  
must be ordered separately

### RE8ST: Kit and accessories

---



- Testfire tester (1 piece): part of the kit



- RE8-S smoke capsule (1 piece): part of the kit



- RE8-CO CO capsule (1 piece): part of the kit



- Battery (2 pieces): part of the kit



- Charger (1 piece) : part of the kit



- Heat detector adaptor (accessory) for telescopic rods FDUM29x:  
must be ordered separately

**Characteristics**

- yellow plastic tubes in light and robust execution (non-conductive material)
- plastic sockets and slide bearings provide for easy sliding of the tubes
- quick spring-type locking mechanisms and continuous length adjustment
- The tubes can be extended to their maximum length and are protected against further extension by a stop bolt.
- Further extension of the telescopic rods is not possible.


**FDUM291**

- light telescopic rod for all applications, for room heights up to 5.5 m
- latch catch for continuous length adjustment
- three-part telescopic with tri-oval tubes as practical grip
- distortion of the tubes is not possible
- weight 1.2 kg without attached tool

**FDUM292**

- long, robust telescopic rod for room heights up to 8 m
- handle catch for continuous length adjustment
- stable, four-part telescopic with round tubes
- weight 3.4 kg without attached tool

**FDUM291**

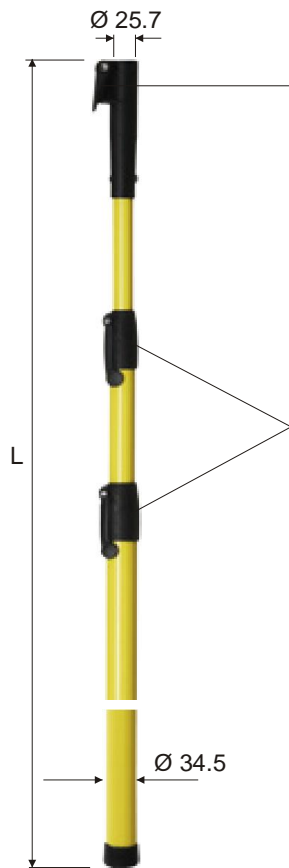

Handle catch

Latch catch

**FDUM291**

L= drawn in length 1.6 m  
L= drawn out length 4.2 m

**FDUM292**

L= drawn in length 2.1 m  
L= drawn out length 7.3 m

**FDUM292**



Beware of falling objects when working with a telescopic rod. Hardhat required.

## Technical data

RE8ST & RE8STCO	Recharge time	1 hour for each battery baton
	Power supply	Vehicle: 12 VDC; Main: 110 / 120-220 /240 VAC
	Humidity ( no condensation permitted)	≤95 %
	Operating / storage temperature	5... +45 °C / -10... +50 °C

## Details for ordering

	Type	Part no.	Designation	Weight
<b>Detector tester</b>	RE8ST	S54370-S23-A1	Testfire 1001-101 RT test kit	3.470 kg
	RE8STCO	S54370-S24-A1	Testfire 2001-101 RTCO test kit	3.750 kg
<b>Capsules</b>	RE8-S	S54370-N25-A1	TS3 smoke capsules (6 pieces)	0.079 kg
	RE8-CO	S54370-N22-A1	TS3 CO capsules (6 pieces)	0.077 kg
<b>Accessory</b>	RE7T-A	S54370-N4-A1	Solo719 Adaptor for FDUM29x	0.260 kg
<b>Spare parts</b>	RE7T-B	S54370-N5-A1	Solo760 Battery for RE7T	1.090 kg
	RE7T-C	S54370-N6-A1	Solo725 Charger for RE7T	1.210 kg
<b>Telescopic rods</b>	FDUM291	A5Q00004996	Telescopic rod three-part telescopic with tri-oval tubes (1.6 m / 4.2 m)	1.960 kg
Spare parts	-	A5Q00009787	Lever with screw and nut (Handle catch)	0.023 kg
	-	A5Q00009786	Adapter with lever, screw and nut incl. attachment and bushing screw	0.088 kg
	-	A5Q00009788	Small flap with screw and nut (Latch catch)	0.015 kg
	-	A5Q00009789	Large flap with screw and nut (Latch catch)	0.016 kg
	FDUM292	A5Q00004997	Telescopic rod four-part telescopic with round tubes (2.1 m / 7.3 m)	4.480 kg
Spare parts	-	A5Q00009787	Lever with screw and nut (Handle catch)	0.020 kg
	-	A5Q00009786	Adapter with lever, screw and nut incl. attachment and bushing screw	0.088 kg