

- de** Montageanleitung
- en** Mounting instructions
- fr** Instructions de montage
- sv** Monteringsinstruktion
- nl** Montage-aanwijzing
- it** Istruzioni di montaggio
- fi** Asennusohje
- es** Instrucciones de montaje
- da** Monteringsvejledning

QXA2100

1

1542Z04a

2

Ø~5 mm
 h~2 mm

Wärmeleitpaste
 Pâte conductrice
 Thermal conducting paste
 Pasta termoconduttrice
 Pasta conductora de calor
 Värmeledande pasta
 Warmtegeleidingspasta

1542Z05

3

B09303

4

Ø 10 ... 100 mm

1542Z06

5

1542Z34


6

8


100

~2

1542Z08

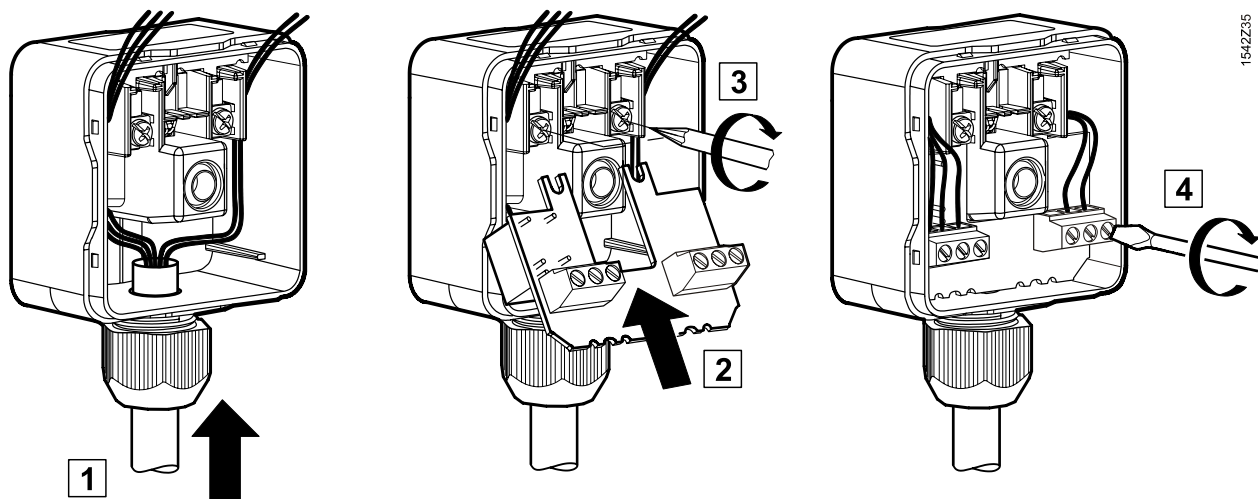


1542Z35

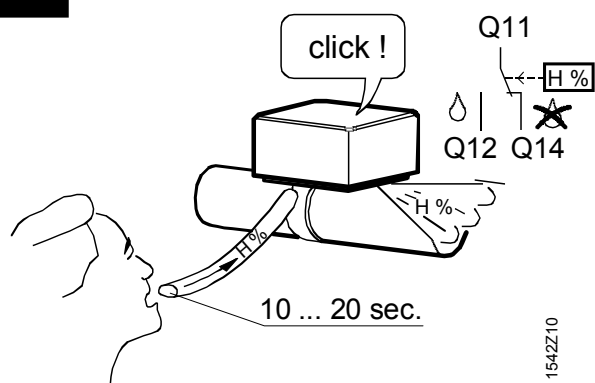


1542Z10

H %	G - G0 (G+ - G-)	
☆	off	Q11 — Q14 Q12
☆	on	Q11 — Q14 Q12
☾	on	Q11 — Q14 Q12

QXA2100:

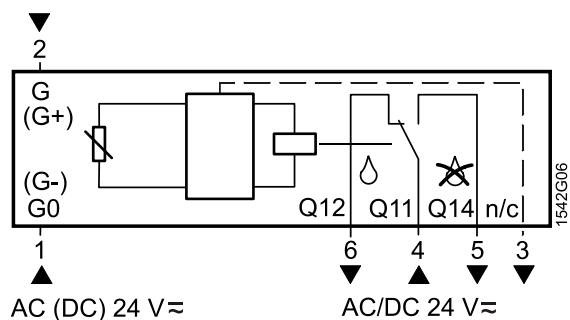


1542G06

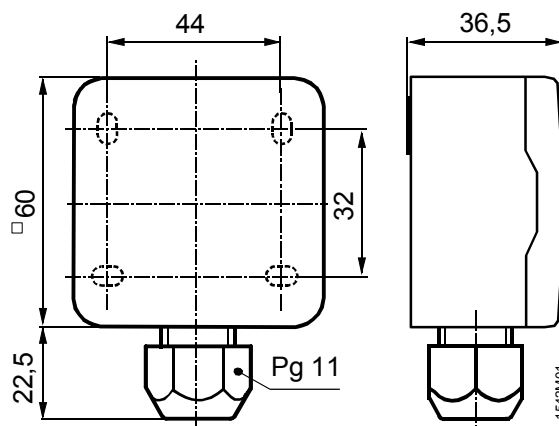

1542M01

QXA2100 + AQX2000:

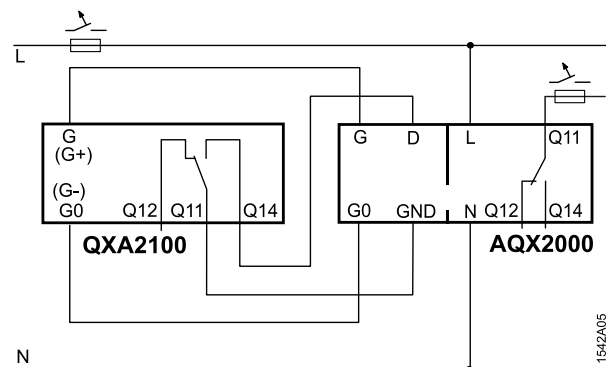

1542A05

Maße in mm
Dimensions in mm
Dimensions en mm
Mått i mm
Maten in mm
Dimensioni in mm
Mitat mm
Dimensiones en mm
Mål i mm