

Spa Panel

FEATURES

- UL Listed
- Factory installed, 2-pole 50A GFCI breaker
- NEMA Type 3R outdoor enclosure
- Provisions for 2 extra circuits
- 125A rated interior
- Factory installed 5 position ground bar
- Suitable for use as service equipment when a main breaker (100A maximum) used in conjunction with main breaker retainer clip ECMBR1^{①②}

① ECMBR1 available Summer 2004. MBR1 to be used until then.

② ECMBR1 for use on QP breakers (60-100A only) and all QPH and HQP breakers.

Catalog Number	2-Pole GFCI Breaker	Dimensions (in inches)		
		H	W	D
W0408L1125SPA50	50A	12-1/4	6	4-1/2
W0408L1125SPA60	60A	12-1/4	6	4-1/2




Dead Front



Enclosure



Hub Cover Plate

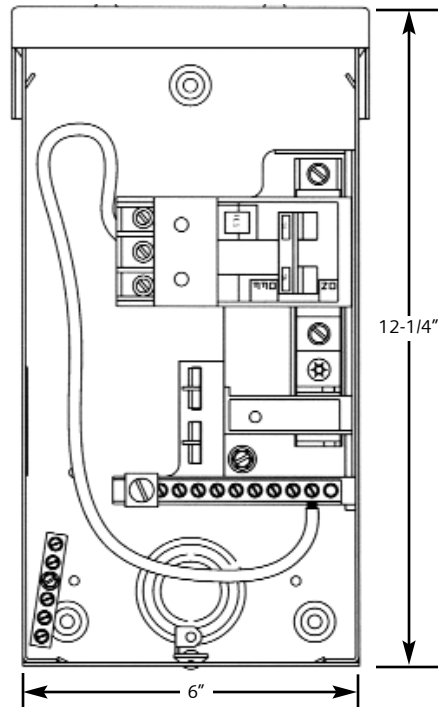

fastfax

SIEMENS