

Meter Centers

Circuit Breaker Service Entrance Modules

FEATURES

- UL Listed for 60/75°C conductors.
See equipment markings for applications.

Series Tested Systems

Specify Siemens Modular Metering equipment in conjunction with Siemens Load Centers.


Maximum Interrupting Rating	Ampere Rating	Indoor Enclosure Type 1 Indoor Catalog Number	Outdoor Enclosure Type 3R Outdoor Catalog Number	Circuit Breaker Type
1 PHASE, 3 WIRE SN, INCOMING		120/240 VOLT AC		
65,000	400	MC4U	WMC4	JD6
65,000	600	MC6U	WMC6	JD6
65,000	800	MC8U	WMC8	MD6
65,000	1000	MC10U	WMC10	ND6
65,000	1200	MC12U	WMC12	ND6
65,000	1600	MC16U	WMC16	PD6
65,000	2000	MC20U		RD6
3 PHASE, 4 WIRE SN, INCOMING		120/240 or 120/208 VOLT AC		
65,000	400	MC44U	WMC44	JD6
65,000	600	MC64U	WMC64	JD6
65,000	800	MC84U	WMC84	MD6
65,000	1000	MC104U	WMC104	ND6
65,000	1200	MC124U	WMC124	ND6
65,000	1600	MC164U	WMC164	PD6



Service Entrance Modules


OUTDOOR

1 PHASE, 3 WIRE, INCOMING

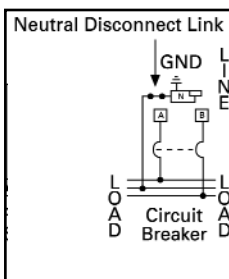

OUTDOOR

3 PHASE, 4 WIRE, INCOMING


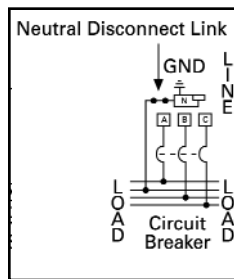


fastfax

SIEMENS

Circuit Breaker Service Entrance Modules

Dimensions (in inches)

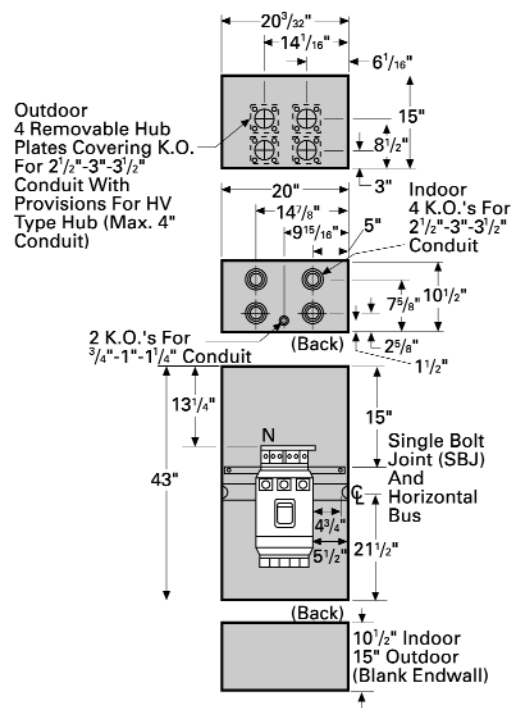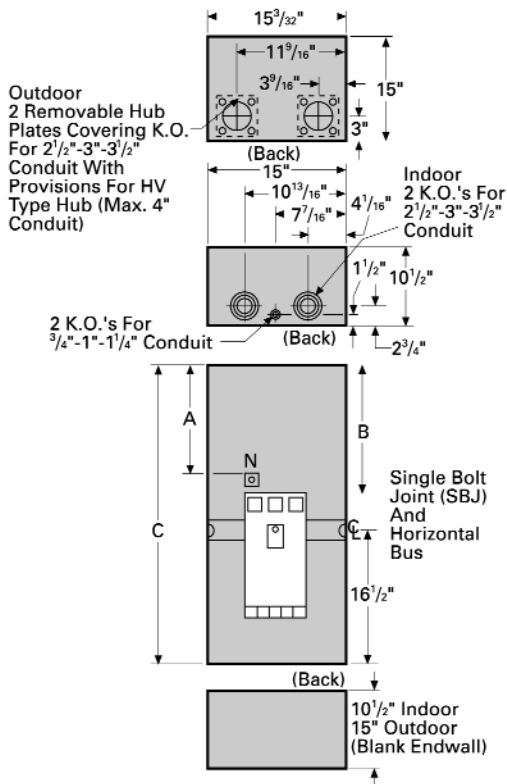


Catalog Number		Dimensions (inches)	
Indoor	Outdoor	(D)	(D)
MC8U	WMC8U	5-7/16	5-7/16
MC84U	WMC84U	5-7/16	5-7/16


Catalog Number		Dimensions (inches)			
Indoor	Outdoor	(A)	(B)	(C)	(D)
MC4U	WMC4U	9-1/4	15-9/16	33	4-9/16
MC6U	WMC6U	14	17-5/8	37	4-9/16
MC44U	WMC44U	9-1/4	15-9/16	33	4-9/16
MC64U	WMC64U	14	17-5/8	37	4-9/16

Circuit Breaker Service Entrance Modules

Dimensions (in inches)

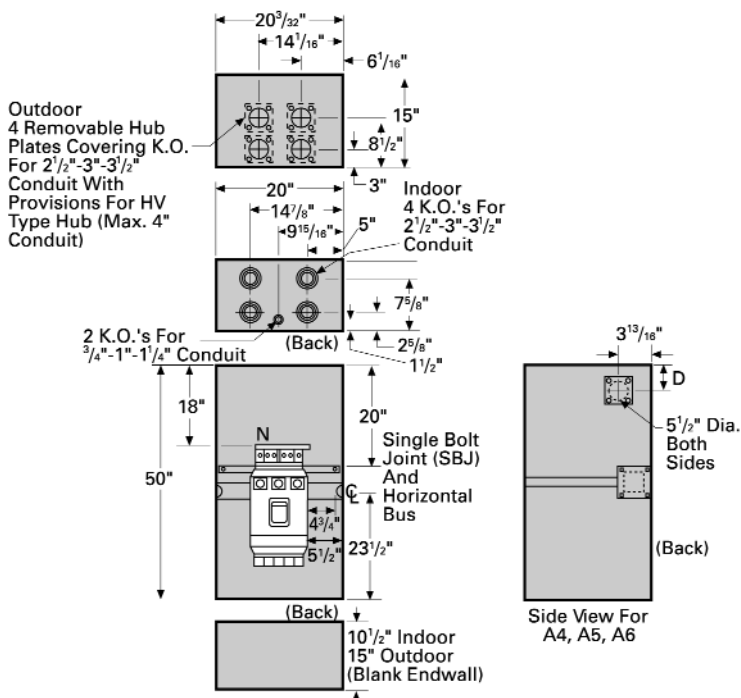

Catalog Number		Dimensions (inches)
Indoor	Outdoor	(D)
MC10U	WMC10U	10-7/16
MC12U	WMC12U	10-7/16
MC104U	WMC104U	10-7/16
MC124U	WMC124U	10-7/16

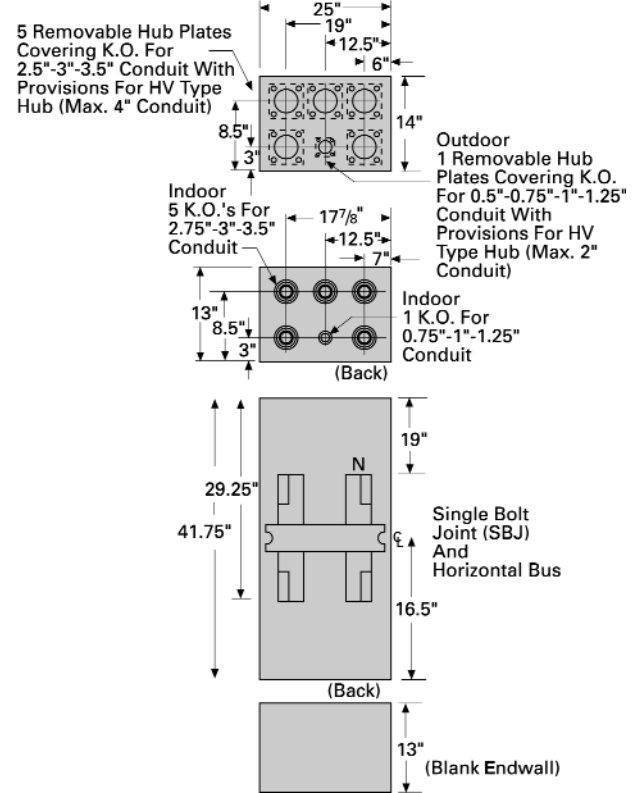

Catalog Number	
Indoor	Outdoor
MC16U	WMC16U
MC164U	WMC164U
MC20U	