



Meter Sockets

200 Ampere, 5 Jaw, Lever Bypass

FEATURES

- UL Listed for service entrance.
- Overhead or underground feed.
- 5th jaw factory installed.
- Clamping jaw lever bypass.
- Powder coat paint.
- 350 mcm lay-in lugs.
- Ground lug included.

| Meter Socket Continuous Ampere Rating | Catalog Number | Enclosure Material | Service | Phase | Number of Jaws | Type of Bypass | Type of Cover | Barrel Lock | Hub Opening |
|---|--------------------|-----------------------|---------|--------|-------------------|-------------------|------------------|----------------|----------------|
| 200 | S40405-015F | Steel | OH/UG | Single | 5 | Lever | Ringless | – | Coverplate |
| 200 | S40405-025 | Steel | OH/UG | Single | 5 | Lever | Ringless | – | Coverplate |
| 200 | S40405-02CO | Steel | OH/UG | Single | 5 | Lever | Ringless | 7/8" | Coverplate |
| 200 | S40405-0BNU | Steel | OH/UG | Single | 5 | Lever | Ringless | 7/16" | Opening |

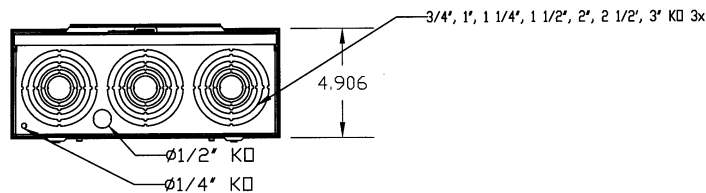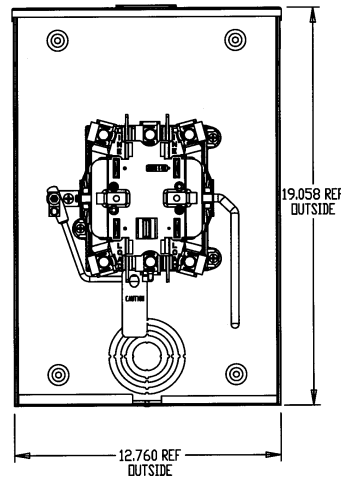

fastfax

SIEMENS

Siemens Energy & Automation, Inc. • 3333 Old Milton Parkway, Alpharetta, GA 30005 • 1-800-964-4114 • www.sea.siemens.com/reselec

©2002 Siemens Energy & Automation, Inc. All Rights Reserved.

Siemens is a registered trademark of Siemens AG. Product names mentioned may be trademarks or registered trademarks of their respective companies.

Specifications are subject to change without notice