


# EQ8693, EQ8695, EQ8696 Circuit Breakers

## FEATURES

- Bolt-on main breaker for Siemens single phase load centers
- UL listed
- Interrupting rating of 22KA
- 120/240V AC
- Wire range #4 – 300 kcmil Cu/Al
- Shunt trip available, use ST suffix for ordering

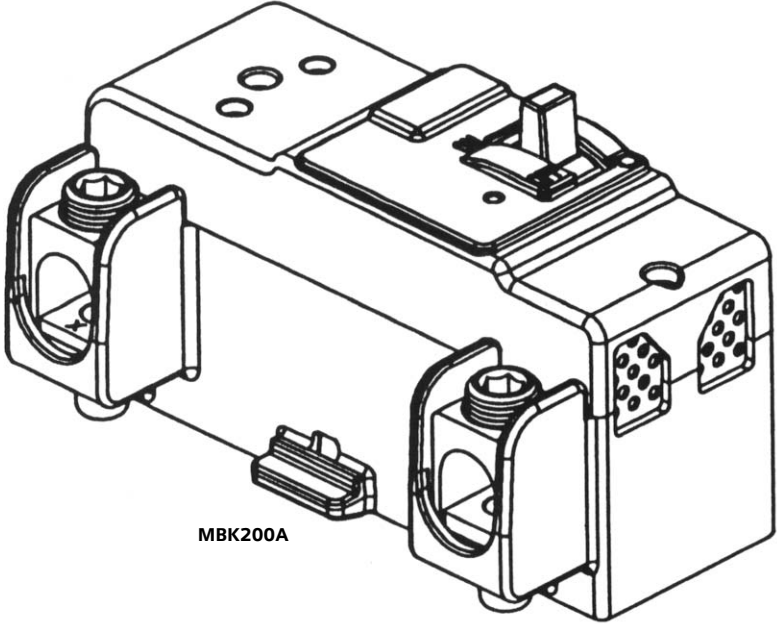


Catalog Number	Amperage	Interrupting Rating	UL Type
MBK150A	150	22K	EQ8693
MBK200A	200	22K	EQ8695
MBK225A	225	22K	EQ8696

*fastfax*

**SIEMENS**

# EQ8693, EQ8695, EQ8696 Circuit Breakers

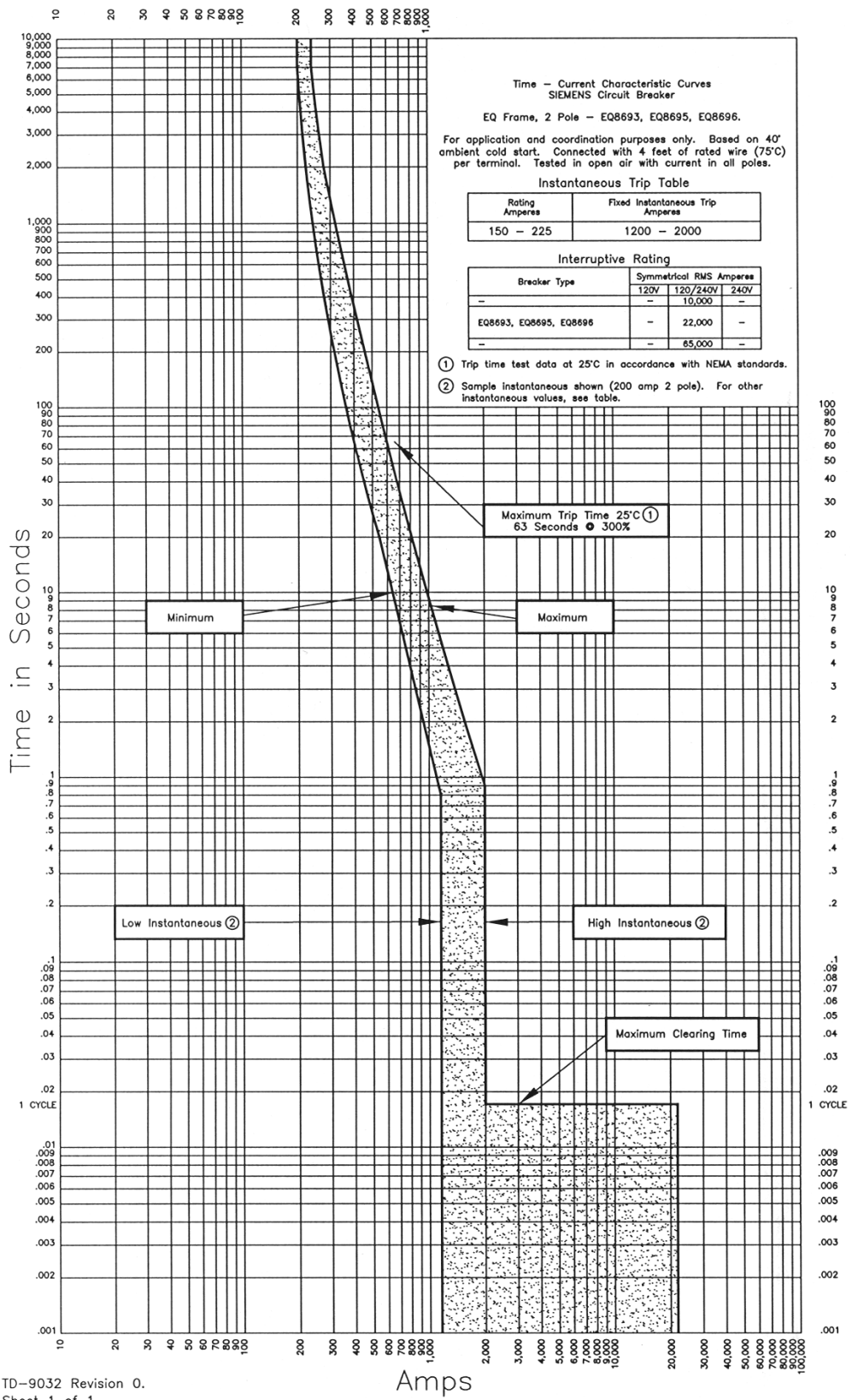

# EQ8693, EQ8695, EQ8696 Circuit Breakers

EQ8693, EQ8695 & EQ8696 Series Ratings 240V 2 Breaker Series								
Branch Breaker or Fuse			Main Breaker or Fuse			Interrupting Rating RMS Symm		
UL Type	Amps	Poles	UL Type	Amps	Poles	RMS Symm Amps	Volts	Phase
QP,BQ,BL	15- 70	1	EQ868#	100-125	2	22,000	120/240	1
QP,BQ,BL	15-125	2	EQ868#	100-125	2	22,000	120/240	1
QG,BG,BLG	15- 30	1	EQ868#	100-125	2	22,000	120	1
QG,BG,BLG	15- 30	2	EQ868#	100-125	2	22,000	120/240	1
QT	15- 50	1, 2	EQ868#	100-125	2	22,000	120/240	1
QT	15- 50	2	EQ868#	100-125	2	22,000	120/240	1
QAF,BQAF,BAF	15- 20	1	EQ868#	100-125	2	22,000	120	1
QPF,BQF,BLF	15- 30	1	EQ868#	100-125	2	22,000	120	1
QPF,BQF,BLF	15- 60	2	EQ868#	100-125	2	22,000	120/240	1
QE,BE,BLE	15- 30	1	EQ868#	100-125	2	22,000	120	1
QE,BE,BLE	15- 60	2	EQ868#	100-125	2	22,000	120/240	1
EQ868#	100	2	HQN,HQNR	150-200	2	65,000	120/240	1
EQ968#	150-200	2	HQN,HQNR	150-200	2	65,000	120/240	1
EQ868#	100-125	2	HQPP	150-225	2	65,000	120/240	1
EQ968#	150-200	2	HQPP	150-225	2	65,000	120/240	1
EQ868#	100-125	2	EQ978#	150-225	2	65,000	120/240	1
EQ868#	100-125	2	FD6,FXD6	150-250	2, 3	65,000	120/240	1
EQ868#	100-125	2	FD6-A,FXD6-A	150-250	2, 3	65,000	120/240	1
EQ868#	100-125	2	HFD6,HFXD6	150-250	2, 3	100,000	120/240	1
EQ868#	100-125	2	T (300V)	100-200	2	100,000	120/240	1

For 240V 3 and 4 Breaker Series information please contact your local sales representative.

# EQ8693, EQ8695, EQ8696 Circuit Breakers

