


Catalog Numbers, Ratings and Features


Catalog No.	Meter Socket Cover	Main Bus, 1200A Max	Main Breaker Max. Rating	Max. 1" Breaker Positions	Max. Circuits	Jaws	Horn Bypass
WC2040B1T1	RING-TYPE	1 Phase	225A	20	40	4	N
WC2040B1T1R	RINGLESS	1 Phase	225A	20	40	4	N
WC2040B1T1RJ	RINGLESS	1 Phase	225A	20	40	5	N
WC2040B1T1RJB	RINGLESS	1 Phase	225A	20	40	5	Y

- Type 3R Outdoor Enclosure
- Main Bus Rating: 1200A Max.
- Meter Socket Rating: 200A Continuous
- 1 Phase In, 1 Phase Out
- 120/240 Volts AC, 1 Phase, 3 Wire
208Y/120 Volts AC (5th jaw may be required)
- 100K AIC Max. Short Circuit Current Rating
(See Wiring Diagram for Details)


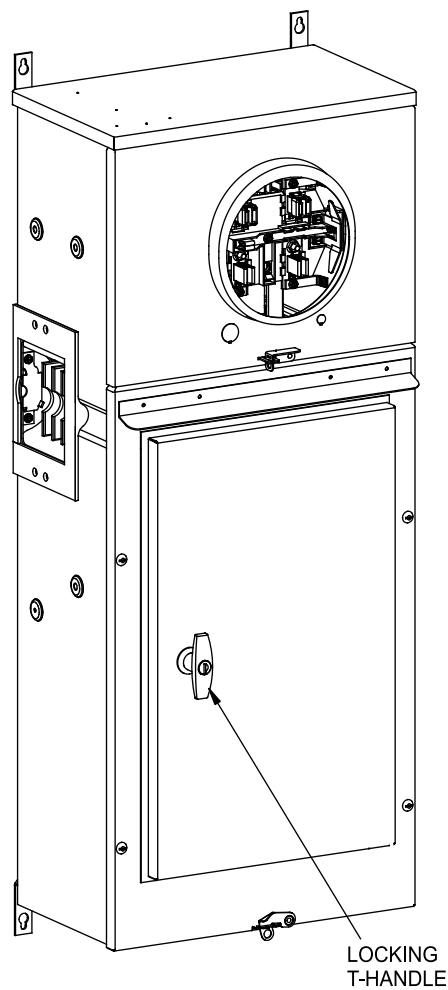


LOCKING T-HANDLE

View Shown with Covers Removed

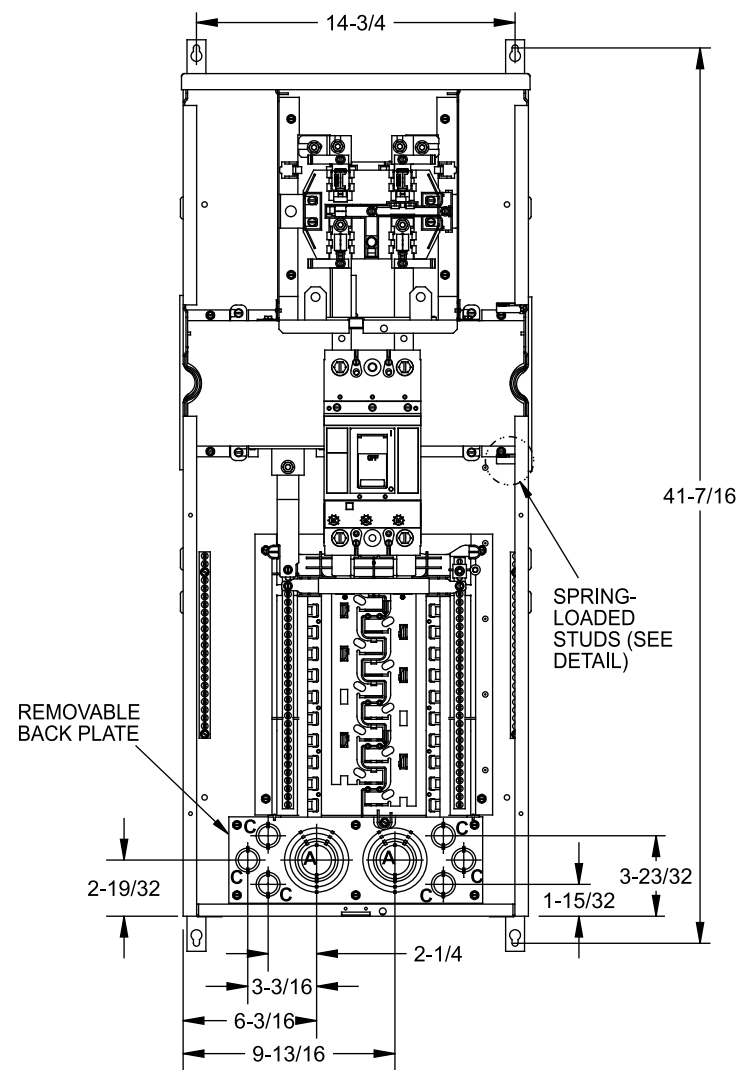

View Shown with Door Removed

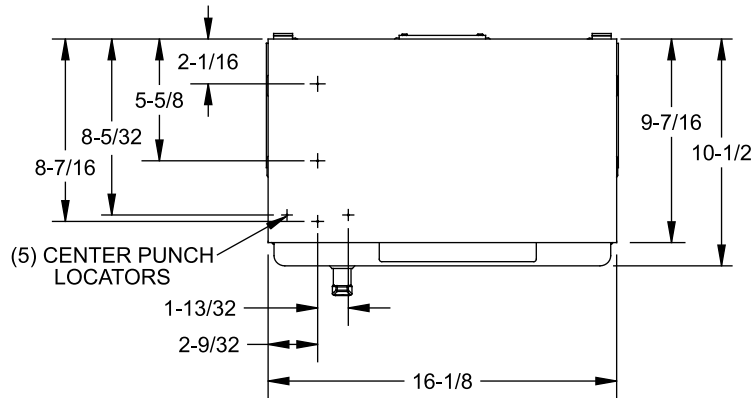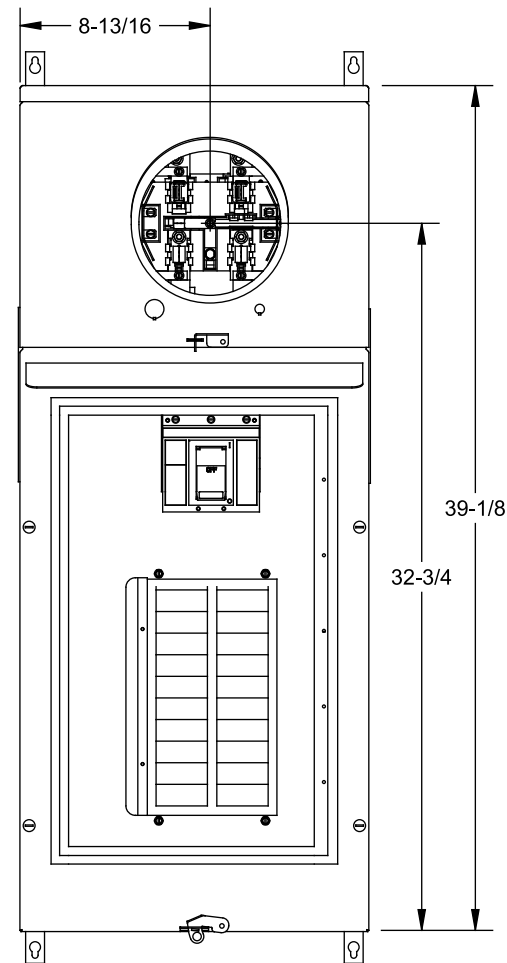

Circuit Breakers

Installed Main Breaker:
HFD62B225

Use Siemens Branch Breaker Types:
QP, QPH, HQP, QT, QAF, QAFH,
QAF2, QAF2H, HQAF2, QPF, QPFH,
QE, QEH, QNR, QNRH, HQNR

Additional Modules

Connect Modules Using:
QuickConnect Catalog No: QC1
Torque: 400-440 lb-in (35-36 ft.-lb.)
Single Bolt Joint Catalog No: SBJ1
Torque: 400-480 lb-in (35-40 ft.-lb.)


Use with Module Siemens Series#
Main Breakers (W)MC, WB, WEB, WXB
Switches WMP, WMS, WS, WES
Tap/Terminal Boxes WMTB, WTB, WET, WT_PU
Pull Boxes WMMB
Meter Module (W)MM, WxMM, (W)MT,
(W)ML, (W)MK
Meter Combinations WC, WCL, WCT
Extension Box WMEX, WSP, WSPD
Bussed Elbow BE

Accessories

Accessories	Cat. No.
1" Filler Plate	ECQF3
SubFeed Lug Kit	ECLK2125
SubFeed Lug Kit	ECLK2225
Neutral Lug Kit	ECLK1-2
Neutral Lug Kit	ECLK2
Meter Socket Repl.	ECMF5
Horn By-Pass	ECMFH
5th Jaw Mod	ECMF5
Insulated 5th Jaw	ECMF5i
End Closure Plate	WMEP
Meter Cover Plate	ECCP3
Mounting Tabs (2)	ECMFTAB
Back Rail/Clip	ECMFWLCLIP
Mounting Rail	MMRAIL
Wall Mounting Rail (60")	MMZR60
Arc Flash Label	ECAFL


Schematic

(Shown with 5th Jaw Installed)

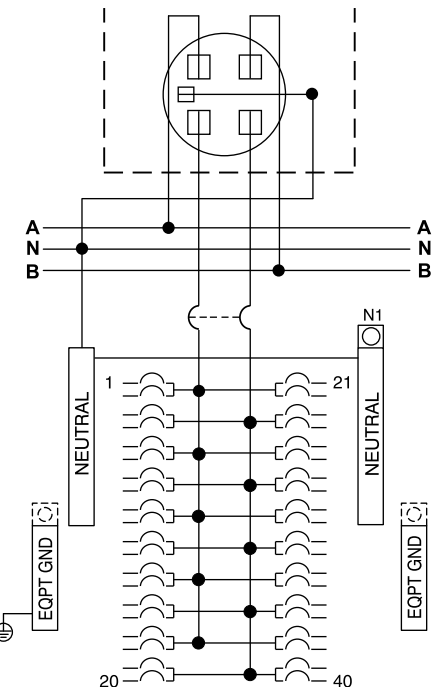


Terminal	Wire Size	Torque
N1	2/0 - #4 AWG	110 lb-in
Branch Breaker Terminals	See Markings on Breaker	
N1/Equip GND	#10 - #14 CU #10 - #12 AL #8 #6 - #4	20 lb-in 20 lb-in 25 lb-in 35 lb-in
Ground Conductors Only	(2) or (3) #14 AWG (2) #12-#10 AWG	20 lb-in 20 lb-in
Ground Bar/Neutral Lug Kits		
ECLK1-2	2/0 - #2 AWG	45 lb-in
ECLK2	2/0 - #4 AWG	135 lb-in

WC2040B1T1RJB Shown

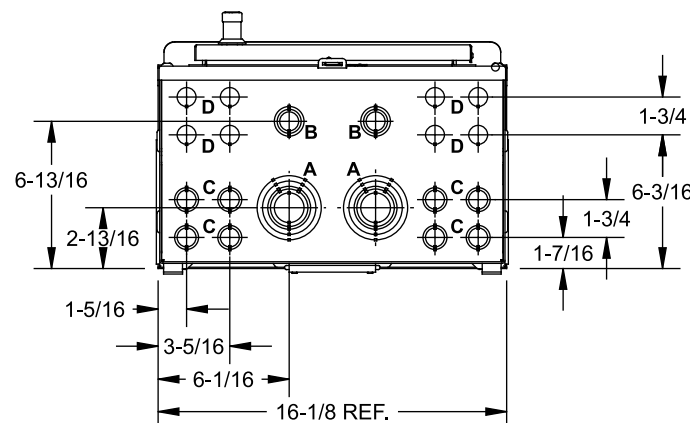

Knockout Chart		
Designation	KO Size	Qty
A	2-1/2, 2, 1-1/2, 1-1/4, 1"	4
B	1, 3/4, 1/2"	2
C	3/4, 1/2"	14
D	1/2"	8

#10-32 x 7/8 SCREWS
ENCLOSURE WALL

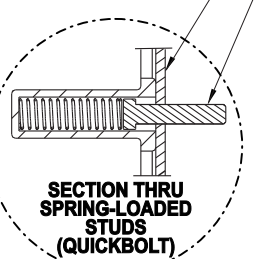

© 2013 Copyright Siemens Industry, Inc.

SIEMENS
Siemens Industry, Inc.

PowerMod™ Modular Metering

Catalog Numbers: **1in-1out Residential Socket with 20 Position 40 Circuit Panel**

Size B Dwg. No. **RESI 1-1_NB**