

Type VBII

Cross-reference Guide




Safety Switches

Answers for industry.

SIEMENS

General Duty 240 Volt, Type 1 (Indoor)

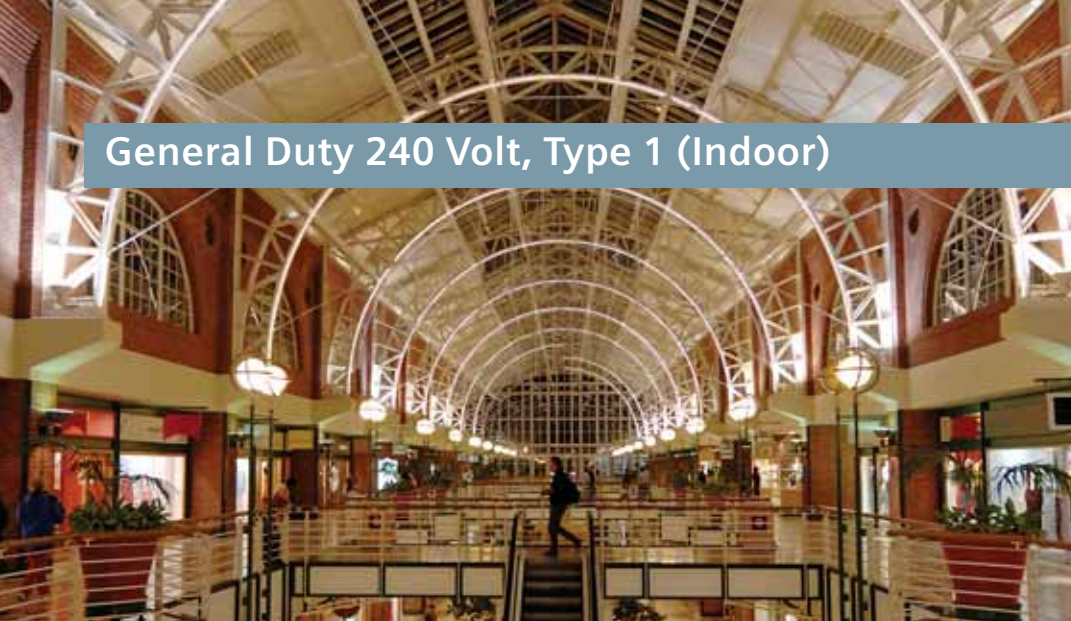

System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, Fusible							
	30						Use
	60	Use	Use	Use	Use	Use	2-Pole
	100	2-Pole	2-Pole	2-Pole	2-Pole	2-Pole	3-Wire
	200	3-Wire	3-Wire	3-Wire	3-Wire	3-Wire	Switch
	400	Switch	Switch	Switch	Switch	Switch	DG225FGK
600							DG226FGK
2-Pole, 3-Wire, Fusible							
	30	GF221N	JN321	GHN321N	TG3221	D221N	DG221NGB
	60	GF222N	JN322	GHN322N	TG3222	D222N	DG222NGB
	100	GF223N	JN323	GHN323N	TG3223	D223N	DG223NGB
	200	GF224N	JN324	GHN324N	TG3224	D224N	DG224NGK
	400	GF225N	JN325	GHN325N	TG3225	D225N	DG225NGK
600	GF226N	JN326	GHN326N	TG3226	D226N	DG226NGK	
3-Pole, 3-Wire, Fusible							
	30				Use		Use
	60	Use	Use	Use	3-Pole	Use	3-Pole
	100	3-Pole	3-Pole	3-Pole	4-Wire	3-Pole	4-Wire
	200	4-Wire	4-Wire	4-Wire	Switch	4-Wire	Switch
	400	Switch	Switch	Switch	TG3325	Switch	DG325FGK
600				TG3326		DG326FGK	
3-Pole, 4-Wire, Fusible							
	30	GF321N	JN421	GHN421N	TG4321	D321N	DG321NGB
	60	GF322N	JN422	GHN422N	TG4322	D322N	DG322NGB
	100	GF323N	JN423	GHN423N	TG4323	D323N	DG323NGB
	200	GF324N	JN424	GHN424N	TG4324	D324N	DG324NGK
	400	GF325N	JN425	GHN425N	TG4325	D325N	DG325NGK
600	GF326N	JN426	GHN426N	TG4326	D326N	DG326NGK	
3-Pole, 3-Wire, Non-Fusible							
	30	GNF321	JU321	GUN321	TGN3321	DU321	DG321UGB
	60	GNF322	JU322	GUN322	TGN3322	DU322	DG322UGB
	100	GNF323	JU323	GUN323	TGN3323	DU323	DG323UGB
	200	GNF324	JU324	GUN324	TGN3324	DU324	DG324UGK
	400	GNF325	JU325	Use Heavy	TGN3325	DU325	DG325UGK
600	GNF326	JU326	Duty Sw.	TGN3326	DU326	DG325UGK	


General Duty 240 Volt, Type 3R (Outdoor)



System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, Fusible							
	30						Use
	60	Use	Use	Use	Use	Use	2-Pole
	100	2-Pole	2-Pole	2-Pole	2-Pole	2-Pole	3-Wire
	200	3-Wire	3-Wire	3-Wire	3-Wire	3-Wire	Switch
	400	Switch	Switch	Switch	Switch	Switch	DG225FRK
600						Switch	DG226FRK
2-Pole, 3-Wire, Fusible							
	30	GF221NR	NR321	GHN321NW	TG3221R	D221NRB	DG221NRB
	60	GF222NR	NR322	GHN322NW	TG3222R	D222NRB	DG222NRB
	100	GF223NR	NR323	GHN323NW	TG3223R	D223NRB	DG223NRB
	200	GF224NR	NR324	GHN324NW	TG3224R	D224NRB	DG224NRK
	400	GF225NR	NR325	GHN325NW	TG3225R	D225NR	DG225NRK
600	GF226NR	NR326	GHN326NW	TG3226R	D226NR	DG226NRK	
3-Pole, 3-Wire, Fusible							
	30				Use		Use
	60	Use	Use	Use	3-Pole	Use	3-Pole
	100	3-Pole	3-Pole	3-Pole	4-Wire	3-Pole	4-Wire
	200	4-Wire	4-Wire	4-Wire	Switch	4-Wire	Switch
	400	Switch	Switch	Switch	TG3325R	Switch	DG325FRK
600				Switch	TG3326R	Switch	DG326FRK
3-Pole, 4-Wire, Fusible							
	30	GF321NR	NR421	GHN421NW	TG4321R	D321NRB	DG321NRB
	60	GF322NR	NR422	GHN422NW	TG4322R	D322NRB	DG322NRB
	100	GF323NR	NR423	GHN423NW	TG4323R	D323NRB	DG323NRB
	200	GF324NR	NR424	GHN424NW	TG4324R	D324NRB	DG324NRK
	400	GF325NR	NR425	GHN425NW	1	D325NR	DG325NRK
600	GF326NR	NR426	GHN426NW	1	D326NR	DG326NRK	
3-Pole, 3-Wire, Non-Fusible							
	30	GNF321R	NFR321	GUN321AW	TGN3321R	DU321RB	DG321URB
	60	GNF322R	NFR322	GUN322AW	TGN3322R	DU322RB	DG322URB
	100	GNF323R	NFR323	GUN323AW	TGN3323R	DU323RB	DG323URB
	200	GNF324R	NFR324	GUN324AW	TGN3324R	DU324RB	DG324URK
	400	Use Heavy	Use Heavy	Use Heavy	Use Heavy	Use Heavy	DG325URK
600	Duty Sw.	Duty Sw.	Duty Sw.	Duty Sw.	Duty Sw.	DG326URK	

¹ Use 3-Pole, 3-Wire Switch. Order separate neutral.

Heavy Duty 240 Volt, Type 1 (Indoor)

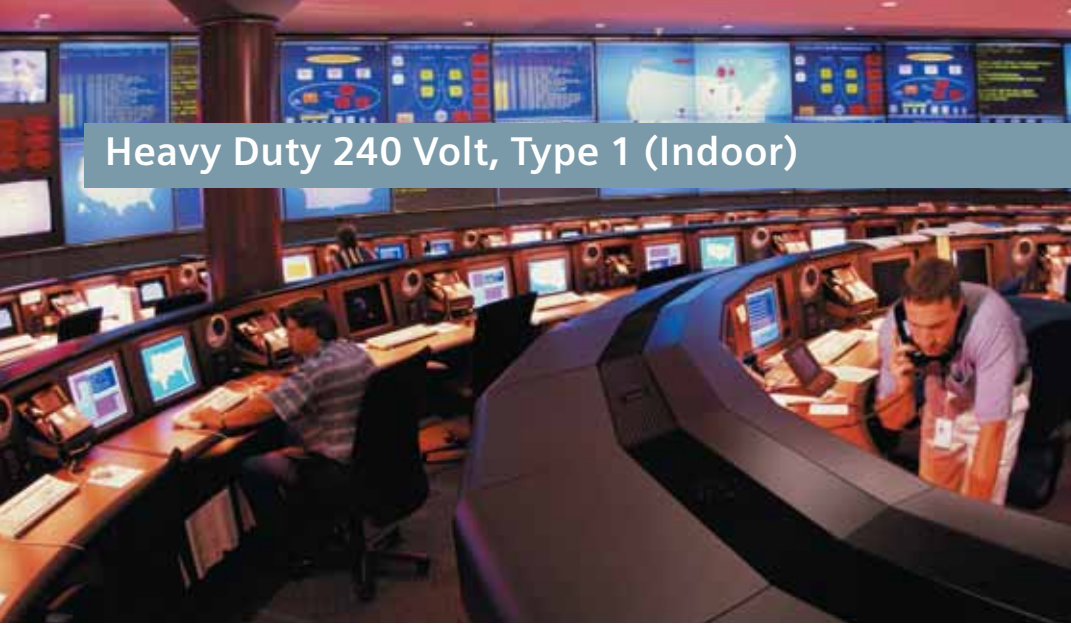


System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 240-V, Fusible							
	30	Use 2-Pole 3-Wire Switch	Use 2-Pole 3-Wire Switch	Use 2-Pole 3-Wire Switch	Use 2-Pole 3-Wire Switch	Use 2-Pole 3-Wire Switch	DH221FGK Use 2-Pole 3-Wire Switch DH225FGK DH226FGK DH227FGK —
	60						
	100						
	200						
	400						
	600						
	800						
1200							
2-Pole, 3-Wire, 240V, Fusible							
	30	HF221N	SN321	HHN321N	TH3221	H221N	DH221NGK
	60	HF222N	SN322	HHN322N	TH3222	H222N	DH222NGK
	100	HF223N	SN323	HHN323N	TH3223	H223N	DH223NGK
	200	HF224N	SN324	HHN324N	TH3224	H224N	DH224NGK
	400	HF225N	SN325	HHN325N	TH3225	H225N	DH225NGK
	600	HF226N	SN326	HHN326N	TH3226	H226N	DH226NGK
	800	HF227N	SN327L	HLN327N	1	H227N	DH227NGK
1200	HF228N	SN328L	HLN328N	1	H228N	—	
3-Pole, 3-Wire, 240V, Fusible							
	30	Use 3-Pole 4-Wire Switch	Use 3-Pole 4-Wire Switch	Use 3-Pole 4-Wire Switch	Use 3-Pole 4-Wire Switch	Use 3-Pole 4-Wire Switch	DH321FGK DH322FGK DH323FGK DH324FGK DH325FGK DH326FGK DH327FGK DH328FGK
	60						
	100						
	200						
	400						
	600						
	800						
1200							
3-Pole, 4-Wire, 240V, Fusible							
	30	HF321N	SN421	HHN421N	TH4321	H321N	DH321NGK
	60	HF322N	SN422	HHN422N	TH4322	H322N	DH322NGK
	100	HF323N	SN423	HHN423N	TH4323	H323N	DH323NGK
	200	HF324N	SN424	HHN424N	TH4324	H324N	DH324NGK
	400	HF325N	SN425	HHN425N	TH4325	H325N	DH325NGK
	600	HF326N	SN426	HHN426N	TH4326	H326N	DH326NGK
	800	HF327N	SN427L	HLN427N	2	H327N	DH327NGK
1200	HF328N	SN428L	HLN428N	2	H328N	DH328NGK	

1 Use 2-Pole, 2-Wire Switch. Order separate neutral.

2 Use 3-Pole, 3-Wire Switch. Order separate neutral.

Heavy Duty 240 Volt, Type 3R (Outdoor)

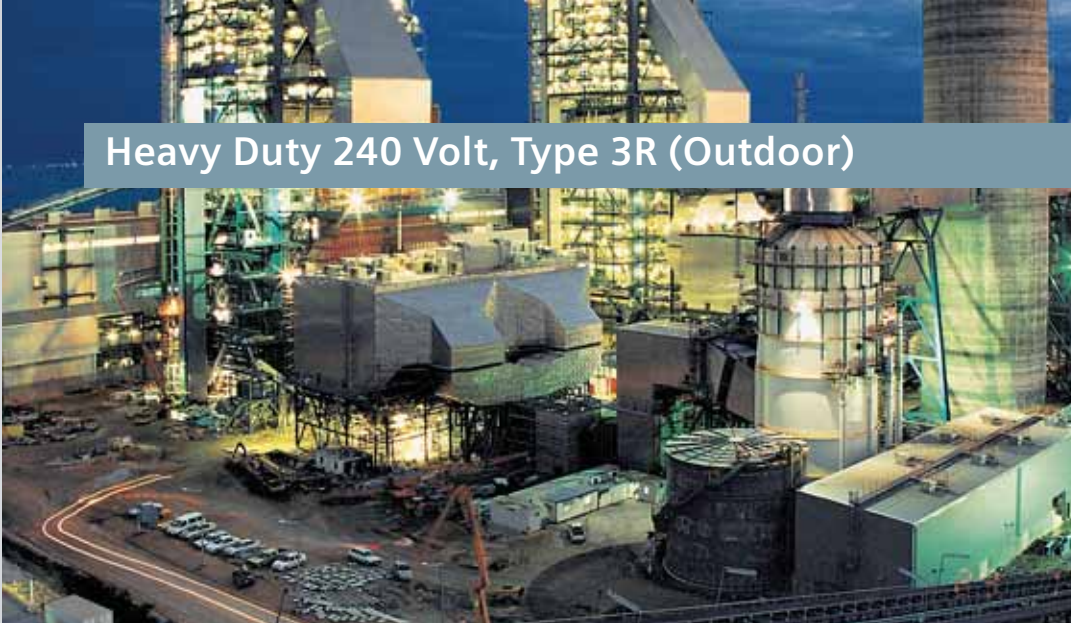

System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 240V, Fusible							
	30	Use 2-Pole 3-Wire Switch	Use 2-Pole 3-Wire Switch	Use 2-Pole 3-Wire Switch	Use 3-Pole Switch	Use 2-Pole Switch	Use 2-Pole
	60						
	100						
	200						
	400						
	600						
800	TC72267R	1					
1200	TC72268R	2					
2-Pole, 3-Wire, 240V, Fusible							
	30	HF221NR	NRH321	HHN321NW	TH3221R	H221NRB	DH221NRK
	60	HF222NR	NRH322	HHN322NW	TH3222R	H222NRB	DH222NRK
	100	HF223NR	NRH323	HHN323NW	TH3223R	H223NRB	DH223NRK
	200	HF224NR	NRH324	HHN324NW	TH3224R	H224NRB	DH224NRK
	400	HF225NR	NRH325	HHN325NW	TH3225R	H225NR	DH225NRK
	600	HF226NR	NRH326	HHN326NW	TH3226R	H226NR	DH226NRK
800	HF227NR	NRH327L	3	4	H227NR	DH227NRK	
1200	HF228NR	NRH328L	3	4	H228NR	2	
3-Pole, 3-Wire, 240V, Fusible							
	30	Use 3-Pole 4-Wire Switch	Use 3-Pole 4-Wire Switch	Use 3-Pole 4-Wire Switch	Use 3-Pole Switch	Use 3-Pole Switch	DH321FRK
	60						
	100						
	200						
	400						
	600						
800	TC72367R	H327R	DH327FRK				
1200	TC72368R	H328R	DH328FRK				
3-Pole, 4-Wire, 240V, Fusible							
	30	HF321NR	NRH421	HHN421NW	TH4321R	H321NRB	DH321NRK
	60	HF322NR	NRH422	HHN422NW	TH4322R	H322NRB	DH322NRK
	100	HF323NR	NRH423	HHN423NW	TH4323R	H323NRB	DH323NRK
	200	HF324NR	NRH424	HHN424NW	TH4324R	H324NRB	DH324NRK
	400	HF325NR	NRH425	HHN425NW	5	H325NR	DH325NRK
	600	HF326NR	NRH426	HHN426NW	5	H326NR	DH326NRK
800	HF327NR	NRH427L	3	5	H327NR	DH327NRK	
1200	HF328NR	NRH428L	3	5	H328NR	DH328NRK	

1 Use 2-Pole, 3-Wire Switch.
 2 Use Two Poles of the 3-Pole, 3-Wire Switch.
 3 Use 600V Heavy Duty Switch.
 4 Use 2-Pole, 2-Wire switch. Order separate neutral.
 5 Use 3-Pole, 3-Wire switch. Order separate neutral.

Heavy Duty 240 Volt, Type 4X (Stainless Steel)



System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 240V, Fusible							
	30	HF221S		1	TH2221SS	H221DS	
	60	HF222S	Use	1	TH2222SS	H222DS	Use
	100	HF223S	Two Poles	1	Use	H223DS	2-Pole
	200	HF224S	of the	1	2-Pole	H224DS	3-Wire
	400	1	3-Pole	—	3-Wire	H225DS	Switch
	600	1	3-Wire	—	Switch	H226DS	—
800	1	Switch	—	—	—	—	—
2-Pole, 3-Wire, 240V, Fusible							
	30	2	Use	3	TH3221SS		DH221NWK
	60	2	Two Poles	3	TH3222SS	Use 2-Pole	DH222NWK
	100	2	of 3-Pole	3	TH3223SS	2-Wire	DH223NWK
	200	2	3-Wire	3	TH3224SS	Switch	DH224NWK
	400	3	Switch	—	TH3225SS	Order sep.	D225NWK
	600	3	Order sep.	—	TH3226SS	Neutral	DH226NWK
800	3	Neutral	—	—	—	DH227NWK	
3-Pole, 3-Wire, 240V, Fusible							
	30	HF321S	F321SS	HHN321AS	TH3321SS	H321DS	DH321FWK
	60	HF322S	F322SS	HHN322AS	TH3322SS	H322DS	DH322FWK
	100	HF323S	F323SS	HHN323AS	Use	H323DS	Use 3-Pole
	200	HF324S	F324SS	HHN324AS	3-Pole	H324DS	4-Wire Sw.
	400	HF325S	F325SS	—	4-Wire	H325DS	DH325FWK
	600	HF326S	F326SS	—	Switch	H326DS	DH326FWK
800	HF327S	F327SSL	—	—	—	DH327FWK	
3-Pole, 4-Wire, 240V, Fusible							
	30	Use	Use	4	TH4321SS	4	DH321NWK
	60	3-Pole	3-Pole	4	TH4322SS	4	DH322NWK
	100	3-Wire	3-Wire	4	TH4323SS	4	DH323NWK
	200	Switch	Switch	4	TH4324SS	4	DH324NWK
	400	Order sep.	Order sep.	—	TH4325SS	H325NDS	DH325NWK
	600	Neutral	Neutral	—	TH4326SS	H326NDS	DH326NWK

1 Use Two Poles of the 3-Pole, 3-Wire Switch.
 2 Use 2-Pole Switch. Order separate neutral.
 3 Use Two Poles of the 3-Pole, 3-Wire Switch. Order separate neutral.
 4 Use 3-Pole, 3-Wire Switch. Order separate neutral.

Heavy Duty 240 Volt, Type 12 (Industrial)



System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 240V, Fusible							
	30	HF221J			TH2221J	H221AWK	Use
	60	HF222J	Use	Use	TH2222J	H222AWK	2-Pole
	100	HF223J	Two Poles of the	Heavy Duty	Use	H223AWK	3-Wire
	200	HF224J	3-Pole	600V	2-Pole	H224AWK	Switch
	400	1	3-Wire	Switch	3-Wire	H225AWK	DH225FDK
	600	1	Switch	—	Switch	H226AWK	DH226FDK
800	1	—	—	—	—	H227AWK	DH227FDK
1200	—	—	—	—	—	H228AWK	—
2-Pole, 3-Wire, 240V, Fusible							
	30	2	Use		TH3221J	Use 2-Pole	DH221NDK
	60	2	Two Poles of 3-Pole	Use	TH3222J	2-Wire	DH222NDK
	100	2	Switch	Heavy Duty	TH3223J	Order Sep. Neutral	DH223NDK
	200	2	3-Wire	600V	TH3224J		DH224NDK
	400	3	Order sep. Neutral	Switch	TH3225J	H225NAWK	DH225NDK
	600	3	—	—	TH3226J	H226NAWK	DH226NDK
800	3	—	—	—	—	H227NAWK	DH227NDK
1200	5	—	—	—	—	H228NAWK	—
3-Pole, 3-Wire, 240V, Fusible							
	30	HF321J	F321H		TH3321J	H321AWK	DH321FDK
	60	HF322J	F322H	Use	TH3322J	H322AWK	DH322FDK
	100	HF323J	F323H	Heavy Duty	Use	H323AWK	DH323FDK
	200	HF324J	F324H	600V	3-Pole	H324AWK	DH324FDK
	400	HF325J	F325H	Switch	4-Wire	H325AWK	DH325FDK
	600	HF326J	F326H	—	Switch	H326AWK	DH326FDK
800	HF327J	F327HL	—	—	—	H327AWK	DH327FDK
1200	5	—	—	—	—	H328AWK	—
3-Pole, 4-Wire, 240V, Fusible							
	30		Use	Use	TH4321J	4	DH321NDK
	60	Use	3-Pole	Use	TH4322J	4	DH322NDK
	100	3-Pole	3-Wire	Heavy Duty	TH4323J	4	DH323NDK
	200	3-Wire	Switch	600V	TH4324J	4	DH324NDK
	400	Order sep. Neutral	Order sep. Neutral	Switch	TH4325J	H325NAWK	DH325NDK
	600	—	—	—	TH4326J	H326NAWK	DH326NDK
800	—	—	—	—	H327NAWK	4	
1200	5	—	—	—	H328NAWK	4	

1 Use Two Poles of the 3-Pole, 3-Wire Switch.
 2 Use 2-Pole Switch. Order separate neutral.
 3 Use Two Poles of the 3-Pole, 3-Wire Switch. Order separate neutral.
 4 Use 3-Pole, 3-Wire Switch. Order separate neutral.
 5 Use 600V Switch.

Heavy Duty 600 Volt, Type 1 (Indoor)



System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 600V, Fusible							
	30	HF261	Use	Use	TH2261DC	1	DH261FGK
	60	HF262			TH2262DC	1	DH262FGK
	100	HF263			TH2263DC	1	DH263FGK
	200	1	of the	of the	1	1	DH264FGK
	400	HF265	3-Pole	3-Pole	1	H265	DH265FGK
	600	HF266	3-Wire	3-Wire	1	H266	DH266FGK
	800	1	Switch	Switch	1	H267	DH267FGK
1200	1			1	H268	1	
3-Pole, 3-Wire, 600V, Fusible							
	30	HF361	F351	HHN361	TH3361	H361	DH361FGK
	60	HF362	F352	HHN362	TH3362	H362	DH362FGK
	100	HF363	F353	HHN363	TH3363	H363	DH363FGK
	200	HF364	F354	HHN364	TH3364	H364	DH364FGK
	400	HF365	F355	HHN365	TH3365	H365	DH365FGK
	600	HF366	F356	HHN366	TH3366	H366	DH366FGK
	800	HF367	F357L	HLN367	TC72367	H367	DH367FGK
1200	HF368	F358L	HLN368	TC72368	H368	DH368FGK	
3-Pole, 4-Wire, 600V, Fusible							
	30	HF361N	SN451	Use	Use	H361N	DH361NGK
	60	HF362N	SN452			Use	H362N
	100	HF363N	SN453	3-Pole	3-Pole	H363N	DH363NGK
	200	HF364N	SN454	3-Wire	3-Wire	H364N	DH364NGK
	400	HF365N	SN455	Switch	Switch	H365N	DH365NGK
	600	HF366N	SN456	Order sep.	Order sep.	H366N	DH366NGK
	800	HF367N	2	Neutral	Neutral	H367N	DH367NGK
1200	2	2			H368N	DH368NGK	
2-Pole, 2-Wire, 600V, Non-Fusible							
	30	HNF261	Use	Use	THN2261DC	1	DH261UGK
	60	HNF262			THN2262DC	1	1
	100	HNF263			THN2263DC	1	DH263UGK
	200	1	of the	3-Pole	1	1	1
	400	HNF265	3-Pole	3-Wire	1	HU265	DH265UGK
	600	HNF266	3-Wire	Switch	1	HU266	DH266UGK
	800	1	Switch	—	1	HU267	DH267UGK
1200	1		—	1	HU268	1	
3-Pole, 2-Wire, 600V, Non-Fusible							
	30	HNF361	NF351	HUN361	THN3361	HU361	DH361UGK
	60	HNF362	NF352	HUN362	THN3362	HU362	DH362UGK
	100	HNF363	NF353	HUN363	THN3363	HU363	DH363UGK
	200	HNF364	NF354	HUN364	THN3364	HU364	DH364UGK
	400	HNF365	NF355	HUN365	THN3365	HU365	DH365UGK
	600	HNF366	NF356	HUN366	THN3366	HU366	DH366UGK
	800	HNF367	NF357	—	TC36367	HU367	DH367UGK
1200	HNF368	NF358	—	TC36368	HU368	DH368UGK	

1 Use Two Poles of the 3-Pole, 3-Wire Switch.
2 Use 3-Pole, 3-Wire Switch. Order separate neutral.

Heavy Duty 600 Volt, Type 3R (Outdoor)




System	Ampere Rating	VBI	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 600V, Fusible							
	30	HF261R	Use Two Poles of the 3-Pole 3-Wire Switch	Use Two Poles of the 3-Pole 3-Wire Switch —	TH2261RDC	1	Use Two Poles of the 3-Pole 3-Wire Switch
	60	HF262R			TH2262RDC	1	
	100	HF263R			TH2263RDC	1	
	200	1			Use	1	
	400	HF265R			Two Poles of 3-Pole	H265R	
	600	HF266R			H266R		
800	1	H267R					
1200	1	H268R					
3-Pole, 3-Wire, 600V, Fusible							
	30	HF361R	FR351	HHN361AW	TH3361R	H361RB	DH361FRK
	60	HF362R	FR352	HHN362AW	TH3362R	H362RB	DH362FRK
	100	HF363R	FR353	HHN363AW	TH3363R	H363RB	DH363FRK
	200	HF364R	FR354	HHN364AW	TH3364R	H364RB	DH364FRK
	400	HF365R	FR355	HHN365AW	TH3365R	H365R	DH365FRK
	600	HF366R	FR356	HHN366AW	TH3366R	H366R	DH366FRK
800	HF367R	FR357L	HLN367AW	TC72367R	H367R	DH367FRK	
1200	HF368R	FR358L	—	TC72368R	H368R	DH368FRK	
3-Pole, 4-Wire, 600V, Fusible							
	30	HF361NR	NRH451	HHN461NW	Use 3-Pole 3-Wire Switch Order sep. Neutral —	H361NRB	DH361NRK
	60	HF362NR	NRH452	HHN462NW		H362NRB	DH362NRK
	100	HF363NR	NRH453	2		H363NRB	DH363NRK
	200	HF364NR	NRH454	2		H364NRB	DH364NRK
	400	HF365NR	NRH455	2		H365NR	DH365NRK
	600	HF366NR	NRH456	2		H366NR	DH366NRK
800	HF367NR	2	2	H367NR	DH367NRK		
1200	2	2	—	H368NR	DH368NRK		
2-Pole, 2-Wire, 600V, Non-Fusible							
	30	HNF261R	Use Two Poles of the 3-Pole 3-Wire Switch	Use Two Poles of the 3-Pole 3-Wire Switch — —	THN2261RDC	1	Use Two Poles of the 3-Pole 3-Wire Switch
	60	HNF262R			THN2262RDC	1	
	100	HNF263R			THN2263RDC	1	
	200	1			1	1	
	400	HNF265R			1	HU265R	
	600	HNF266R			1	HU266R	
800	1	—	HU267R				
1200	1	—	HU268R				
3-Pole, 3-Wire, 600V, Non-Fusible							
	30	HNF361R	NFR351	HUN361AW	THN3361R	HU361RB	DH361URK
	60	HNF362R	NFR352	HUN362AW	THN3362R	HU362RB	DH362URK
	100	HNF363R	NFR353	HUN363AW	THN3363R	HU363RB	DH363URK
	200	HNF364R	NFR354	HUN364AW	THN3364R	HU364RB	DH364URK
	400	HNF365R	NFR355	HUN365AW	THN3365R	HU365R	DH365URK
	600	HNF366R	NFR356	HUN366AW	THN3366R	HU366R	DH366URK
800	HNF367R	NFR357	—	—	HU367R	DH367URK	
1200	HNF368R	NFR358	—	—	HU368R	DH368URK	

1 Use Two Poles of the 3-Pole, 3-Wire Switch.

2 Use 3-Pole, 3-Wire Switch. Order separate neutral.

Heavy Duty 600 Volt, Type 4X (Stainless Steel)

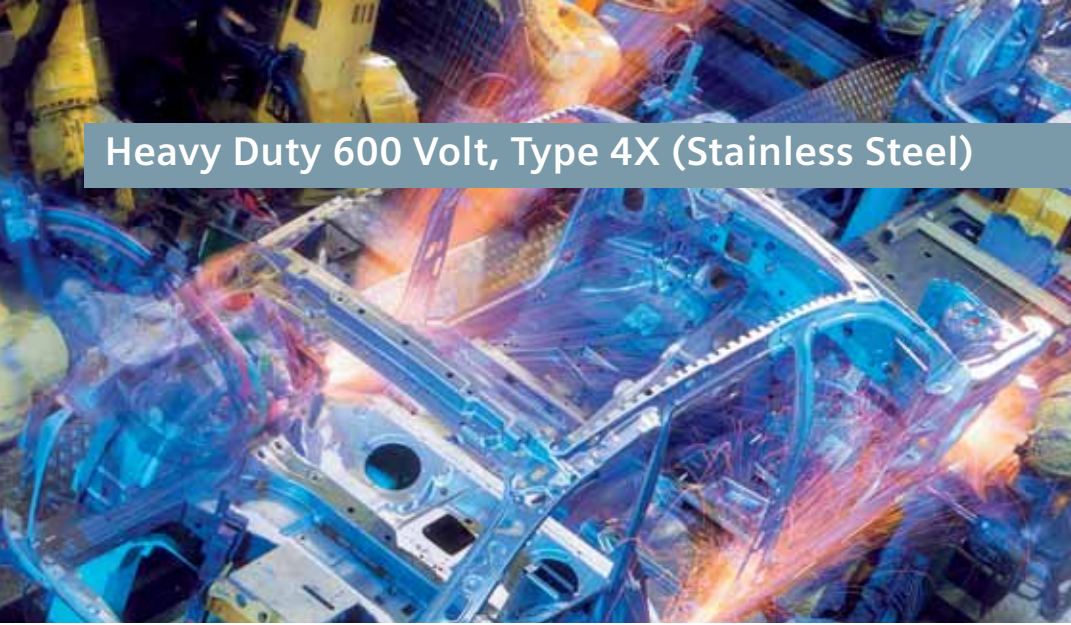


System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 600V, Fusible							
	30	HF261S		Use	TH2261SSDC	1	DH261FWK
	60	HF262S	Use	Two Poles	TH2262SSDC	1	1
	100	HF263S	Two Poles	of 3-Pole	TH2263SSDC	1	1
	200	1	of the	3-Wire	1	1	DH264FWK
	400	HF265S	3-Pole	Switch	1	H265DS	1
	600	HF266S	3-Wire	—	1	1	1
800	1	Switch	—	—	1	1	
3-Pole, 3-Wire, 600V, Fusible							
	30	HF361S	F351SS	HHN361AS	TH3361SS	H361DS	DH361FWK
	60	HF362S	F352SS	HHN362AS	TH3362SS	H362DS	DH362FWK
	100	HF363S	F353SS	HHN363AS	TH3363SS	H363DS	DH363FWK
	200	HF364S	F354SS	HHN364AS	TH3364SS	H364DS	DH364FWK
	400	HF365S	F355SS	HHN365AS	TH3365SS	H365DS	DH365FWK
	600	HF366S	F356SS	—	TH3366SS	H366DS	DH366FWK
	800	HF367S	F357SSL	—	—	—	DH367FWK
1200	HF368S	—	—	—	—	DH368FWK	
3-Pole, 4-Wire, 600V, Fusible							
	30			2		2	DH361NWK
	60	Use	Use	2	Use	2	DH362NWK
	100	3-Pole	3-Pole	2	3-Pole	2	DH363NWK
	200	3-Wire	3-Wire	2	3-Wire	H364NDS	DH364NWK
	400	Switch	Switch	2	Switch	H365NDS	DH365NWK
	600	Order sep.	Order sep.	—	Order sep.	H366NDS	DH366NWK
800	Neutral	Neutral	—	Neutral	—	2	
2-Pole, 2-Wire, 600V, Non-Fusible							
	30	HNF261S	Use	Use	THN2261SSDC	1	Use
	60	HNF262S	Two Poles	Two Poles	THN2262SSDC	1	Two Poles
	100	HNF263S	of the	of 3-Pole	THN2263SSDC	1	of the
	200	1	3-Pole	3-Wire	1	1	3-Pole
	400	HNF265S	3-Wire	Switch	1	HU265DS	3-Wire
600	HNF266S	Switch	—	1	HU266DS	Switch	
3-Pole, 3-Wire, 600V, Non-Fusible							
	30	HNF361S	NF351SS	HUN361AS	THN3361SS	HU361DS	DH361UWK
	60	HNF362S	NF352SS	HUN362AS	THN3362SS	HU362DS	DH362UWK
	100	HNF363S	NF353SS	HUN363AS	THN3363SS	HU363DS	DH363UWK
	200	HNF364S	NF354SS	HUN364AS	THN3364SS	HU364DS	DH364UWK
	400	HNF365S	NF355SS	HUN365AS	THN3365SS	HU365DS	DH365UWK
	600	HNF366S	NF356SS	—	THN3366SS	HU366DS	DH366UWK
	800	HNF367S	—	—	—	—	DH367UWK
	1200	HNF368S	—	—	—	—	DH368UWK

¹ Use Two Poles of the 3-Pole, 3-Wire Switch.

² Use 3-Pole, 3-Wire Switch. Order separate neutral.

Heavy Duty – 600 Volt, Type 12 (Industrial)

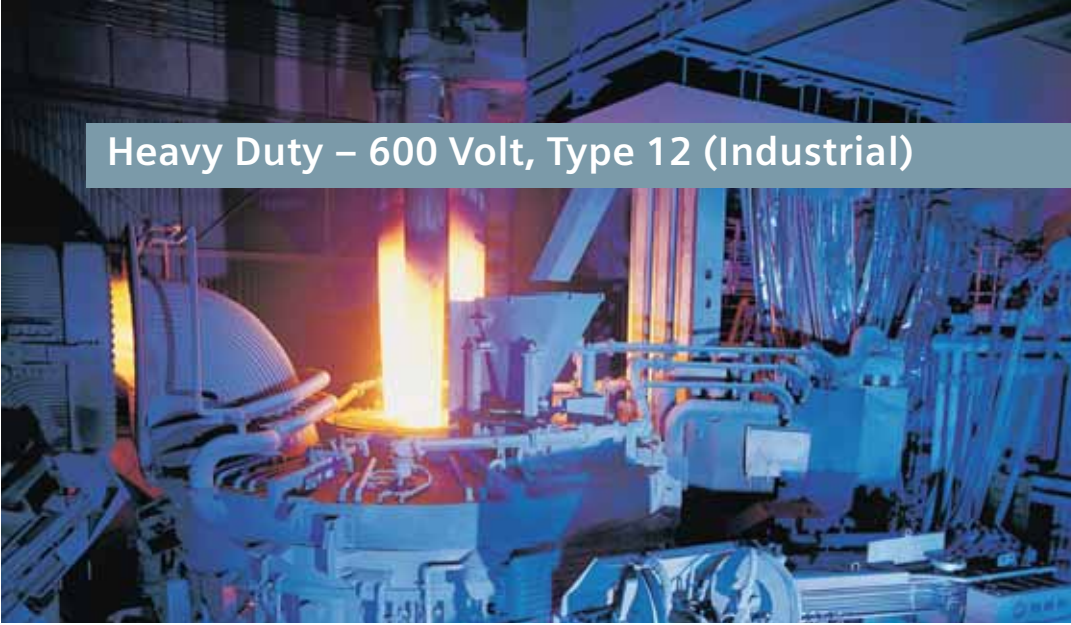

System	Ampere Rating	VBII	Vacu-Break [®]	Murray	General Electric	Square D	Cutler-Hammer
2-Pole, 2-Wire, 600V, Fusible							
	30	HF261J	Use	Use	TH2261JDC	1	DH261FDK
	60	HF262J	Two	Two Poles	TH2262JDC	1	DH262FDK
	100	HF263J	Poles	of 3-Pole	TH2263JDC	1	DH263FDK
	200	1	of the	3-Wire	1	1	DH264FDK
	400	HF265J	3-Pole	Switch	1	H265AWK	DH265FDK
	600	HF266J	3-Wire	—	1	H266AWK	DH266FDK
	800	1	Switch	—	—	H267AWK	DH267FDK
1200	—	—	—	—	—	H268AWK	—
3-Pole, 3-Wire, 600V, Fusible							
	30	HF361J	F351H	HN361AJ	TH3361J	H361AWK	DH361FDK
	60	HF362J	F352H	HN362AJ	TH3362J	H362AWK	DH362FDK
	100	HF363J	F353H	HHN363AJ	TH3363J	H363AWK	DH363FDK
	200	HF364J	F354H	HN364AJ	TH3364J	H364AWK	DH364FDK
	400	HF365J	F355H	HHN365AJ	TH3365J	H365AWK	DH365FDK
	600	HF366J	F356H	—	TH3366J	H366AWK	DH366FDK
	800	HF367J	F357HL	—	—	H367AWK	DH367FDK
1200	HF368J	—	—	—	—	H368AWK	DH368FDK
3-Pole, 4-Wire, 600V, Fusible							
	30	Use	Use	Use 3-Pole	Use	2	DH361NDK
	60	3-Pole	3-Pole	3-Wire	3-Pole	2	DH362NDK
	100	3-Wire	3-Wire	Switch	3-Wire	2	DH363NDK
	200	Switch	Switch	Order sep.	Switch	H364NAWK	DH364NDK
	400	Order sep.	Order sep.	Neutral	Order sep.	H365NAWK	DH365NDK
	600	Neutral	Neutral	—	Neutral	H366NAWK	DH366NDK
	800	—	—	—	—	H367NAWK	2
1200	—	—	—	—	H368NAWK	—	
2-Pole, 2-Wire, 600V, Non-Fusible							
	30	HNF261J	Use	Use	THN2261JDC	1	DH261UDK
	60	HNF262J	Use	Two Poles	THN2262JDC	1	DH262UDK
	100	HNF263J	Two Poles	of the	THN2263JDC	1	DH263UDK
	200	1	of the	3-Pole	1	1	DH264UDK
	400	HNF265J	3-Pole	3-Wire	1	HU265AWK	DH265UDK
	600	HNF266J	3-Wire	Switch	1	HU266AWK	DH266UDK
	800	1	Switch	—	—	HU267AWK	DH267UDK
1200	—	—	—	—	—	HU268AWK	—
3-Pole, 3-Wire, 600V, Non-Fusible							
	30	HNF361J	NF351H	HUN361AJ	THN3361J	HU361AWK	DH361UDK
	60	HNF362J	NF352H	HUN362AJ	THN3362J	HU362AWK	DH362UDK
	100	HNF363J	NF353H	HUN363AJ	THN3363J	HU363AWK	DH363UDK
	200	HNF364J	NF354H	HUN364AJ	THN3364J	HU364AWK	DH364UDK
	400	HNF365J	NF355H	HUN365AJ	THN3365J	HU365AWK	DH365UDK
	600	HNF366J	NF356H	HUN366AJ	THN3366J	HU366AWK	DH366UDK
	800	HNF367J	NF357H	—	—	HU367AWK	DH367UDK
	1200	HNF368J	—	—	—	—	HU368AWK

¹ Use Two Poles of the 3-Pole, 3-Wire Switch.

² Use 3-Pole, 3-Wire Switch. Order separate neutral.

Siemens Energy & Automation, Inc.
3333 Old Milton Parkway
Alpharetta, GA 30005

1-800-964-4114
info.sea@siemens.com

www.sea.siemens.com

Order No.: SSXR-00100-0109
XMXX0109 Printed in USA

© 2008 Siemens Energy & Automation, Inc. All rights reserved. Siemens is a registered trademark of Siemens AG. Product names mentioned may be trademarks or registered trademarks of their respective companies. Specifications are subject to change without notice.