

# Outdoor Elbows for Outside and Inside Corners

Power Mod™

## Outdoor Elbows for Outside and Inside Corners

This elbow for Power Mod is rated for outdoor use (N3R), but can be used indoors as well.

### Features include:

- QuickSystem features
- Available in single and three phase designs


### Reference Data:

- 1200A thru bus rating
- UL Standard #UL67
- UL file #E27100
- AIC rating 100KAIC
- Single Phase
- Three Phase
- All swing latches and rivets are stainless steel
- Outdoor = NEMA 3R rated
- G90 Galvanized Steel
- ANSI 61 Paint





# Power Mod: Type WELB NEMA 3R Elbows

Inside Corner

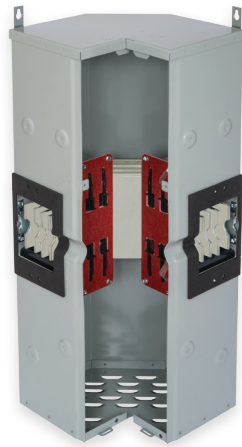

Outside Corner

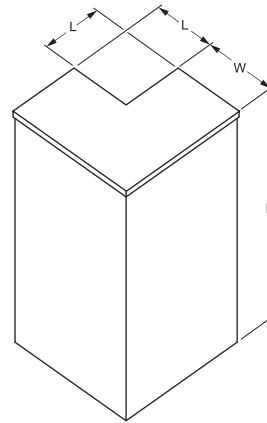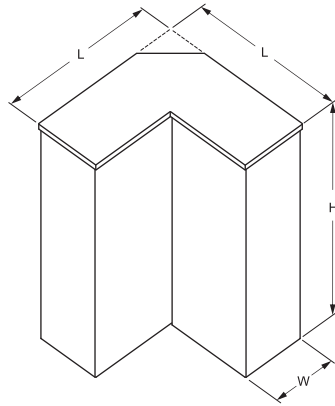

Catalog Number	Phase	Maximum AIC	Outside/Inside Corner Type	Dimensions (inches)		
				Height (H)	Length (L)	Width (W)
WELB118	1	100k	Inside	30	18.3	8
WELB318	3	100k	Inside	30	18.3	8
WELB112	1	100k	Inside	30	12.3	8
WELB312	3	100k	Inside	30	12.3	8
WELB107E	1	100k	Outside	30	6.8	8
WELB307E	3	100k	Outside	30	6.8	8

Siemens Industry, Inc.  
5400 Triangle Parkway  
Norcross, GA 30092

1-800-241-4453  
info.us@siemens.com

Subject to change without prior notice  
Order No. PDFL-WELB1-1116  
Printed in USA  
All rights reserved  
© 2016, Siemens Industry, Inc.

Subject to changes and errors. The information given in this document only contains general descriptions and/or performance features which may not always specifically reflect those described, or which may undergo modification in the course of further development of the products. The requested performance features are binding only when they are expressly agreed upon in the concluded contract.