

Power Mod™ Outdoor Elbows for Outside and Inside Corners

Outdoor Elbows for Outside and Inside Corners

This elbow for Power Mod is rated for outdoor use (N3R), but can be used indoors as well.

Features include:


- QuickSystem features
- Available in single and three phase designs

Reference Data:

- 1200A thru bus rating
- UL Standard #UL67
- UL file #E27100
- AIC rating 100KAIC
- Single Phase
- Three Phase
- All swing latches and rivets are stainless steel
- Outdoor = NEMA 3R rated
- G90 Galvanized Steel
- ANSI 61 Paint



Power Mod™ Type WELB NEMA 3R Elbows

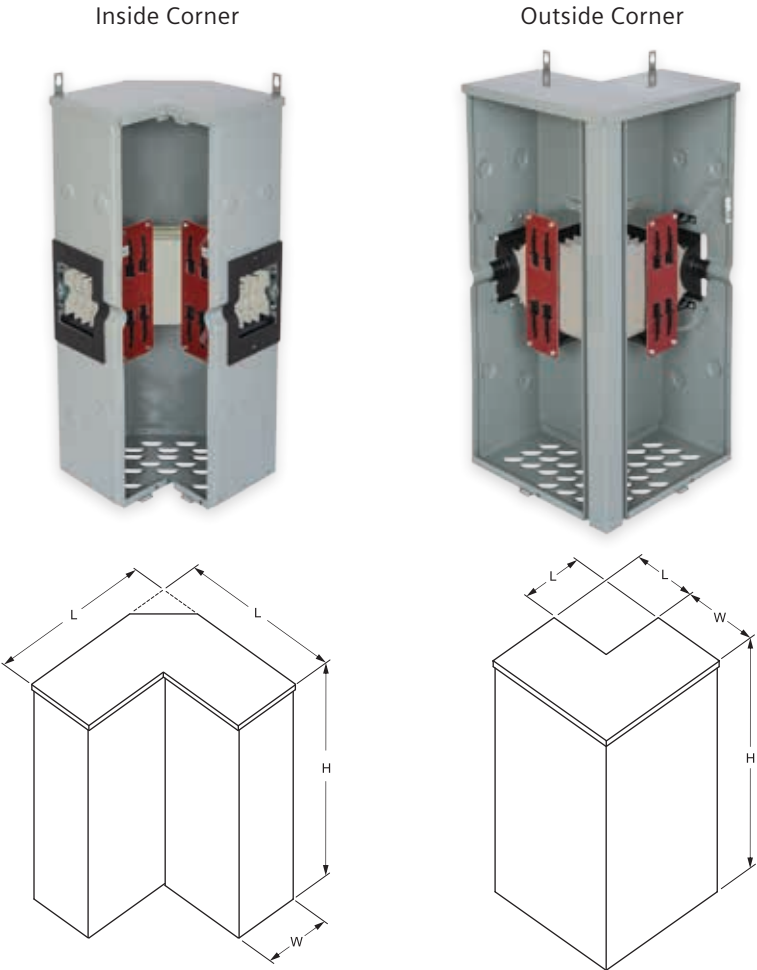

Catalog Number	Phase	Maximum AIC	Outside/Inside Corner Type	Dimensions (inches)		
				Height (H)	Length (L)	Width (W)
WELB118	1	100k	Inside	30	18.3	8
WELB318	3	100k	Inside	30	18.3	8
WELB112	1	100k	Inside	30	12.3	8
WELB312	3	100k	Inside	30	12.3	8
WELB107E	1	100k	Outside	30	6.8	8
WELB307E	3	100k	Outside	30	6.8	8

Published by
Siemens 2018

Siemens Industry, Inc.
5400 Triangle Parkway
Norcross, GA 30092

Printed in USA
All Rights Reserved
© 2018, Siemens Industry, Inc.
usa.siemens.com/powermod

Siemens Technical Support: 1-800-333-7421
info.us@siemens.com
Order No. PDFL-WELB1-0418-CP

The technical data presented in this document is based on an actual case or on as-designed parameters, and therefore should not be relied upon for any specific application and does not constitute a performance guarantee for any projects. Actual results are dependent on variable conditions. Accordingly, Siemens does not make representations, warranties, or assurances as to the accuracy, currency or completeness of the content contained herein. If requested, we will provide specific technical data or specifications with respect to any customer's particular applications. Our company is constantly involved in engineering and development. For that reason, we reserve the right to modify, at any time, the technology and product specifications contained herein.