






REVISION	DATE	BY	DATE	BY
			17/03/15	RM

Confidential - Property of Siemens Industry, Inc.	
CUSTOMER	
ORDER NO.	DWG. NO.
	3F3Y500BCLN3SSN4X SH 1 OF 2

SIEMENS	
CATALOG NO. 3F3Y500BCLN3SSN4X SERIAL NO. SERIES H 500 kVA 60 Hz 3 PHASE 4.2 % IMP AT 100 °C 80 °C RISE 30 °C AVG. AMBIENT 220 °C TEMP CLASS 40 °C MAX. AMBIENT PRIMARY (H1 H2 H3) 480 V SECONDARY(X0 X1 X2 X3) 208Y/120 V WINDING MATERIAL CU ENCLOSURE TYPE 4X WEIGHT 4450 LBS	
	VOLTS CONNECT 504 1-2 492 2-3 480 3-4 468 4-5 456 5-6 444 6-7 432 7-8
SPACINGS BETWEEN ENCLOSURE PANEL AND ANY ADJACENT WALL SHALL BE A MINIMUM OF 12 INCHES SOUND LEVEL IS 3 DB LOWER THAN NEMA ST20 REQUIREMENTS SUITABLE FOR INDOOR OR OUTDOOR LOCATIONS BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION MANUAL NEMA Class ANC Dry Type Transformer Siemens Industry, Inc. Norcross, GA	
TYPE KN DRY TYPE TRANSFORMER   LR 3902 E112313	

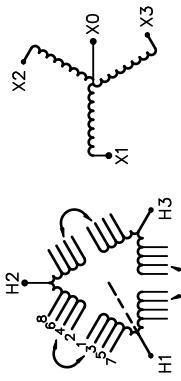

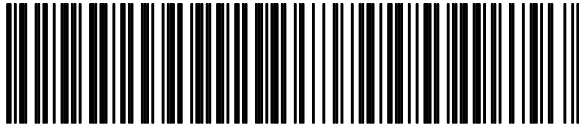
3F3Y500BCLN3SSN4X

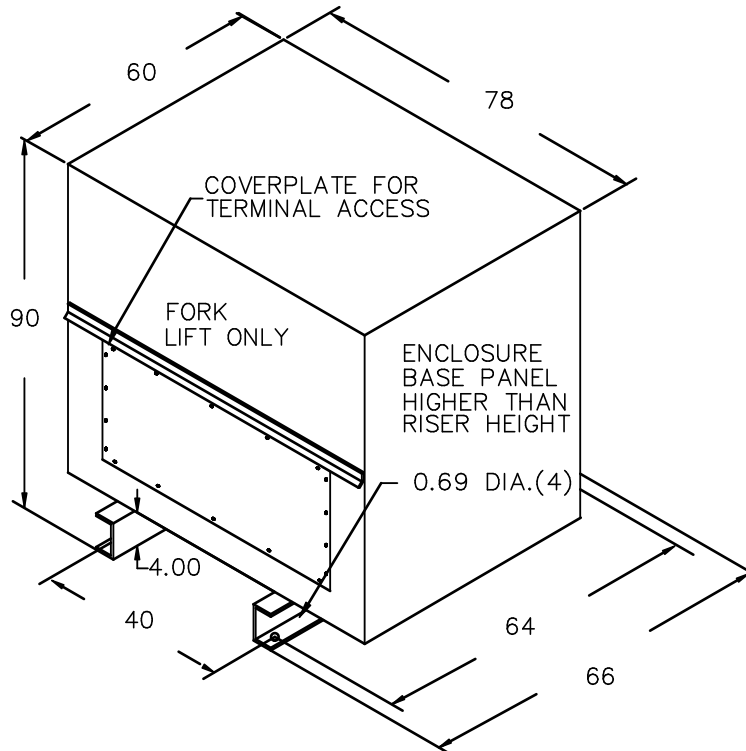


All Dimensions in inches

ENCLOSURE COLOR :304 STAINLESS STEEL #3 POLISH

HV TERMINAL DETAIL

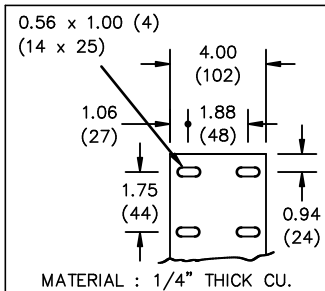

LV TERMINAL DETAIL

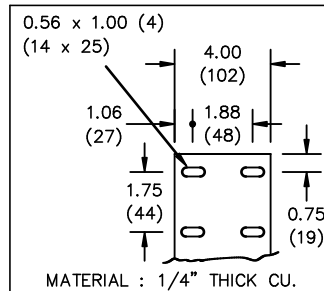

CUSTOMER NOTES:

- HV TERMINATED AT TOP FRONT
- LV TERMINATED AT BOTTOM FRONT

Confidential – Property of
Siemens Industry, Inc.

REVISION	DATE	BY	DATE	BY
			17/03/15	RM

CUSTOMER	
ORDER NO.	DWG. NO.
	3F3Y500BCLN3SSN4X SH 2 OF 2

0.2 mmarch 2017/03/16 13:09