




# Catalog Number: 47604-81GP

## Features and Ratings




- Ringless Type Meter Socket
- 320A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 1 Phase, 3 Wire, Commercial Socket
- 4 Jaw Meter Socket
- Meter Socket Type HQ-4SUT
- For Overhead & Underground Service
- HD Type Hub Opening
- Lever Bypass
- 7/8" Barrel Lock Provision w/Bracket

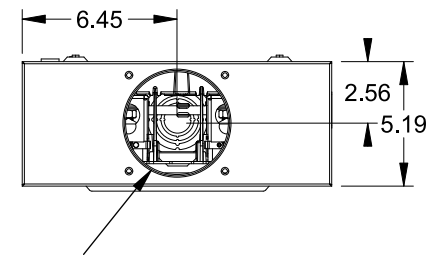

TYPE HD (LARGE) HUB OPENING

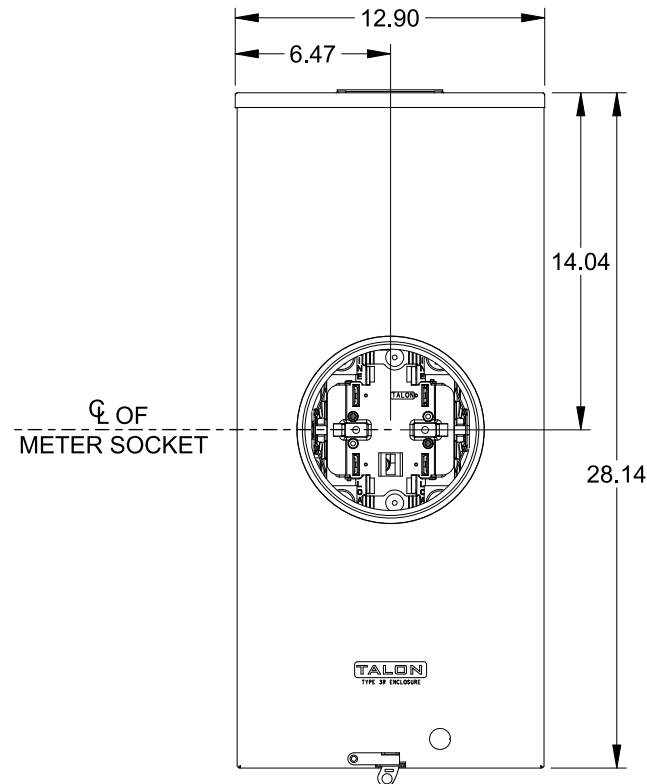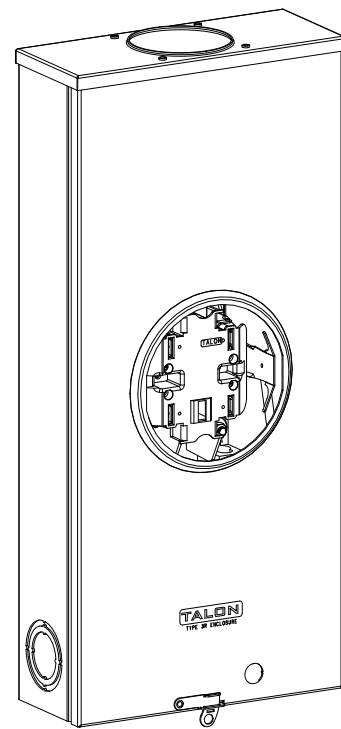

VIEW SHOWN WITH COVER REMOVED

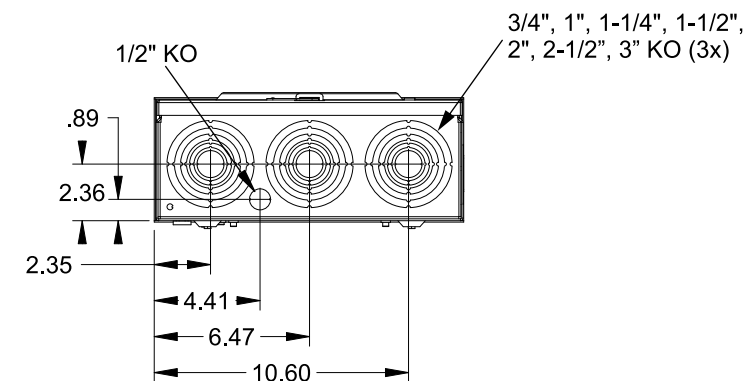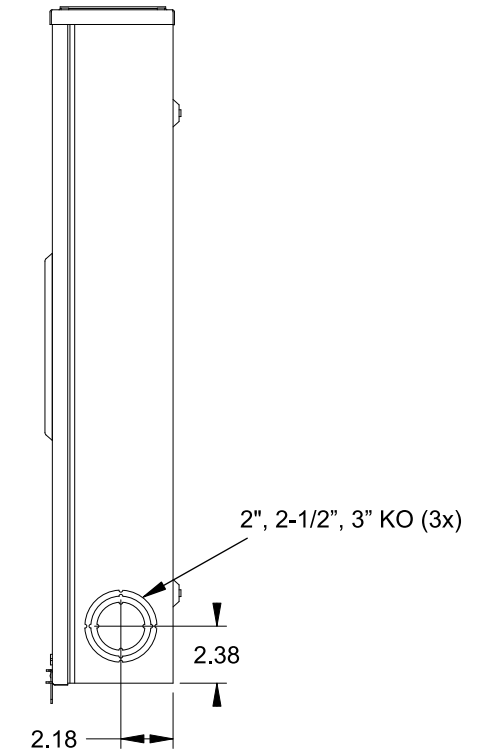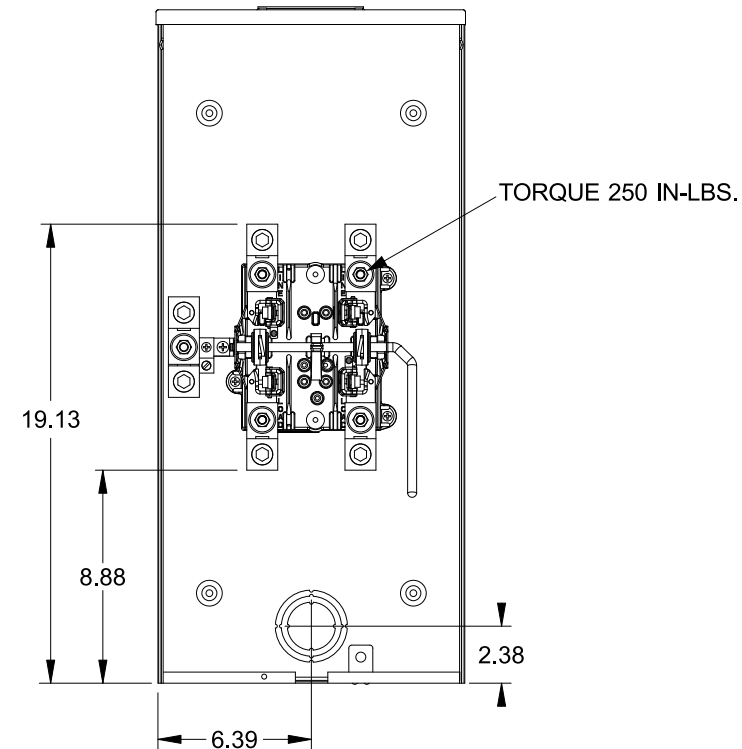

## Accessories

| CONDUIT HUBS (HD Type) |                     |
|------------------------|---------------------|
| TRADE SIZE             | CATALOG No.         |
| 3 INCH                 | EC56856 or H56856-2 |
| 3-1/2 INCH             | EC56857 or H56857-2 |
| 4 INCH                 | EC56858 or H56858-2 |
| Hub Cover Plate        | EC56933 or H56933S  |

### Meter Opening Cover Plate

Cat No: H659-0162

### 5th Jaw Kit

Cat. No: H35815-3

## Connectors, Wire Sizes and Torques

| CONNECTOR         | PART No. | WIRE SIZE                          | HEX DRIVE | TORQUE      |
|-------------------|----------|------------------------------------|-----------|-------------|
| LINE/LOAD/NEUTRAL | 60162    | #4-600 kcmil/<br>(2) 1/0-250 kcmil | 3/8"      | 375 IN-LBS. |
| GROUND            | 67554A   | #14 - 2/0 AWG                      | ..        | 50 IN-LBS.  |

© 2019 Copyright Siemens Industry, Inc.

**TALON**

**Meter Socket**

Description: **320A Cont, 4 Jaw, HQ-4SUT, 600V AC, Painted Steel Enclosure**

KAM 4/15/19 | DO NOT SCALE DRAWING | Dwg No: **47604-81GP**