




# Catalog Number: 47605-01FL

## Features and Ratings




- Ringless Type Meter Socket
- 200A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 1 or 3 Phase, 3-Wire, Commercial Socket
- 5 Jaw Meter Socket
- Meter Socket Type HQ-5SU
- For Overhead & Underground Service
- RX Type Hub Opening
- Lever Bypass

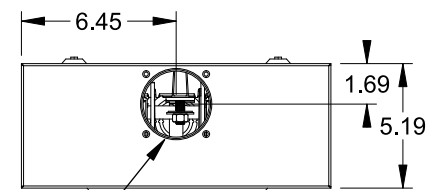

SMALL HUB OPENING

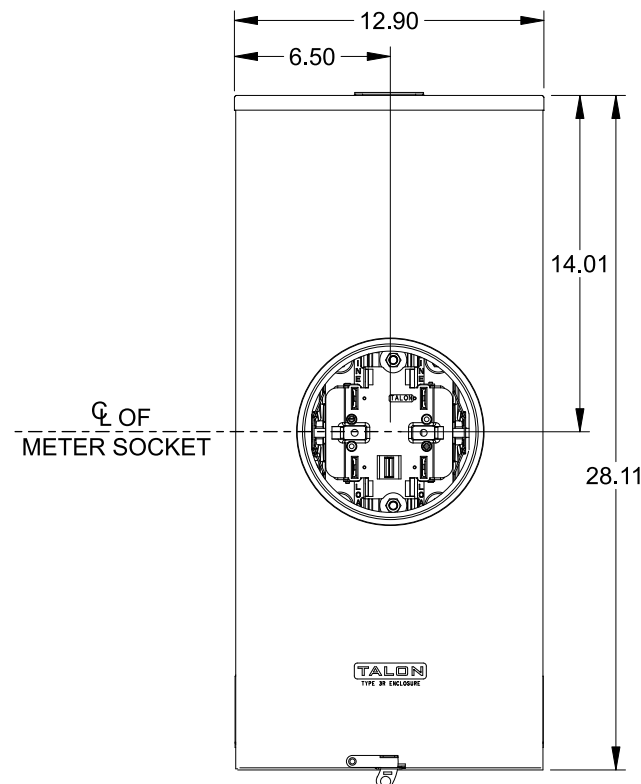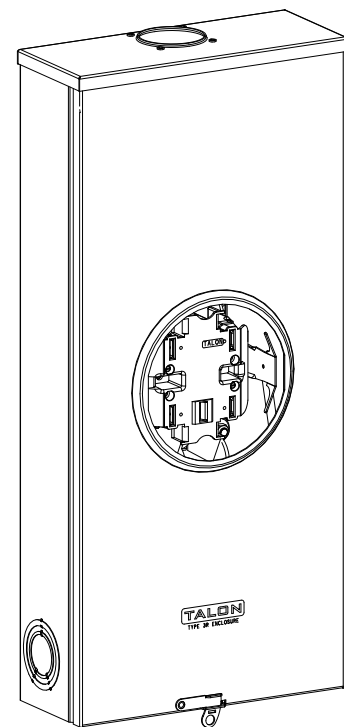

VIEW SHOWN WITH COVER REMOVED

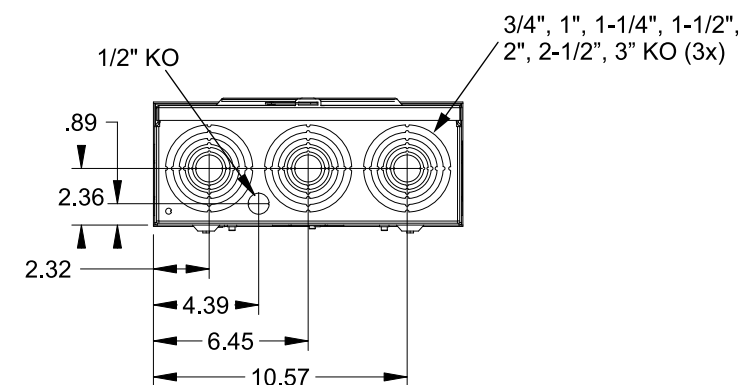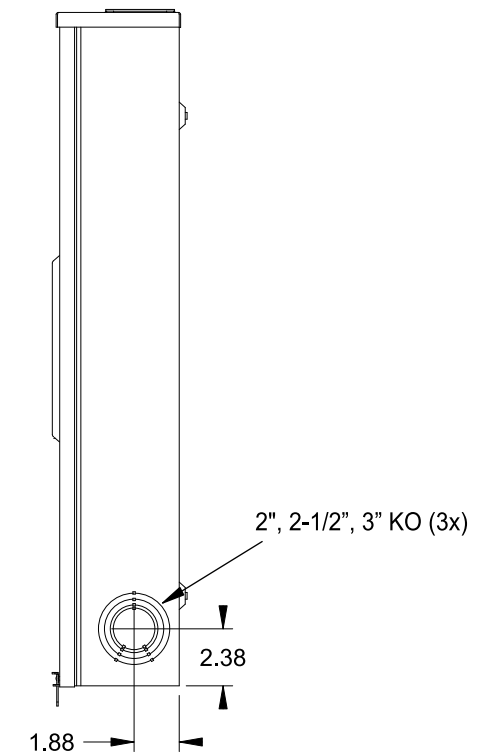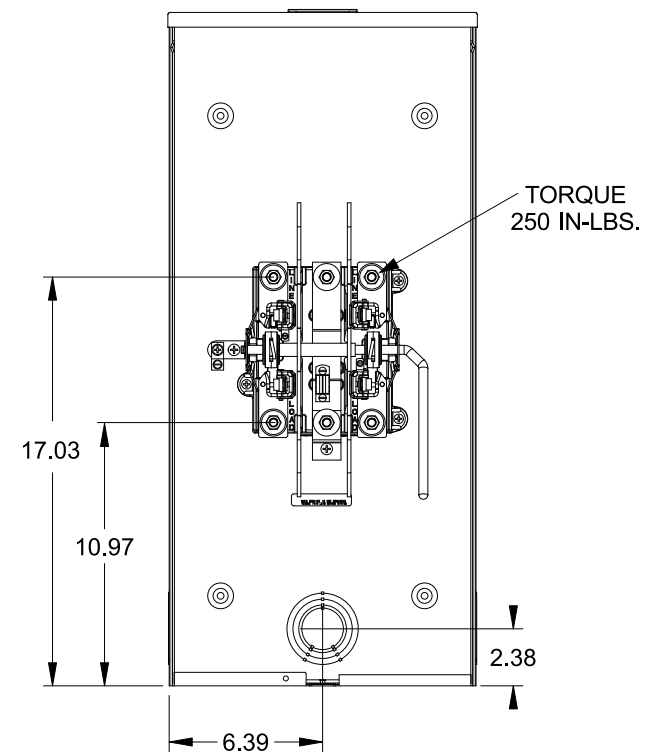

## Accessories

CONDUIT HUBS (RX Type)	
TRADE SIZE	CATALOG No.
1-1/4 INCH	EC38597 or H38597-2
1-1/2 INCH	EC38598 or H38598-2
2 INCH	EC38599 or H38599-2
2-1/2 INCH	EC38600 or H38600-2
Hub Cover Plate	EC38595 or H38595-1

Meter Opening Cover Plate

Cat No: H659-0162

5th Jaw Kit

Cat No: H35815-3

## Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	WIRE SIZE	HEX DRIVE	TORQUE
LINE,LOAD,NEUTRAL	55890-1	#6 - 350 kcmil	5/16"	275 IN-LBS.
GROUND	36503	#14 - 2 AWG	..	50 IN-LBS.

© 2016 Copyright Siemens Industry, Inc.

**TALON**

**Meter Socket**

Description: **200A Cont, 5 Jaw, HQ-5SU, 600V AC, Painted Steel Enclosure**

JEL 3/18/16 | DO NOT SCALE DRAWING | Dwg No: **47605-01FL**