





Catalog Number: 47705-82KCPL

Features and Ratings

- Ringless Type Meter Socket
- 320A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 1 Phase, 3 Wire, Commercial Socket
- 5 Jaw Meter Socket
- Meter Socket Type HQ-5DT
- For Overhead & Underground Service
- HD Type Hub Opening, Cover Plate Included
- Lever Bypass

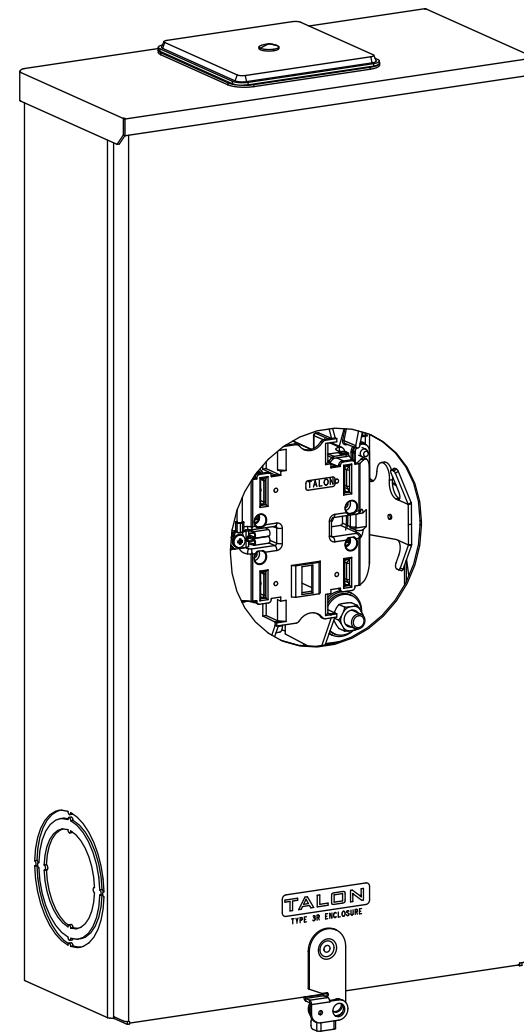

TYPE HD (LARGE) HUB OPENING WITH COVERPLATE INSTALLED

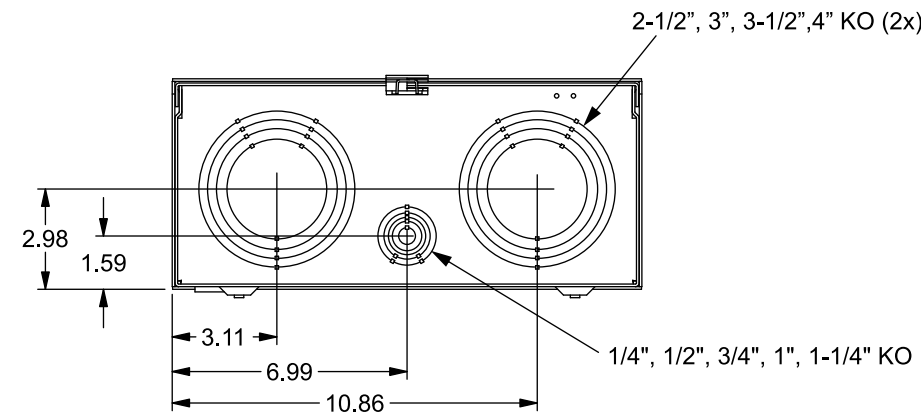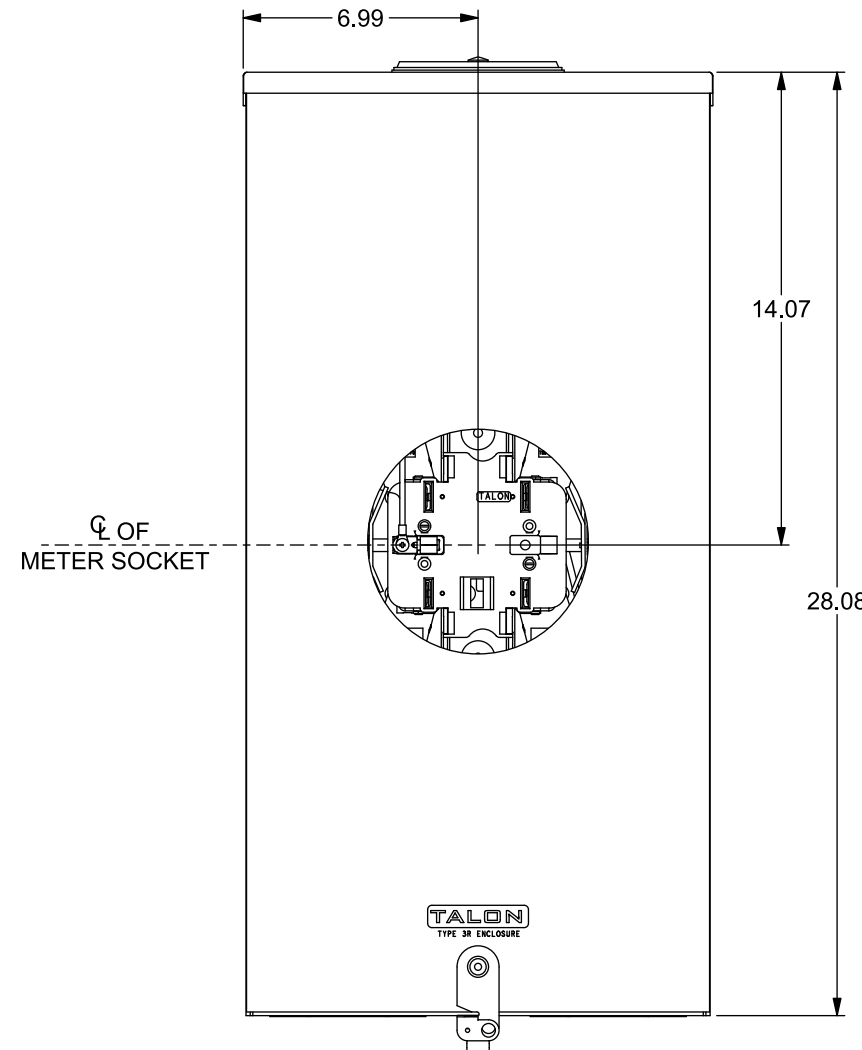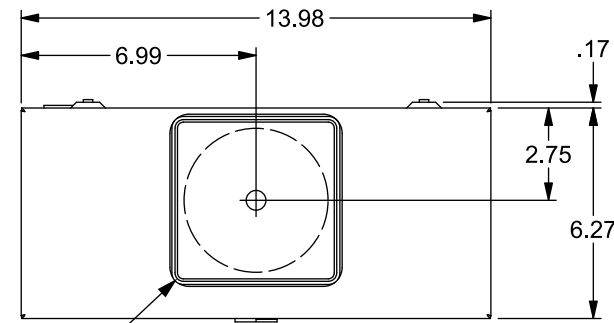

Accessories



| CONDUIT HUBS (HD Type) | |
|------------------------|---------------------|
| TRADE SIZE | CATALOG No. |
| 3 INCH | EC56856 or H56856-2 |
| 3-1/2 INCH | EC56857 or H56857-2 |
| 4 INCH | EC56858 or H56858-2 |
| Hub Cover Plate | EC56933 or H56933S |

Meter Opening Cover Plate
Cat No: H659-0162

Connectors, Wire Sizes and Torques

| CONNECTOR | PART No. | WIRE SIZE | TORQUE |
|--------------|----------|---------------------------|-------------|
| LINE | 60162 | #4-600 (2) 1/0-250 MCM | 500 IN-LBS. |
| LOAD/NEUTRAL | 56732 | (2)#4-350 MCM | 275 IN-LBS. |
| GROUND | 67754 | #14 - 2/0 AWG | 50 IN-LBS. |

VIEW SHOWN WITH COVER REMOVED

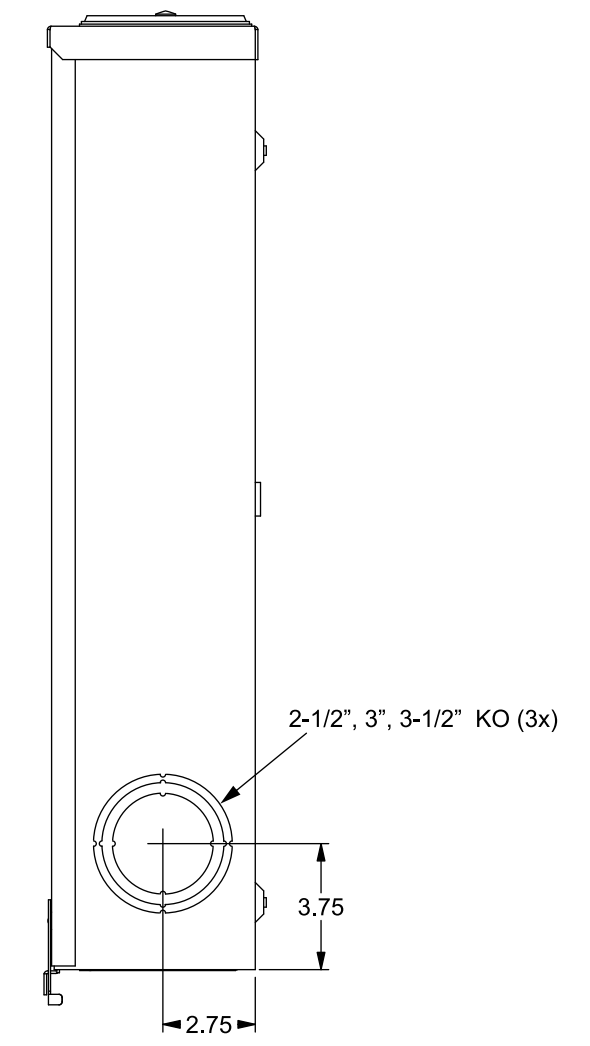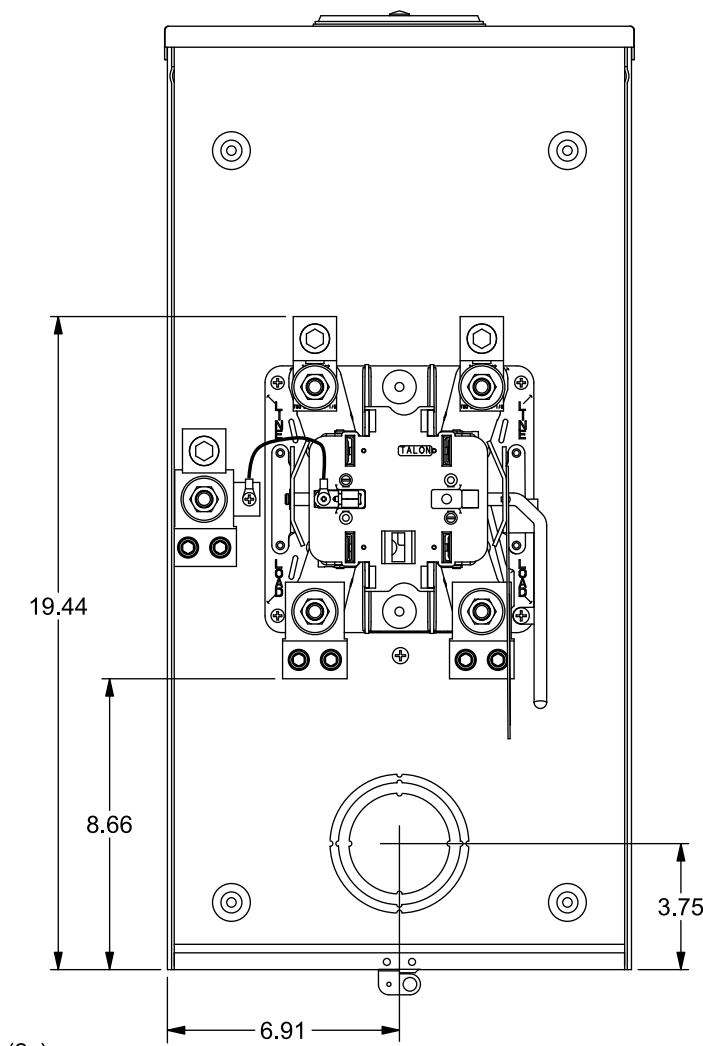

© 2018 Copyright Siemens Industry, Inc.



| | | |
|--|----------------------|-----------------------------|
| Description: 320A Cont, 5 Jaw, HQ-5DT, 600V AC, Painted Steel Enclosure | | |
| KAM 2/22/18 | DO NOT SCALE DRAWING | Dwg No: 47705-82KCPL |