




# Catalog Number: 9817-9406

## Features and Ratings




- Ringless Type Meter Socket
- 400A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted Steel Enclosure
- 2 or 3 Phase, Commercial/Industrial Socket
- Meter Socket Type K-5T
- For Overhead & Underground Service
- Two Large Hub Openings, HD Type Cover Plates Installed

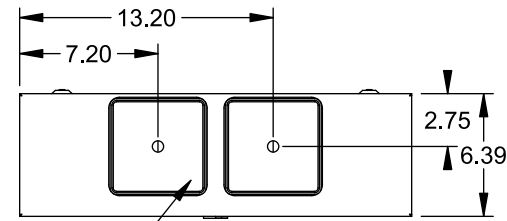

(2) TYPE HD (LARGE) HUB OPENINGS COVER PLATES INSTALLED

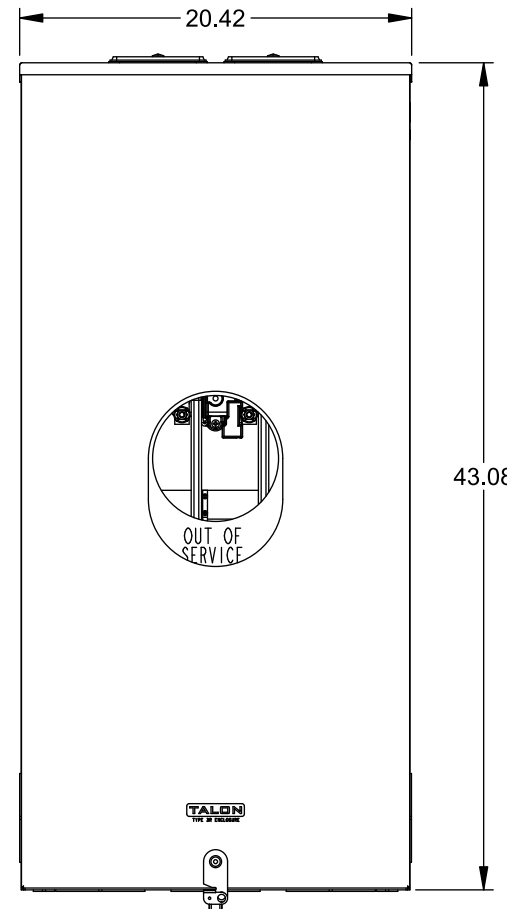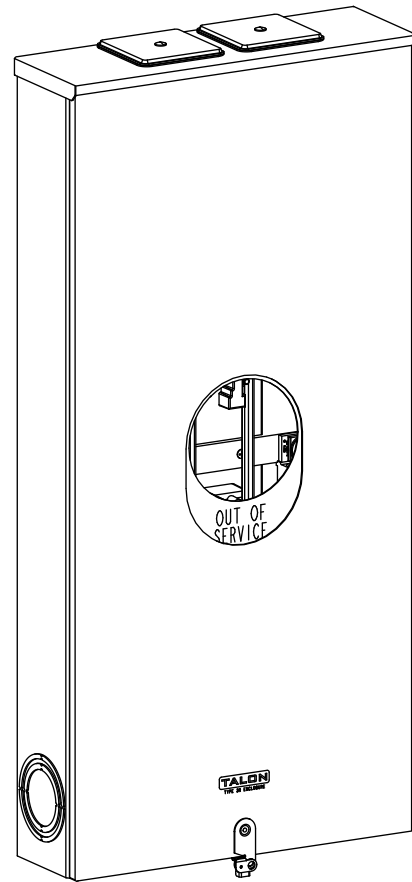

VIEW SHOWN WITH COVER REMOVED

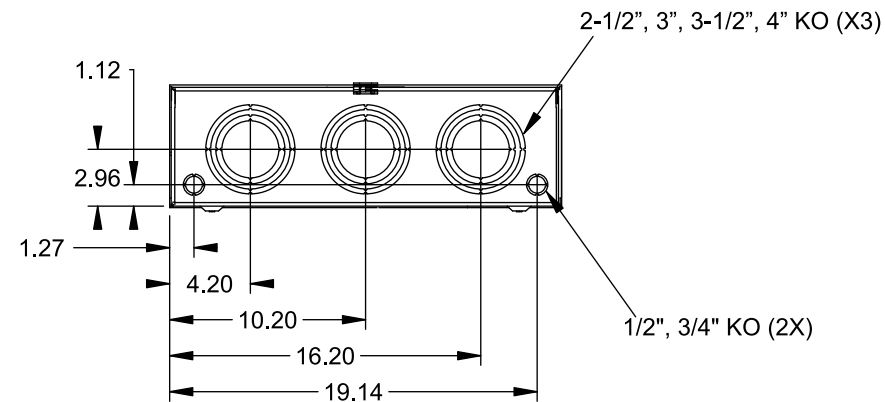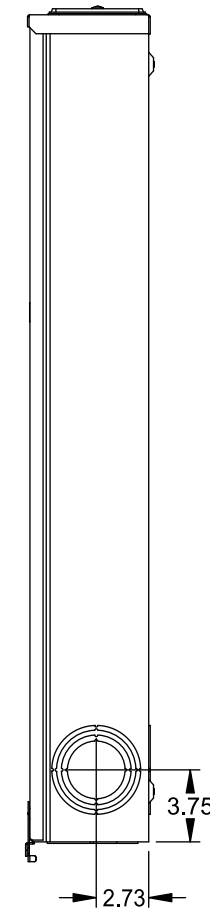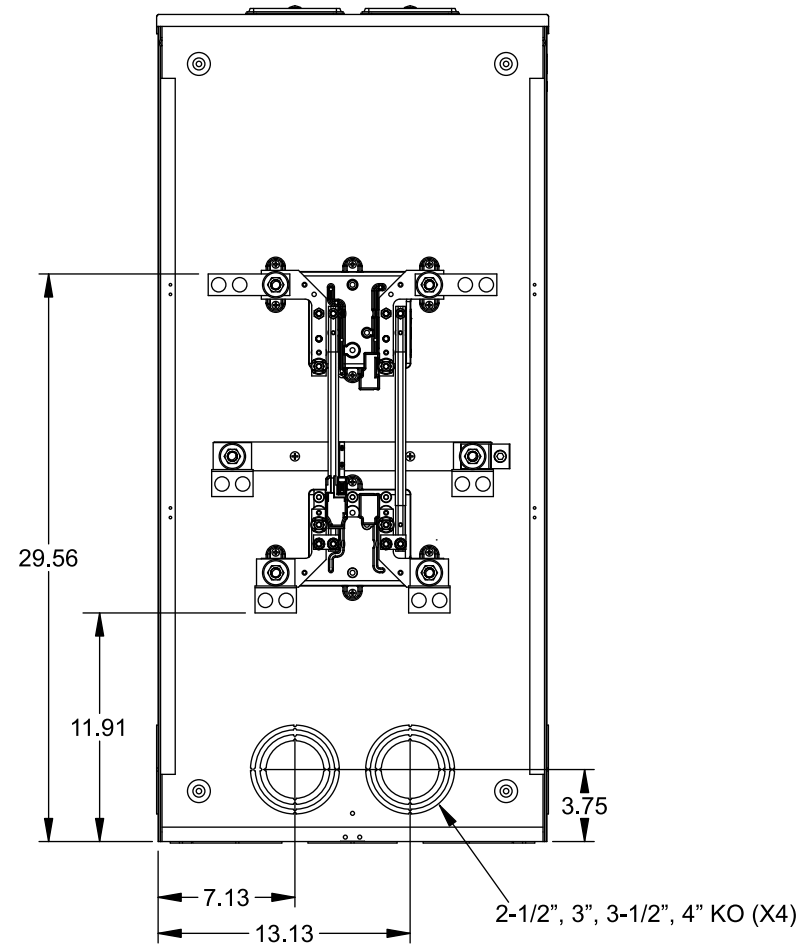

## Accessories

CONDUIT HUBS (HD Type)		CAT No.	DESCRIPTION
TRADE SIZE	CATALOG No.		
3 INCH	EC56856 or H56856-2	H69685-1	Bypass Isolated Neutral Kit
3-1/2 INCH	EC56857 or H56857-2	H69546-1	Hex Magnet Socket Kit
4 INCH	EC56858 or H56858-2	H69232-1	Insulated T-Handle Kit
Hub Cover Plate	EC56933 or H56933S	H65050	K-base Insulator Kit
		H63864	K-base Ground Kit

## Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	HEX DRIVE	WIRE SIZE	TORQUE
LINE	56427-M*	1/2"	(2)#2 - 500 kcmil	375 IN-LBS.
LOAD	56732-M*	1/2"	(2)#4 - 500 kcmil	375 IN-LBS.
GROUND	56734*	5/16"	#6 - 250 kcmil	275 IN-LBS.

\*Factory installed

© 2019 Copyright Siemens Industry, Inc.

**TALON**

**Meter Socket**

Description: **400A Cont, 5 Terminal, K-5T, 600V AC, Painted Steel Enclosure**

JEL 7/19/19 | DO NOT SCALE DRAWING | Dwg No: **9817-9406**