


# Catalog Number: SUAT417-XGF

## Features and Ratings

- Ringless Type Meter Socket
- 200A Continuous, 250A Max.
- Outdoor Enclosure (NEMA Type 3R)
- 1 Phase, 3 Wire, 600V AC
- 4 Jaw
- For Overhead or Underground Service
- RX Hub Opening With Coverplate Installed
- Quad Bonded Neutral
- Painted G90 steel enclosure
- Stainless steel latch and hasp

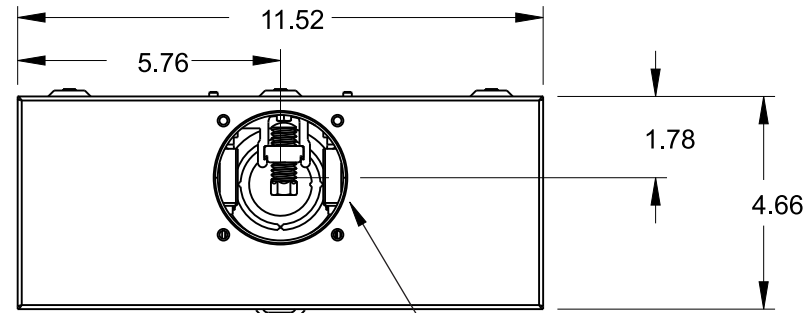

RX HUB PROVISION  
Factory Installed (Not Shown)

### Accessories

Meter Opening Cover Plate  
Cat No: H39968

#### RX HUB KITS

Cat No: H38597-2 (1.25")  
Cat No: H38598-2 (1.50")  
Cat No: H38599-2 (2.00")  
Cat No: H38600-2 (2.50")

#### RX HUB KITS

Cat No: EC38597 (1.25")  
Cat No: EC38598 (1.50")  
Cat No: EC38599 (2.00")  
Cat No: EC38600 (2.50")


#### HUB COVER PLATE

Cat No: H38595-2




### Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	250 LB-IN
LOAD*	#6-350 kcmil	250 LB-IN
NEUTRAL*	#6-350 kcmil	250 LB-IN
GROUND	#14-2	50 LB-IN

\* External Hex drive 1/2"  
\* Internal Hex drive 5/16"

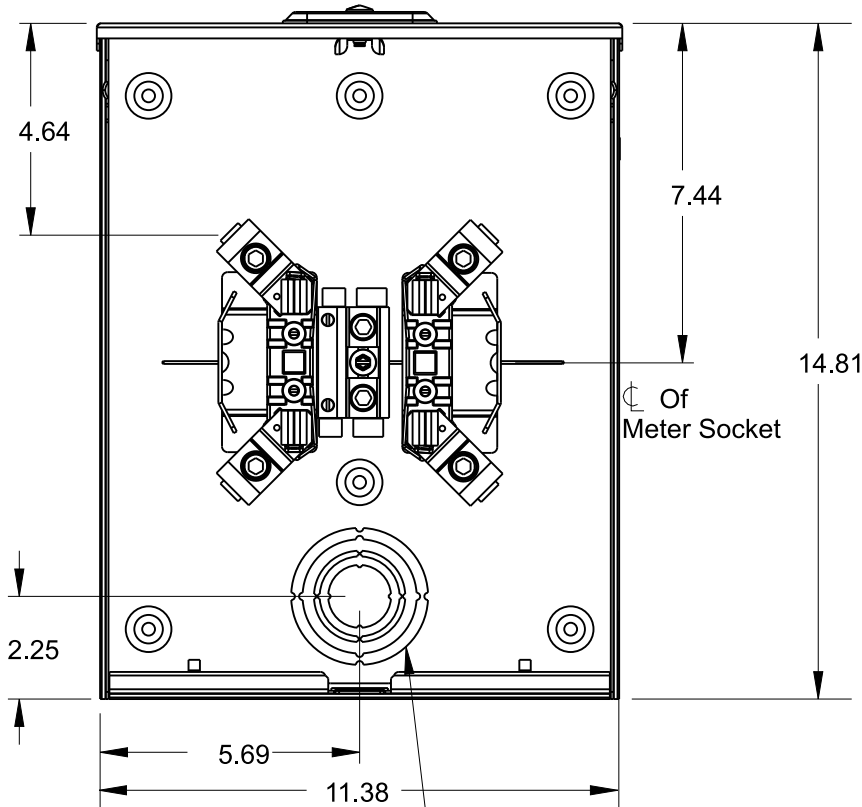


Center of Meter Socket

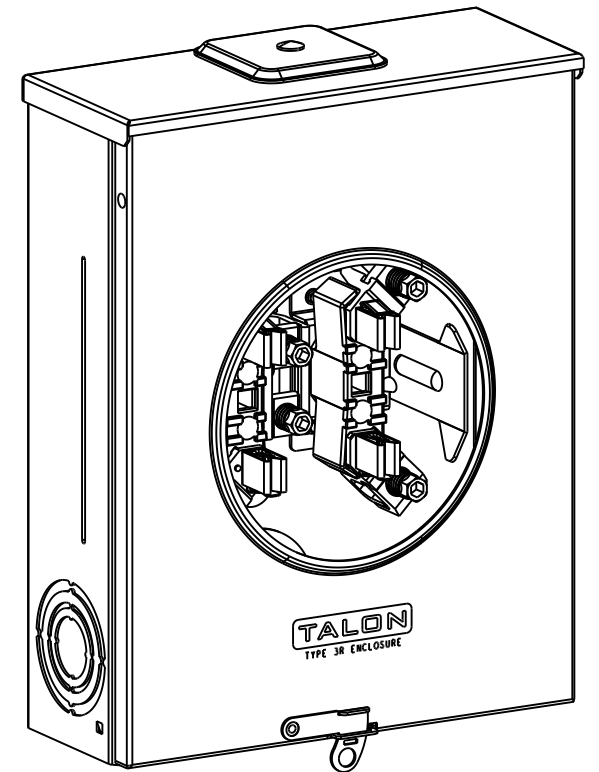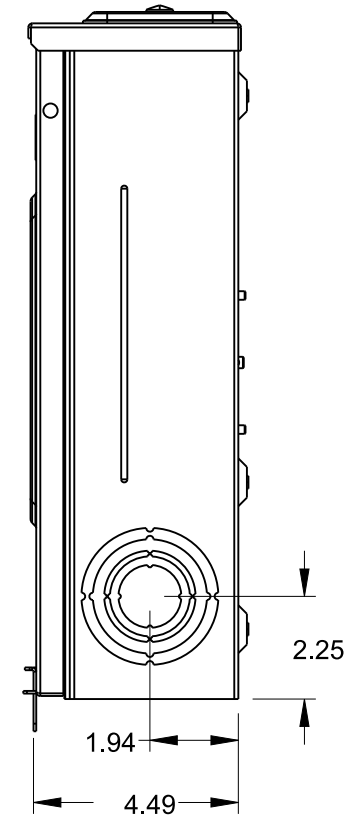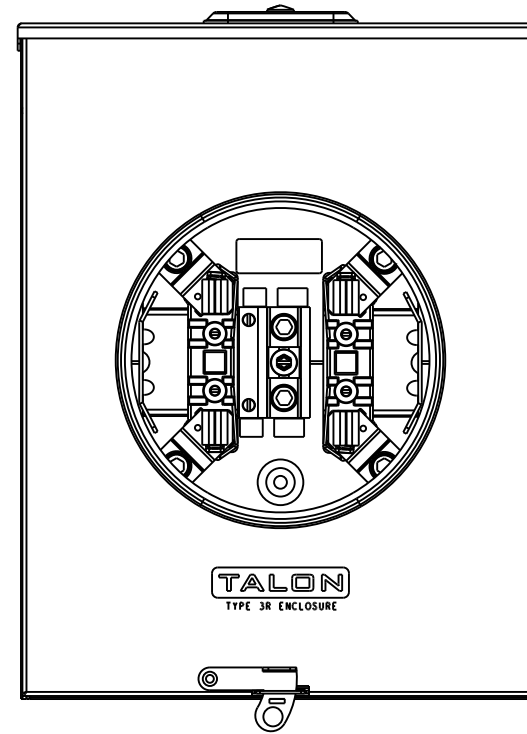

Ø .250, Ø .625, Ø .875, ACTUAL SIZE KO (2x)

1", 1-1/4", 1-1/2", 2", 2-1/2" KO 3x

1", 1-1/4", 1-1/2", 2", 2-1/2" KO 3x

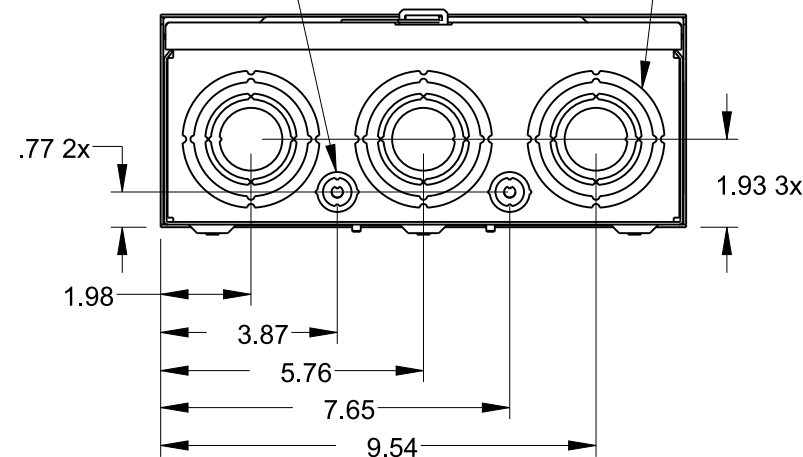

**TALON**  
Meter Socket

Description:  
200A Cont, 4 Jaw, UAT-4, 600V AC,  
Painted G90 Steel