
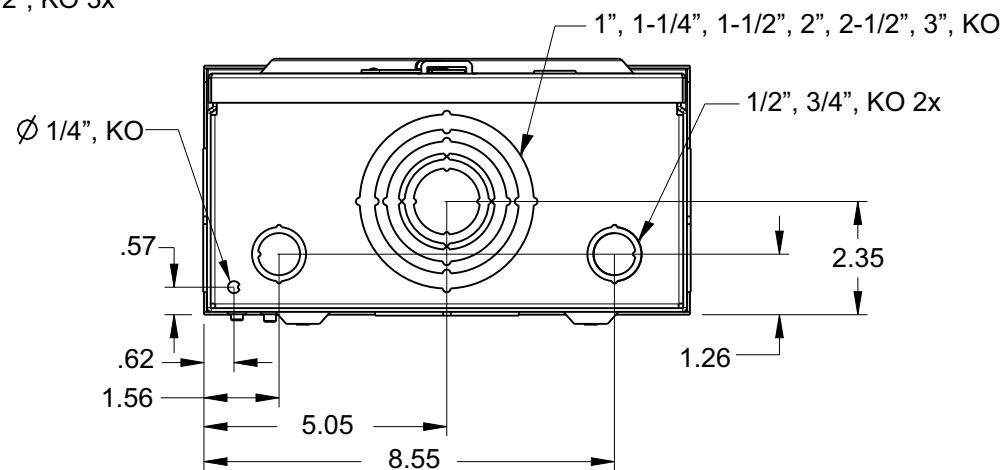
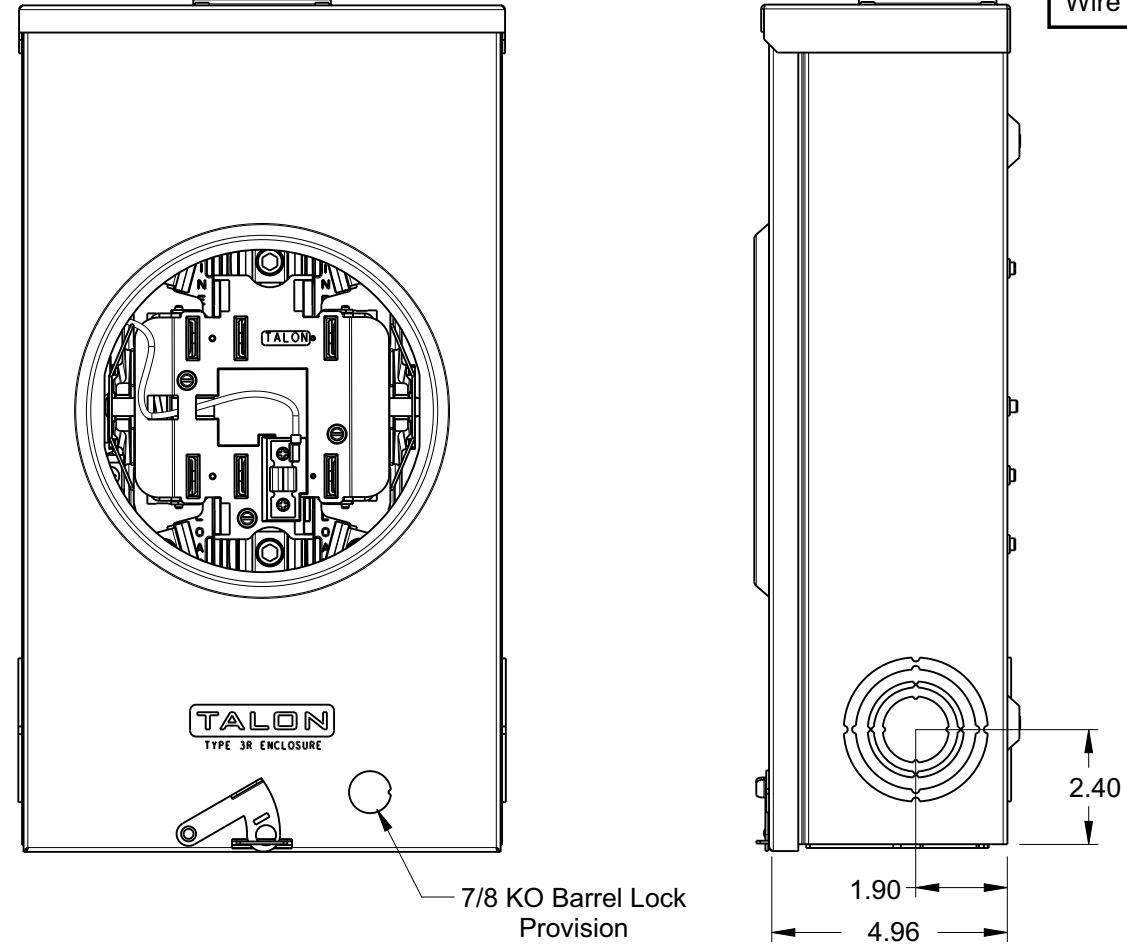
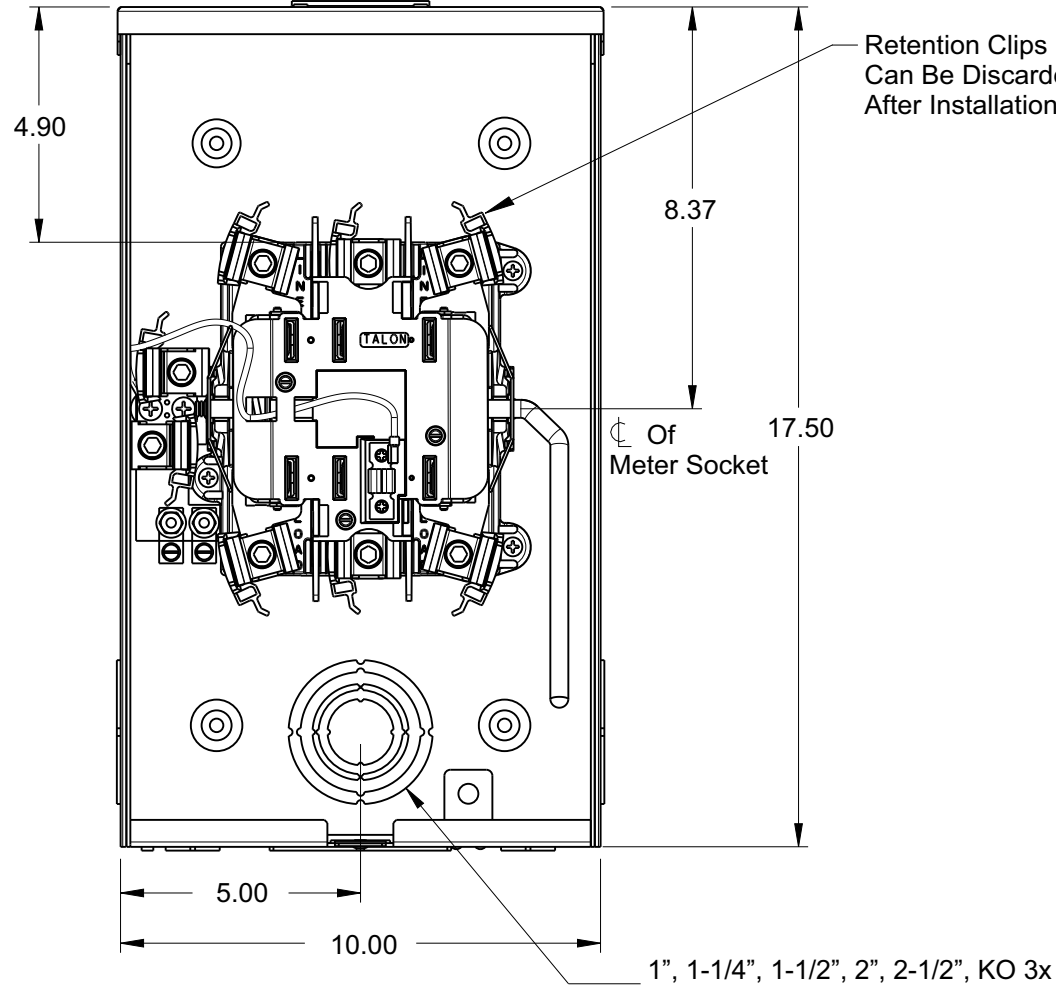


# Catalog Number: 41007-01GP

## Features and Ratings

- Ringless Type Meter Socket
- 200A Continuous, 250A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Aluminum Enclosure
- 3 Phase, 4 Wire, 600V AC
- 7 Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead Service Only
- RX Hub Opening
- Two Ground Lugs
- 7/8" Barrel Lock Provision

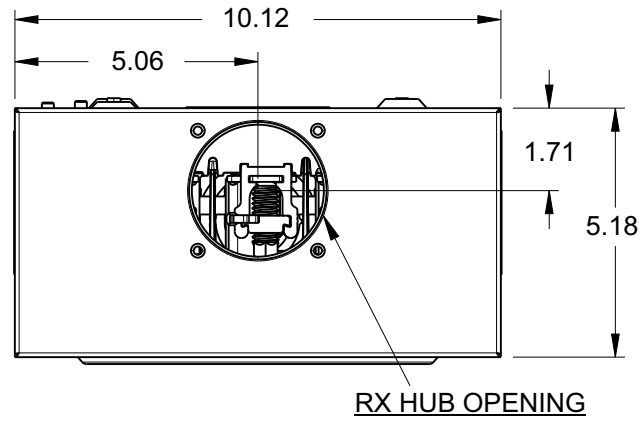

### Accessories

Meter Opening Cover Plate  
Cat No: H39968

#### RX HUB KITS

Cat No: H38597-2 (1.25")  
Cat No: H38598-2 (1.50")  
Cat No: H38599-2 (2.00")  
Cat No: H38600-2 (2.50")

#### RX HUB KITS

Cat No: EC38597 (1.25")  
Cat No: EC38598 (1.50")  
Cat No: EC38599 (2.00")  
Cat No: EC38600 (2.50")

#### HUB COVER PLATE

Cat No: H38595-1


#### GROUND LUG KIT

Cat No: H6509991  
Wire Size #14-2 45 LB-IN

### Lugs, Wire Sizes and Torques

| LOCATION | LUG SIZE     | TORQUE    |
|----------|--------------|-----------|
| LINE*    | #6-350 kcmil | 275 LB-IN |
| LOAD*    | #6-350 kcmil | 275 LB-IN |
| NEUTRAL* | #6-350 kcmil | 275 LB-IN |
| GROUND   | #14-2        | 45 LB-IN  |

\* External Hex drive 1/2"  
\* Internal Hex drive 5/16"

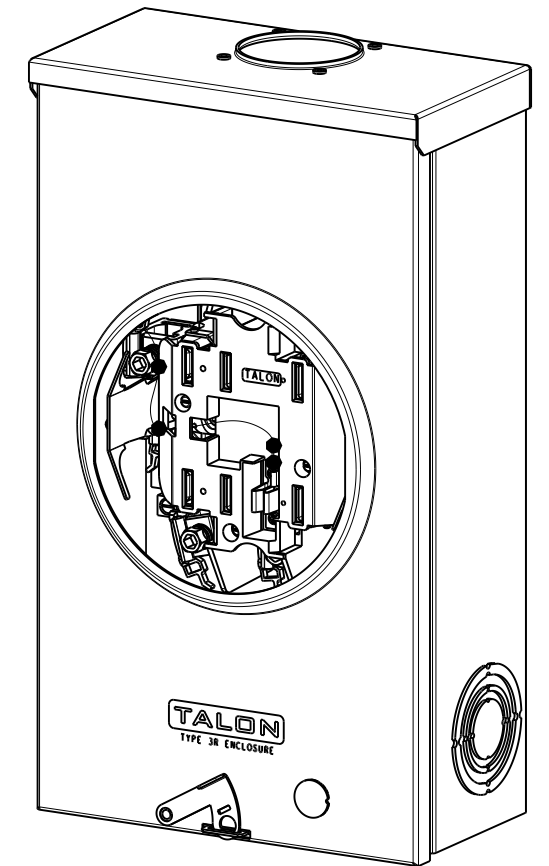

**TALON**  
**Meter Socket**

Description:  
**200A Cont, 7 Jaw, HQ7, 600V AC,  
Aluminum Enclosure**