
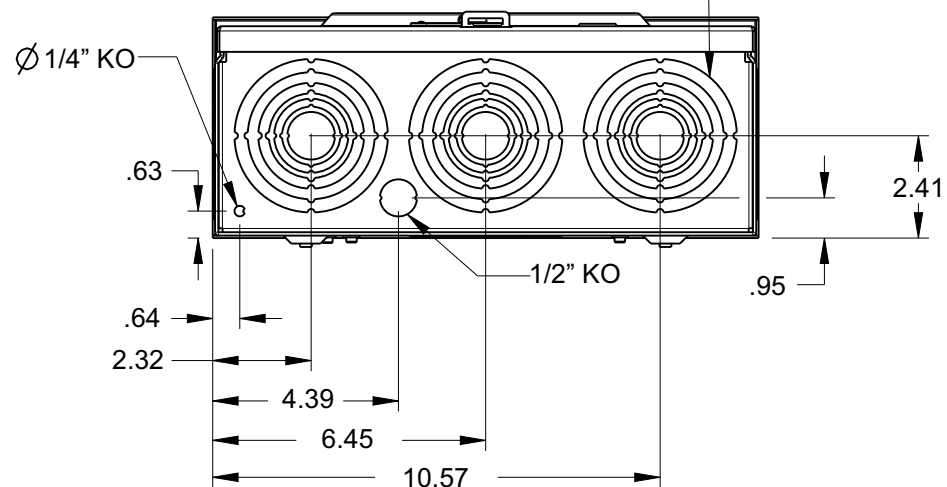
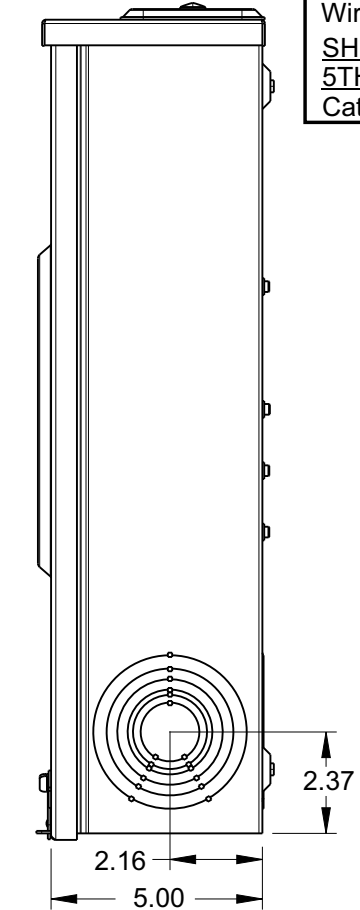
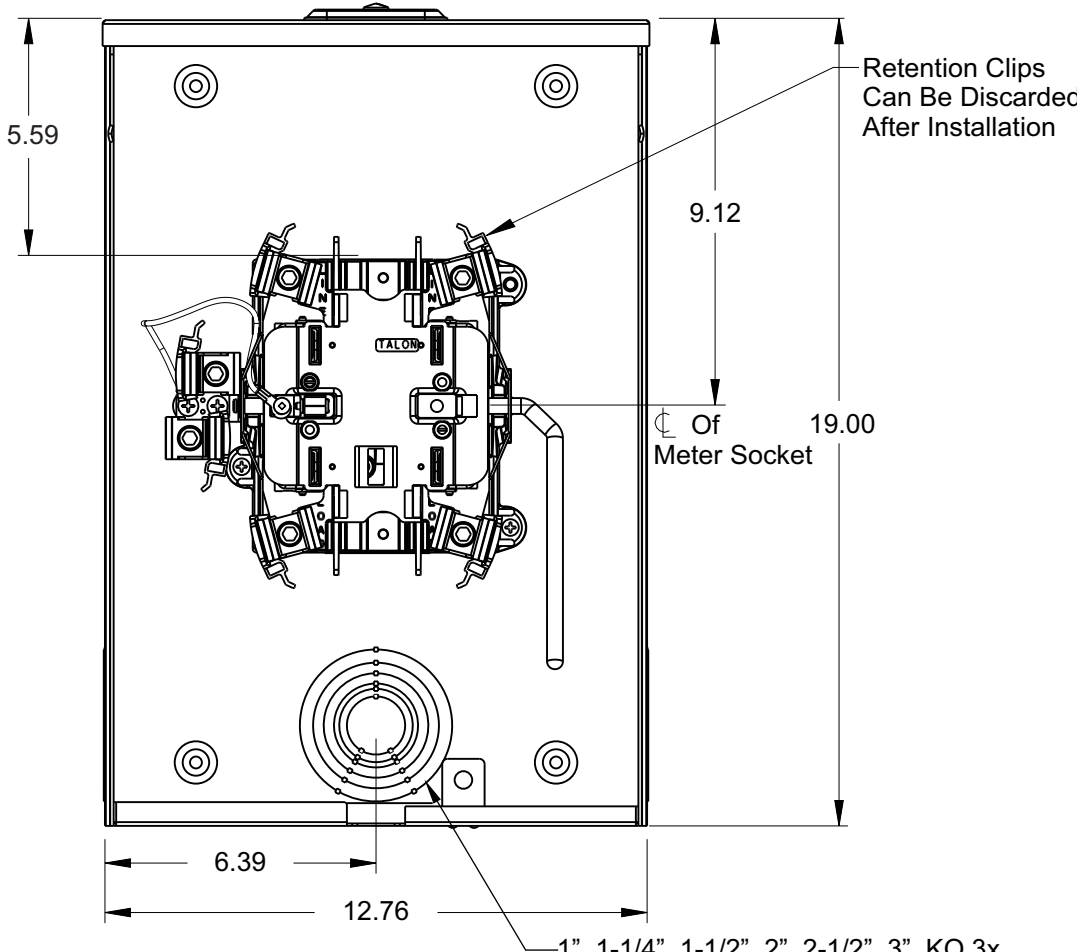


# Catalog Number: 41405-02GP

## Features and Ratings

- Ringless Type Meter Socket
- 200A Continuous, 250A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Aluminum Enclosure
- 1 Phase, 3 Wire, 600V AC
- 5 Jaw, 9 O'clock 5th Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- RX Hub Opening With Coverplate Installed
- 7/8" Barrel Lock Provision

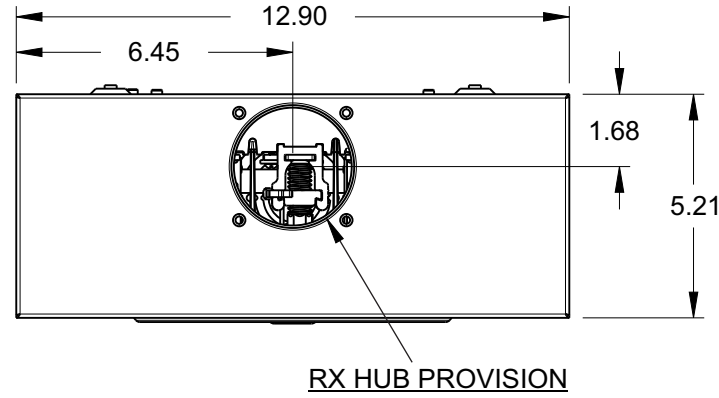

### Accessories

Meter Opening Cover Plate  
Cat No: H39968

RX HUB KITS  
Cat No: H38597-2 (1.25")  
Cat No: H38598-2 (1.50")  
Cat No: H38599-2 (2.00")  
Cat No: H38600-2 (2.50")

RX HUB KITS  
Cat No: EC38597 (1.25")  
Cat No: EC38598 (1.50")  
Cat No: EC38599 (2.00")  
Cat No: EC38600 (2.50")


HUB COVER PLATE  
Cat No: H38595-1

GROUND LUG KIT  
Cat No: H6509991  
Wire Size #4-2 45 LB-IN  
SHIELD ASSEMBLY WITH  
5TH JAW  
Cat No: H35815-3

### Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	275 LB-IN
LOAD*	#6-350 kcmil	275 LB-IN
NEUTRAL*	#6-350 kcmil	275 LB-IN
GROUND	#14-2	45 LB-IN

\* External Hex drive 1/2"  
\* Internal Hex drive 5/16"

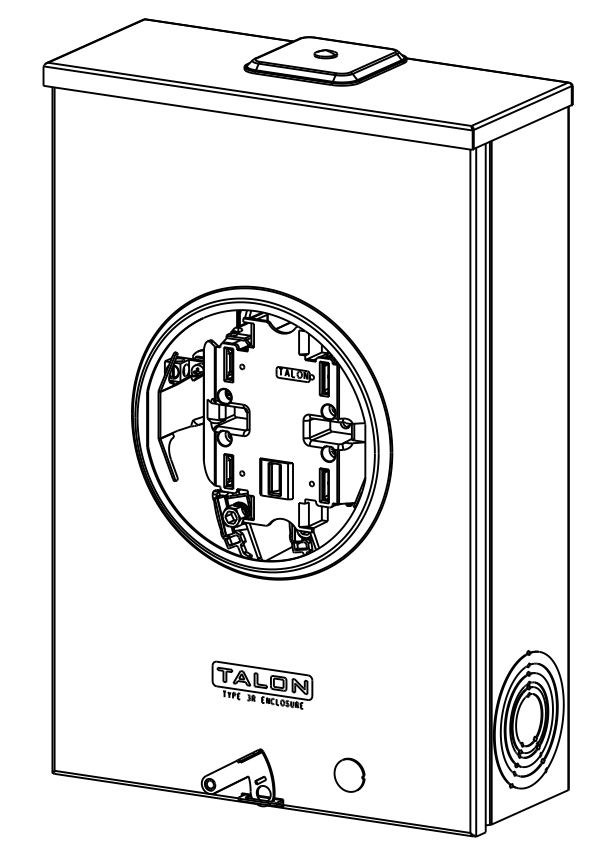

**TALON**  
Meter Socket

Description:  
**200A Cont, 5 Jaw, HQ5, 600V AC,  
Aluminum Enclosure**