
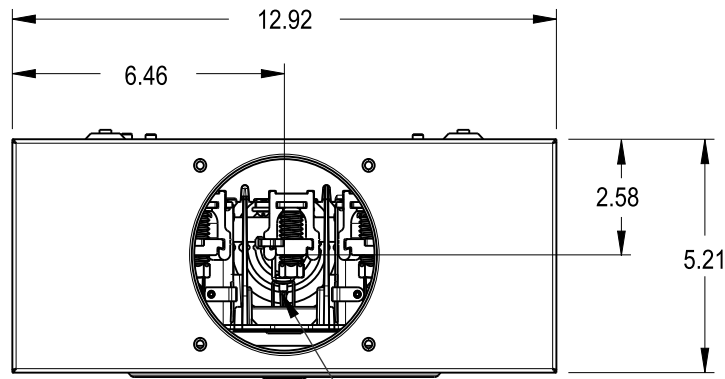




Catalog Number: 41405-02MR

Features and Ratings


- Ringless Type Meter Socket
- 200A Continuous, 250A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Painted Aluminum
- 1 Phase, 3 Wire, 600V AC
- 5 Jaw, 6 O'clock 5th Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- HD Hub Opening With Coverplate Installed
- Two Ground Lugs

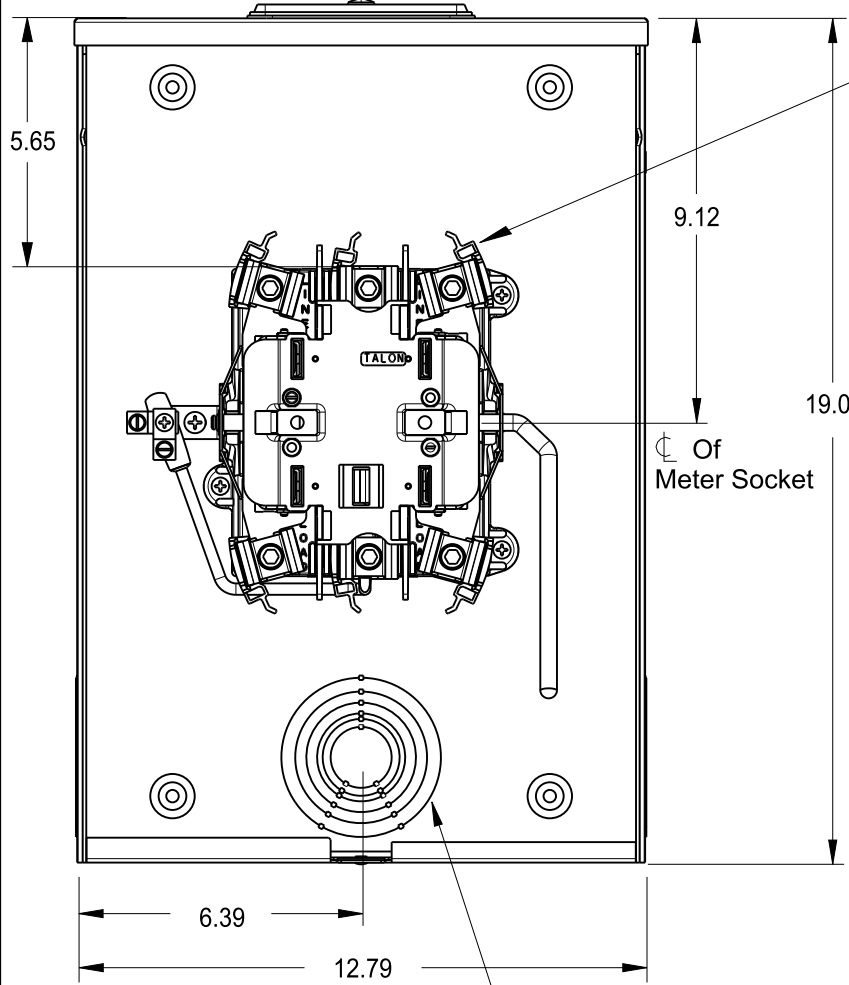

HD HUB PROVISION

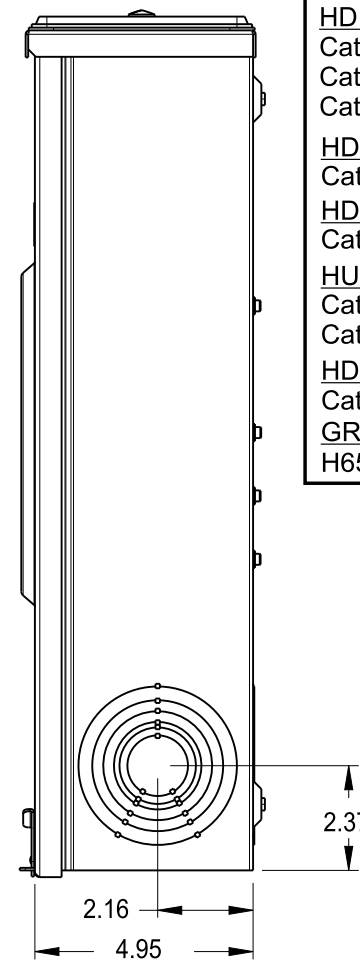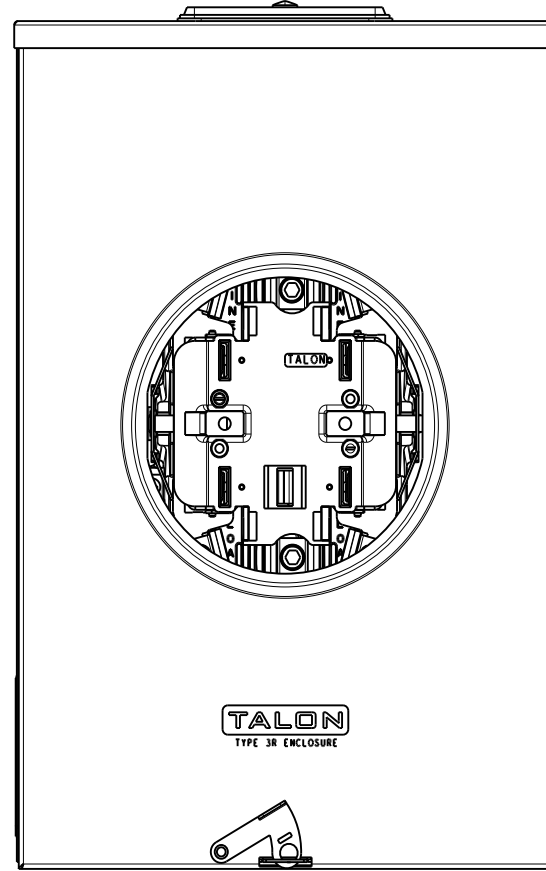

1", 1-1/4", 1-1/2", 2", 2-1/2", 3" KO 3x

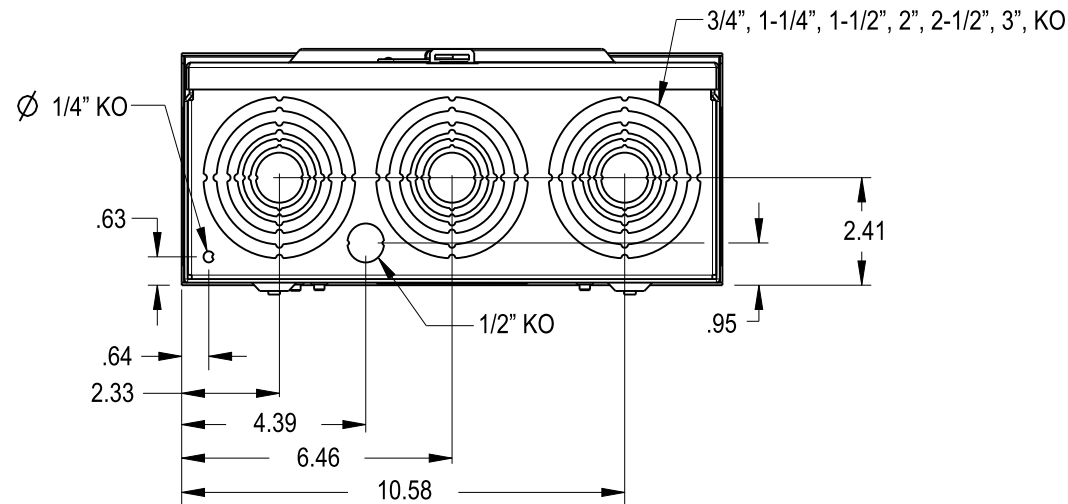

Accessories

Meter Opening Cover Plate
Cat No: H39968

RX HUB KITS

- Cat No: H38597-2 (1.25")
- Cat No: H38598-2 (1.50")
- Cat No: H38599-2 (2.00")
- Cat No: H38600-2 (2.50")

RX HUB KITS

- Cat No: EC38597 (1.25")
- Cat No: EC38598 (1.50")
- Cat No: EC38599 (2.00")
- Cat No: EC38600 (2.50")

HD HUB KITS

- Cat No: H56856-2 (3.00")
- Cat No: H56857-2 (3.50")
- Cat No: H56858-2 (4.00")

HD HUB KITS

- Cat No: EC56856 (3")
- Cat No: EC56857 (3.50")
- Cat No: EC56858 (4")

HD-RX Adapter Plate:

Cat No: H9747-1113

HD-RX Adapter Plate:

Cat No: EC9747-1113

HUB COVER PLATE

Cat No: H38595-8 (RX)

Cat No: H56933-3 (HD)

HD COVERPLATE

Cat No: EC56933S

GROUND LUG KIT


H6509991 #14-2 45 LB-IN

Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	275 LB-IN
LOAD*	#6-350 kcmil	275 LB-IN
NEUTRAL*	#6-350 kcmil	275 LB-IN
GROUND	#14-2	45 LB-IN

* External Hex drive 1/2"

* Internal Hex drive 5/16"

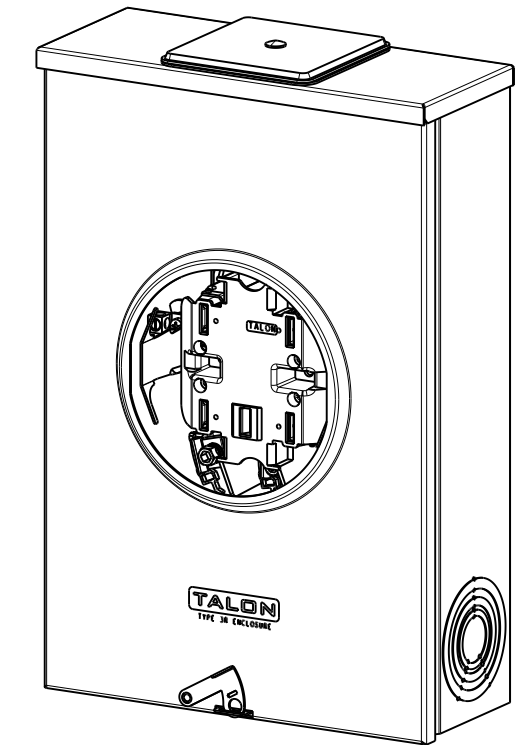

TALON

Meter Socket

Description:
**200A Cont, 5 Jaw, HQ5, 600V AC,
Painted Aluminum**