
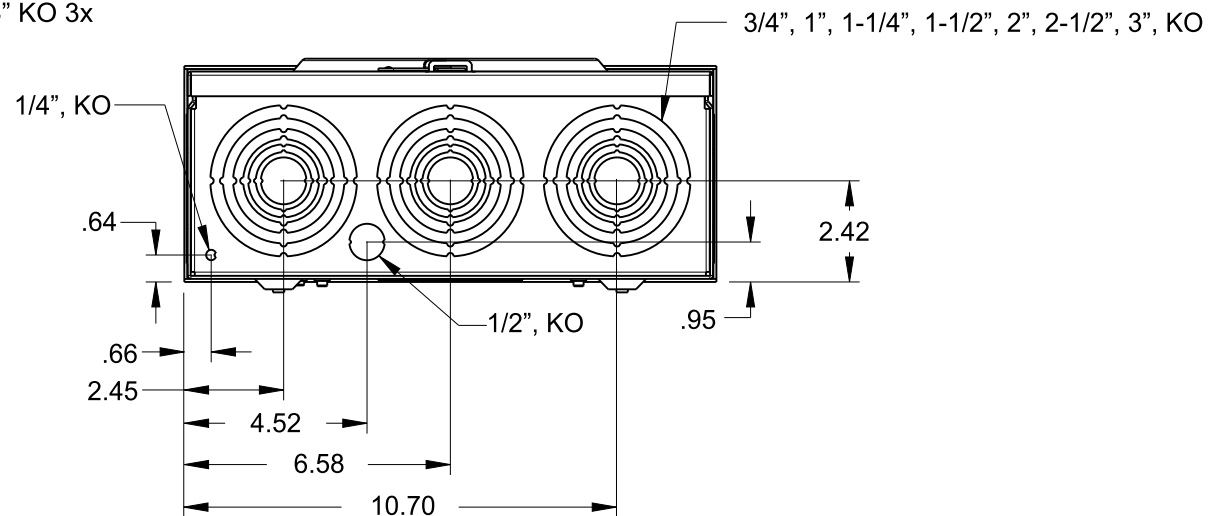
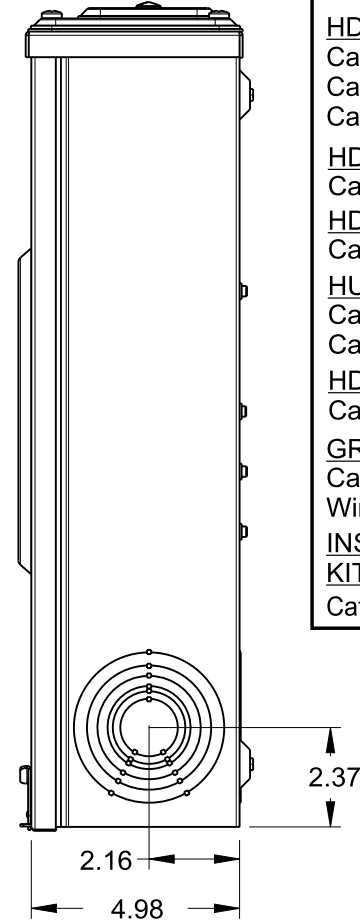
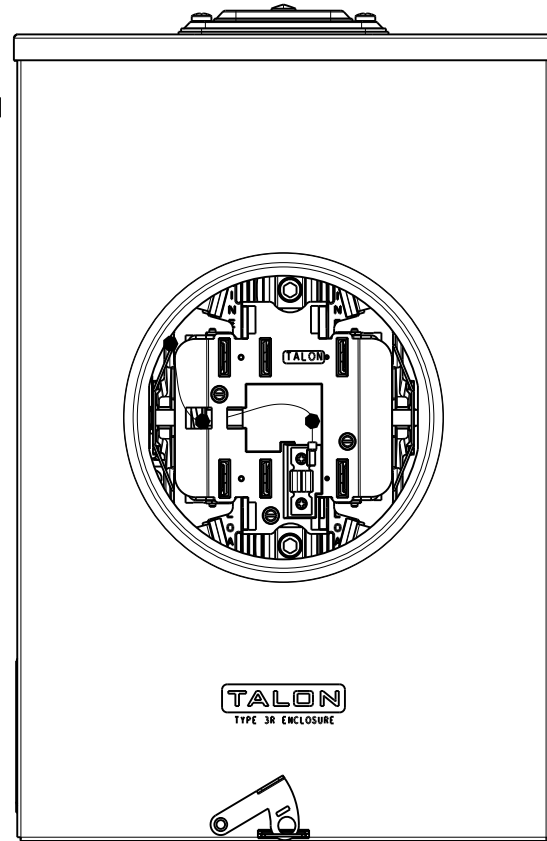
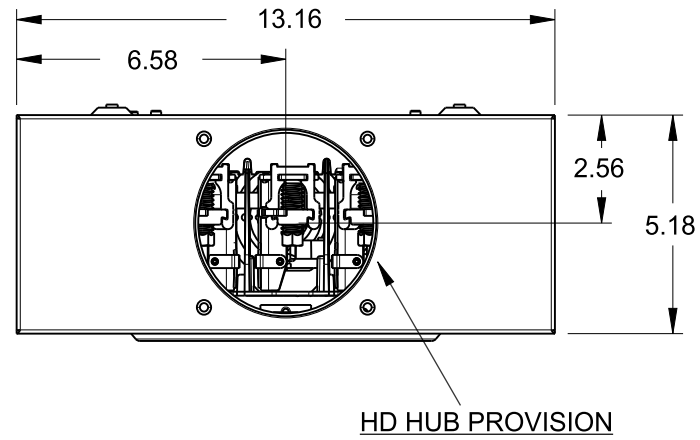


# Catalog Number: 44307-02MR

## Features and Ratings

- Ringless Type Meter Socket
- 200A Continuous Duty, 250A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 STEEL
- 3 Phase, 4 Wire, 600V AC
- 7 Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- HD Hub Opening With HD-RX Adapter Plate and RX Coverplate Installed
- Two Ground Lugs

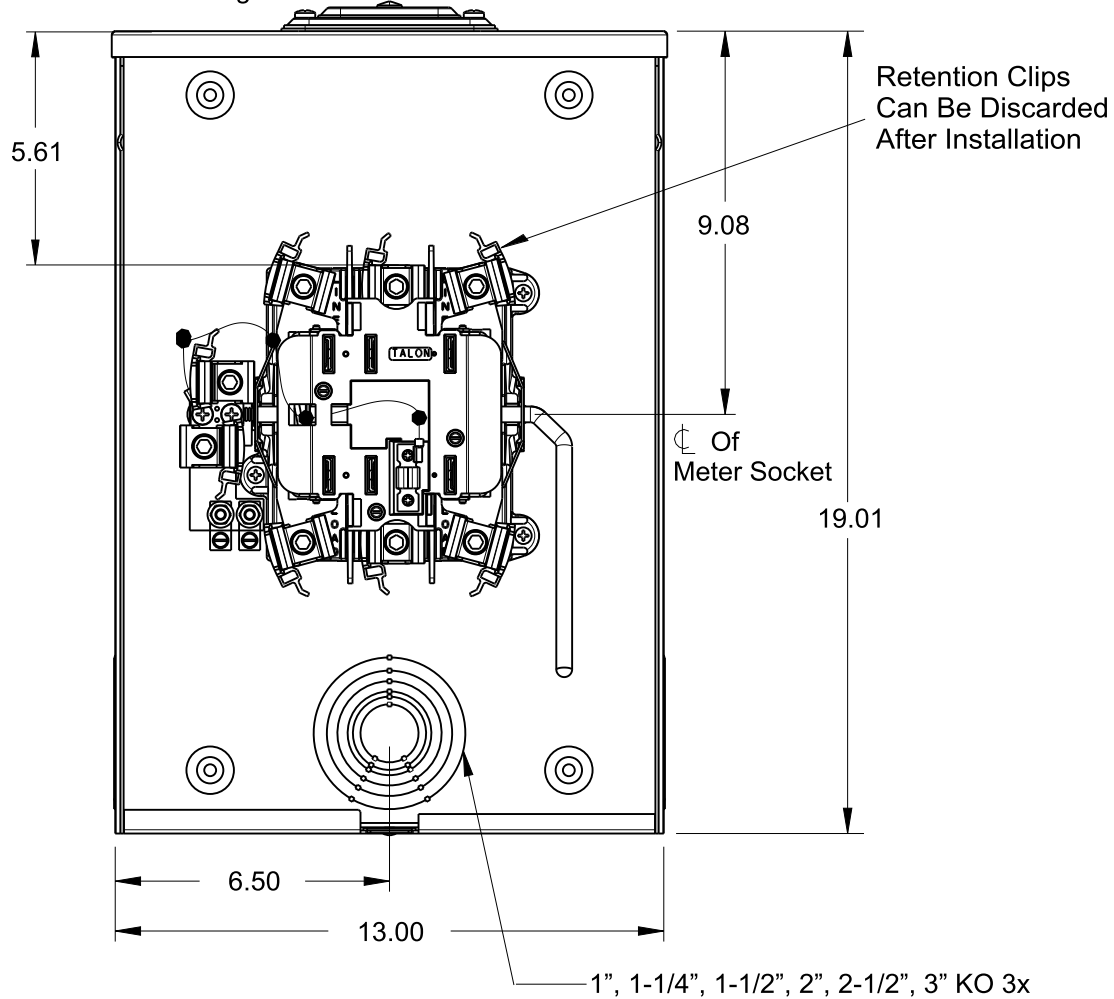


### Accessories

- Meter Opening Cover Plate  
Cat No: H39968
- RX HUB KITS  
Cat No: H38597-2 (1.25")  
Cat No: H38598-2 (1.50")  
Cat No: H38599-2 (2.00")  
Cat No: H38600-2 (2.50")
- RX HUB KITS  
Cat No: EC38597 (1.25")  
Cat No: EC38598 (1.50")  
Cat No: EC38599 (2.00")  
Cat No: EC38600 (2.50")
- HD HUB KITS  
Cat No: H56856-2 (3.00")  
Cat No: H56857-2 (3.50")  
Cat No: H56858-2 (4.00")
- HD HUB KITS  
Cat No: EC56856 (3")  
Cat No: EC56857 (3.50")  
Cat No: EC56858 (4")
- HD-RX Adapter Plate:  
Cat No: H9747-1113
- HD-RX Adapter Plate:  
Cat No: EC9747-1113
- HUB COVER PLATE  
Cat No: H38595-1 (RX)  
Cat No: H56933-2 (HD)
- HD COVERPLATE  
Cat No: EC56933S
- GROUND LUG KIT  
Cat No: H80500017  
Wire Size #2-14 45 LB-IN
- INSULATED NEUTRAL KIT  
Cat No: H65685-1, H64690-1

### Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	275 LB-IN
LOAD*	#6-350 kcmil	275 LB-IN
NEUTRAL*	#6-350 kcmil	275 LB-IN
GROUND	#14-2	45 LB-IN

\* External Hex drive 1/2"  
\* Internal Hex drive 5/16"

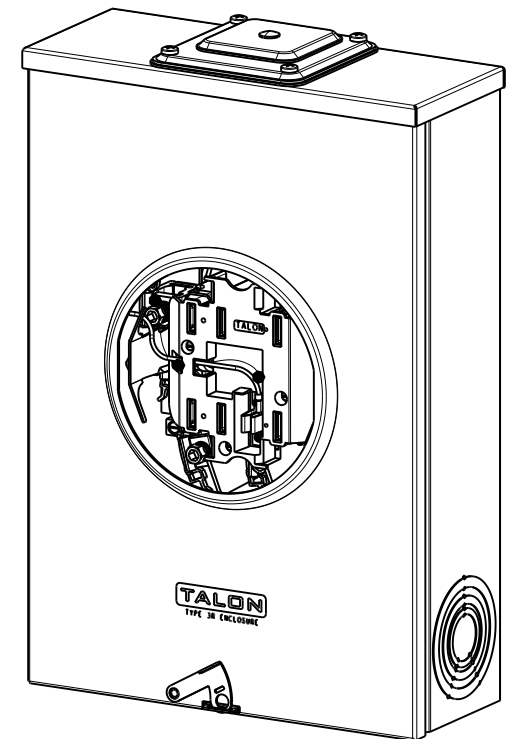

**TALON**  
Meter Socket

Description:  
**200A Cont, 7 Jaw, HQ7U, 600V AC,  
Painted G90 Steel**