
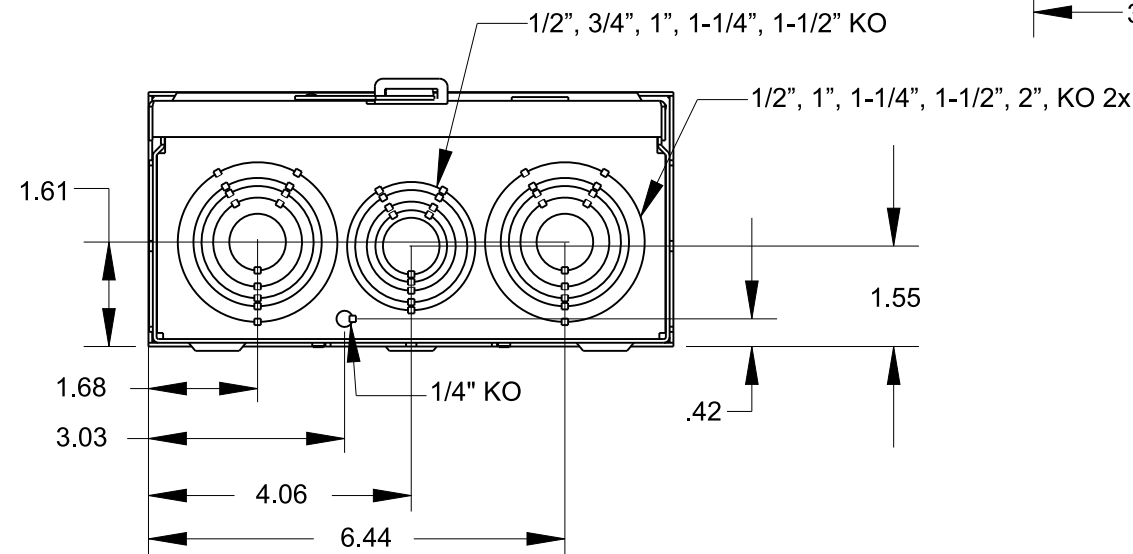
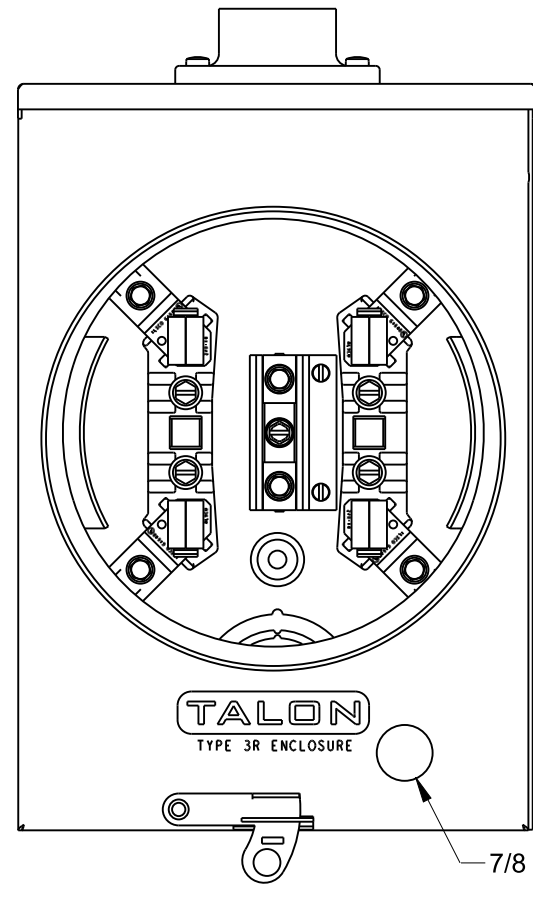
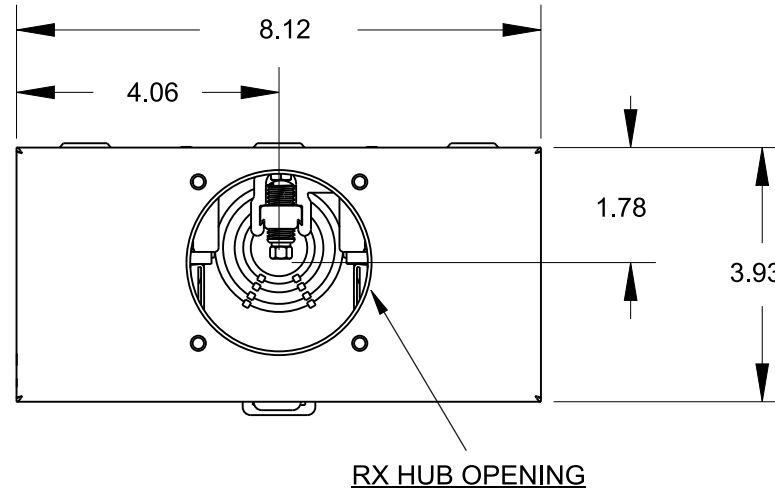


Catalog Number: UAT131-BPGP

Features and Ratings

- Ringless Type Meter Socket
- 135A Continuous, 135A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 STEEL
- 1 Phase, 3 Wire, 600V AC
- 4 Jaw
- Horn Bypass
- For Overhead or Underground Service
- RX Hub Opening, 1/4" Hub Installed
- 7/8" Barrel Lock Provision

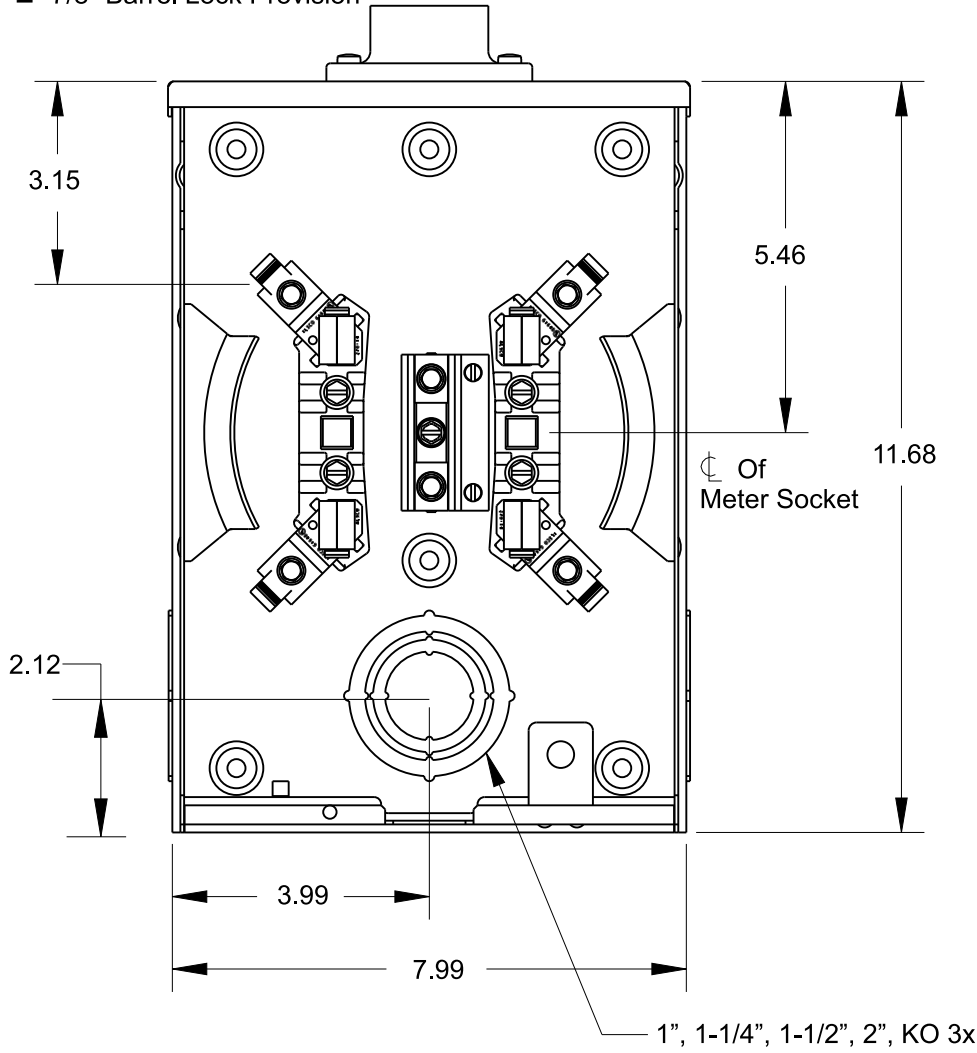

Accessories

Meter Opening Cover Plate
Cat No: H39968

RX HUB KITS

Cat No: H38597-2 (1.25")
Cat No: H38598-2 (1.50")
Cat No: H38599-2 (2.00")
Cat No: H38600-2 (2.50")

RX HUB KITS

Cat No: EC38597 (1.25")
Cat No: EC38598 (1.50")
Cat No: EC38599 (2.00")
Cat No: EC38600 (2.50")



HUB COVER PLATE

Cat No: H38595-2

Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	250 LB-IN
LOAD*	#6-350 kcmil	250 LB-IN
NEUTRAL*	#6-350 kcmil	250 LB-IN
GROUND*	#14-2	50 LB-IN

* External Hex drive 1/2"
* Internal Hex drive 5/16"

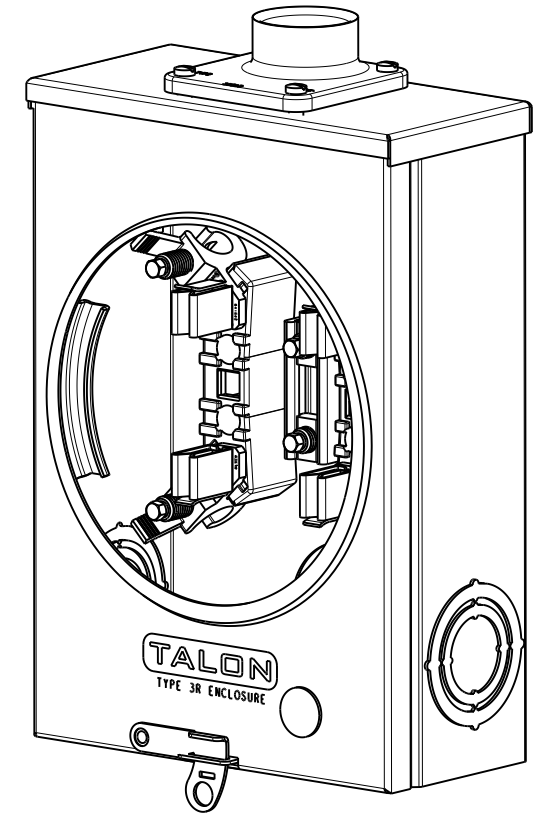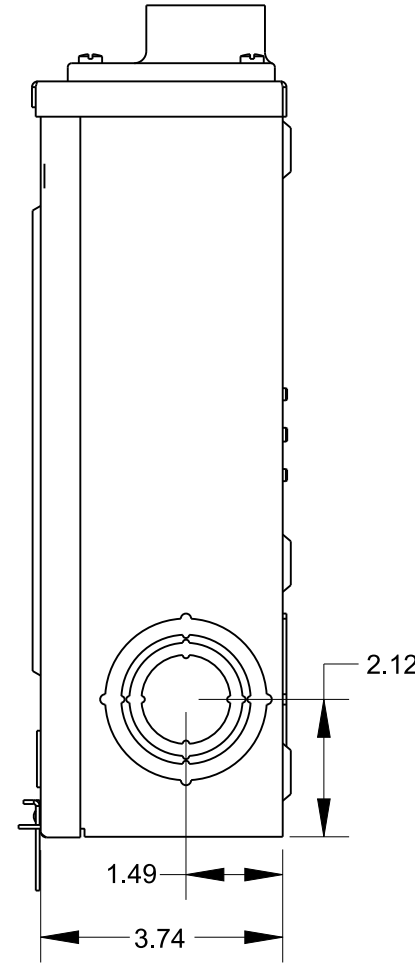

TALON Meter Socket

Description:
**135A Cont, 4 Jaw, UAT-1, 600V AC,
Painted G90 STEEL**