


Features and Ratings


- Outdoor Enclosure (NEMA Type 3R)
- Natural finish 5052-H32 Aluminum
- For Underground Service

Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
GROUND	#14 - 2/0 AWG	50 IN.-LBS.

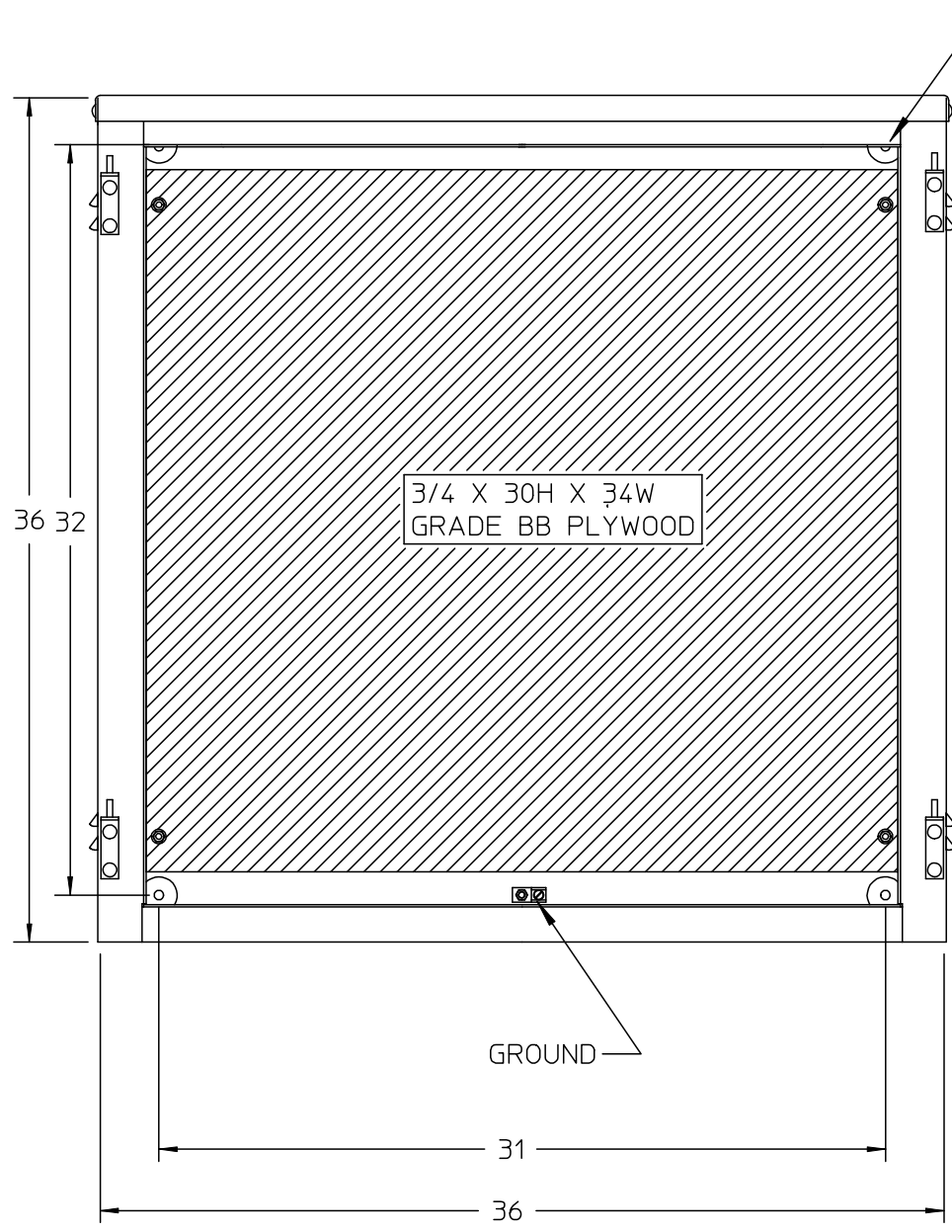


MOUNTING EMBOSS FOR 3/8" LAG BOLT (4) PLACES

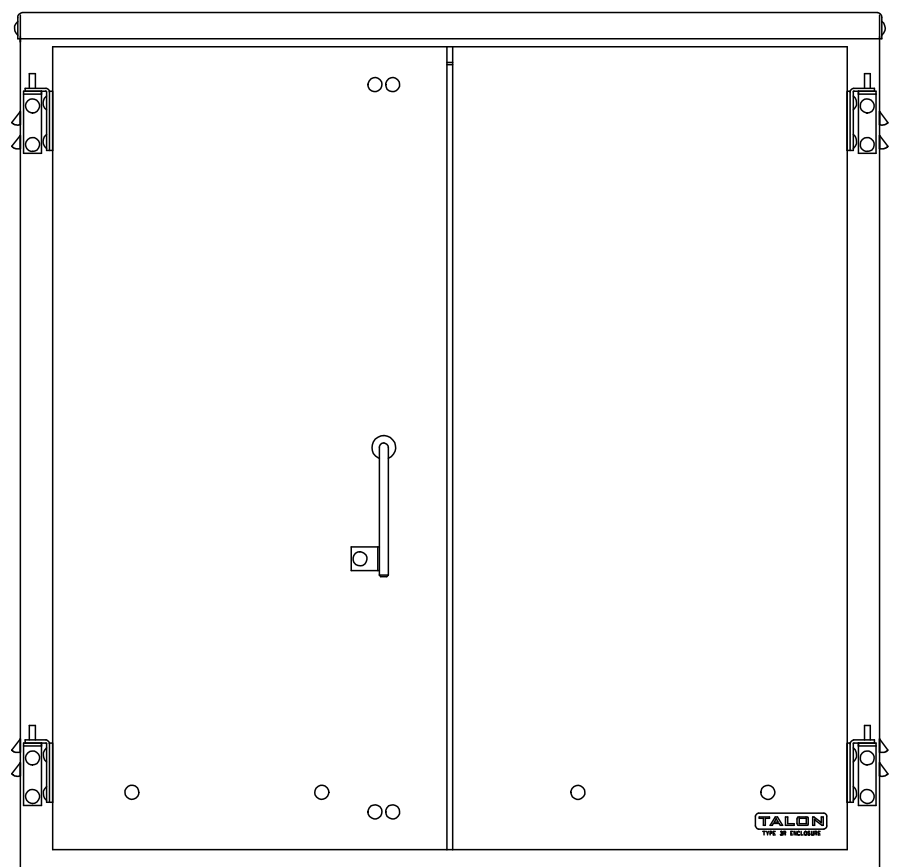


STAINLESS
STEEL
PADLOCKABLE
HANDLE

SEE NOTE #3

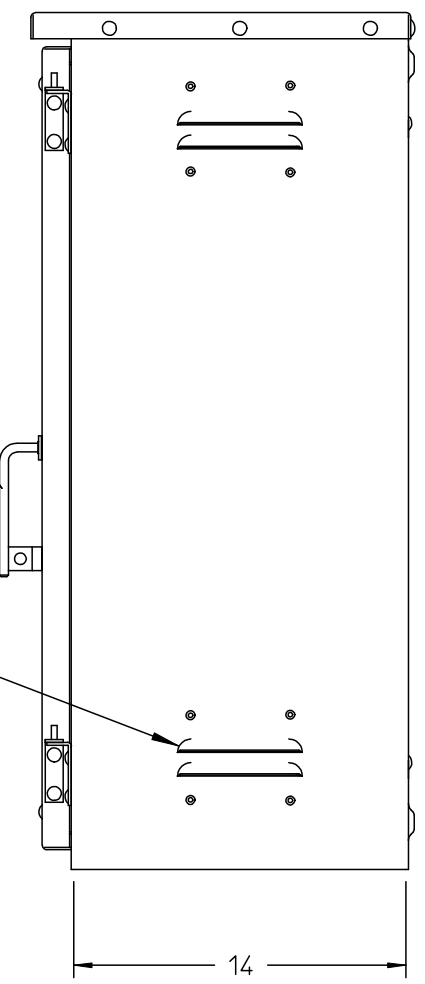

- NOTES:
- 1) ALL HARDWARE AND HINGES ARE STAINLESS STEEL
 - 2) BOTH DOORS ARE EQUIPPED WITH MANUAL DOOR STOPS WHICH HOLD THE DOORS OPEN AT APPROXIMATELY 125° FROM THE CLOSED POSITION.
 - 3) 5-1/4 INCH LOUVERS WITH BAFFLES, (2) SETS ON LEFT AND RIGHT SIDE OF ENCLOSURE.

Ø.136 (2) PLACES

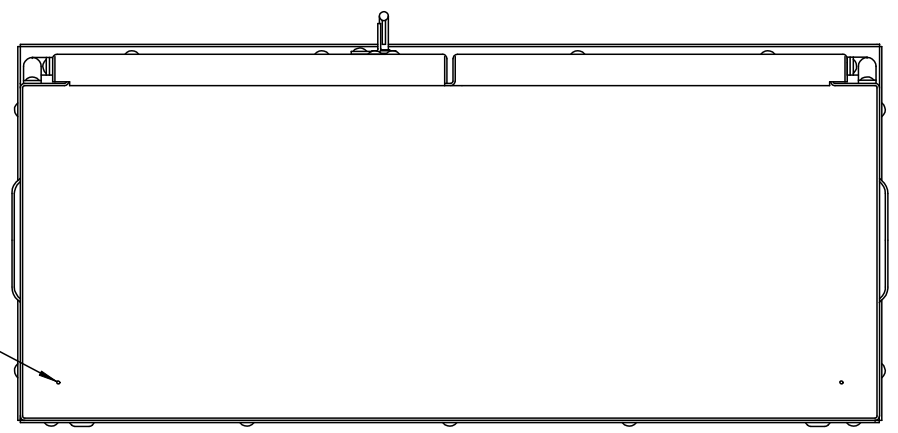

© 2015 Copyright Siemens Industry, Inc.



Outdoor Current Transformer Enclosure

Description: CT ENC 363614 DD PLYWD

3/17/05 SCB DO NOT SCALE DRAWING Dwg No: LG143636CTA1