

Catalog Number: 9837-8503

Features and Ratings

- Ringless Type Meter Socket
- 20A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 3 Phase, 4 Wire
- 13 Jaw Meter Socket
- Meter Socket Type PTS-13
- For Overhead or Underground Service
- RX Type Hub Opening, Cover Plate Installed

Connectors, Wire Sizes and Torques

| CONNECTOR | WIRE SIZE | TORQUE |
|----------------------------|--------------|-------------|
| CURRENT, POTENTIAL, GROUND | #14 - 10 AWG | 35 IN.-LBS. |
| CURRENT, POTENTIAL, GROUND | #8 AWG | 40 IN.-LBS. |
| CURRENT, POTENTIAL, GROUND | #6 AWG | 45 IN.-LBS. |
| POTENTIAL, GROUND | #4 AWG | 45 IN.-LBS. |
| GROUND | #3 - 2 AWG | 50 IN.-LBS. |



Accessories

CONDUIT HUBS (RX Type)

| TRADE SIZE | CATALOG No. |
|------------|-------------|
| 3/4 INCH | H38594-2 |
| 1 INCH | H38596-2 |
| 1-1/4 INCH | H38597-2 |
| 1-1/2 INCH | H38598-2 |
| 2 INCH | H38599-2 |
| 2-1/2 INCH | H38600-2 |

Steel Hub Cover Plate Kit
Cat No: H38595-1

Aluminum Hub Cover Plate Kit
Cat No: H38595-2

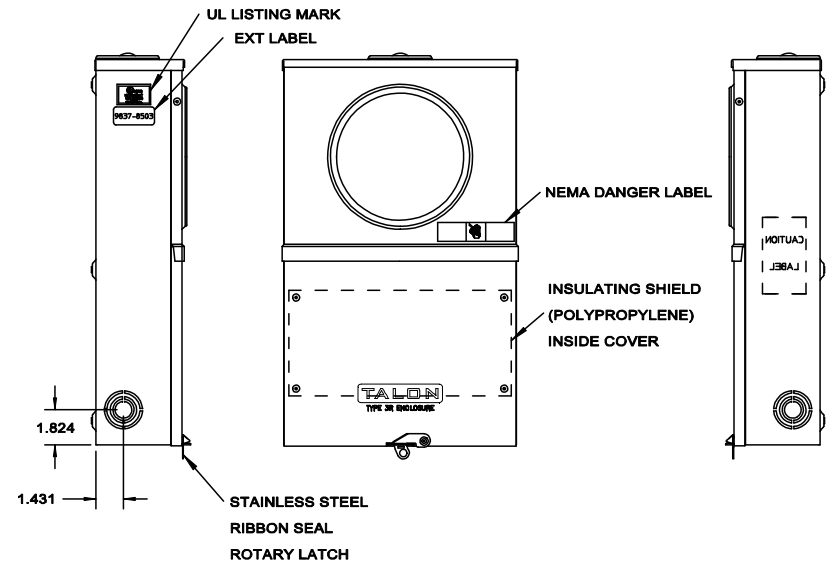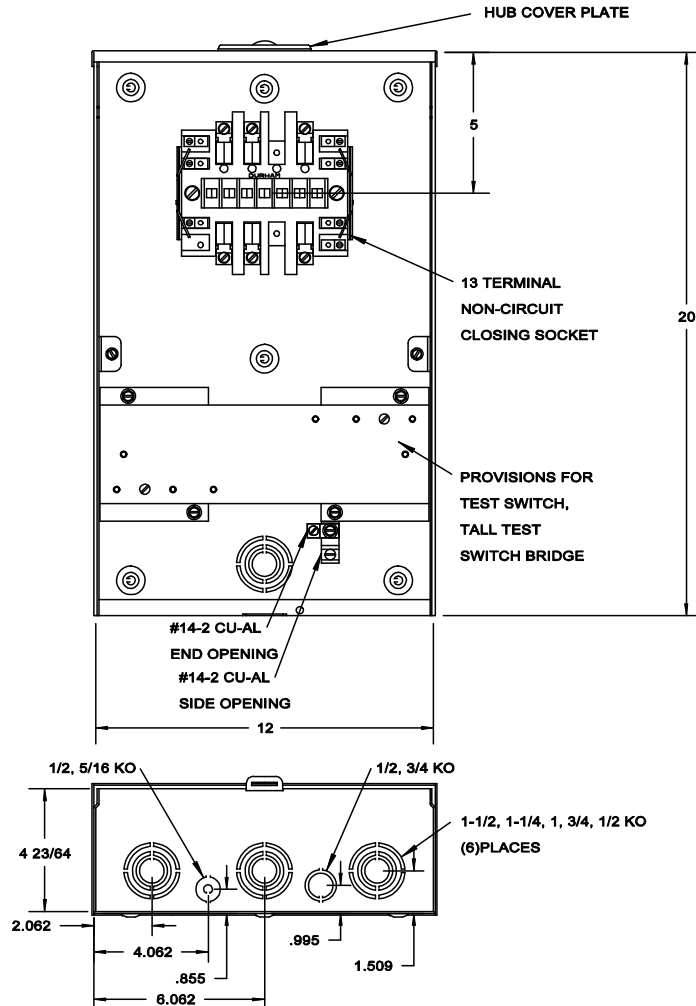

© 2017 Copyright Siemens Industry, Inc.

| | |
|--|----------------------|
| TALON | |
| PTS13 | |
| Description: SKT/SW 20A 13T HCP | |
| CQ 08/25/2018 | DO NOT SCALE DRAWING |
| Dwg No. | 9837-8503 |