


**Catalog Number: 9810-9549**

**Features and Ratings**

- Ringless Type Meter Socket
- 480A Continuous, 600A Max., 300V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 1 Phase, 3-Wire
- Meter Socket Type K-4UT
- For Overhead & Underground Service
- (2) Large HD Type Hub Openings with Cover Plates Installed

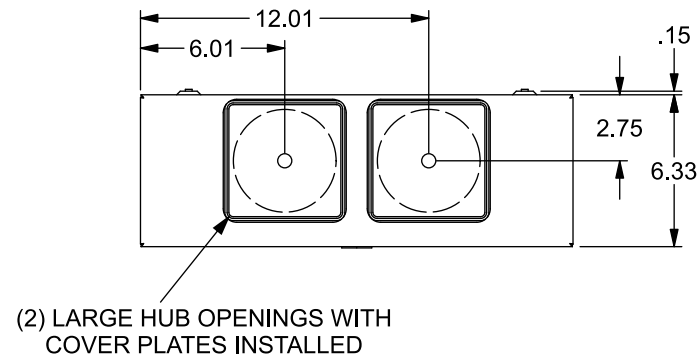



**Accessories**

CONDUIT HUBS (HD Type)	
TRADE SIZE	CATALOG No.
3 INCH	EC56856 or H56856-2
3-1/2 INCH	EC56857 or H56857-2
4 INCH	EC56858 or H56858-2
Hub Cover Plate	EC56933 or H56933S




K4 Lexan Shield Cat No: 5007400-K  
 K4 Manual Bypass Cat No: H56495  
 Blank Sliding Cover Cat. No: HA-300529-3

**Connectors, Wire Sizes and Torques**

CONNECTOR	PART No.	WIRE SIZE	TORQUE
LINE	68752-1	(3) #6-250 kcmil	275 IN-LBS.
LOAD	68752-1	(3) #6-250 kcmil	275 IN-LBS.
NEUTRAL	56426	(4) #6-350 kcmil	275 IN-LBS.
GROUND	56734	(1) #6-250 kcmil	275 IN-LBS.

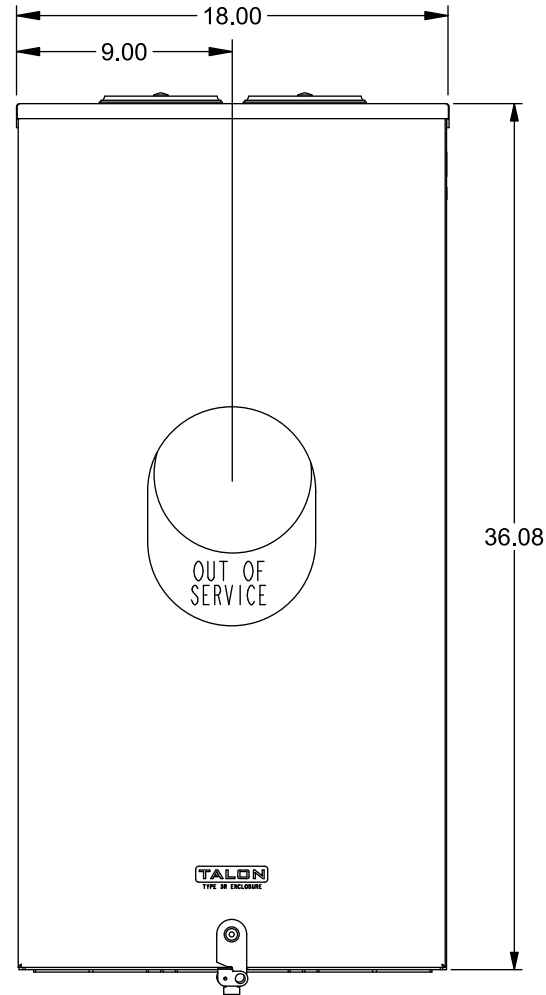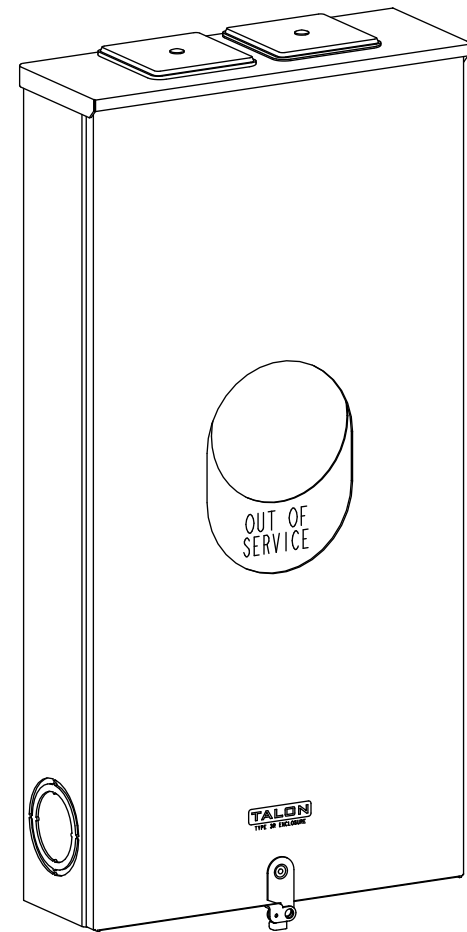

VIEW SHOWN WITH COVER REMOVED

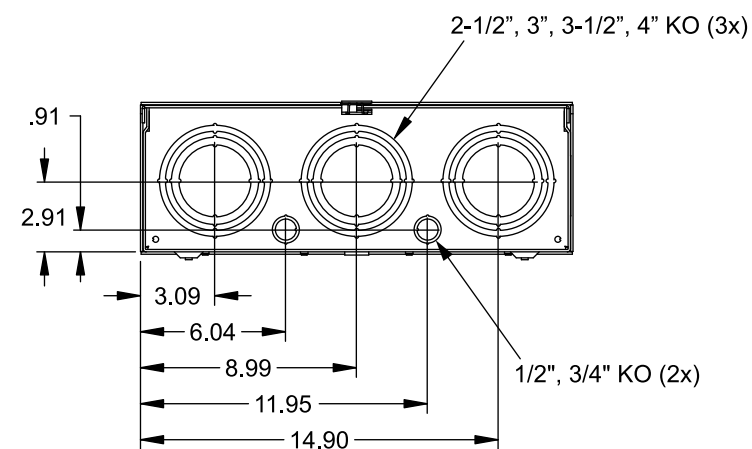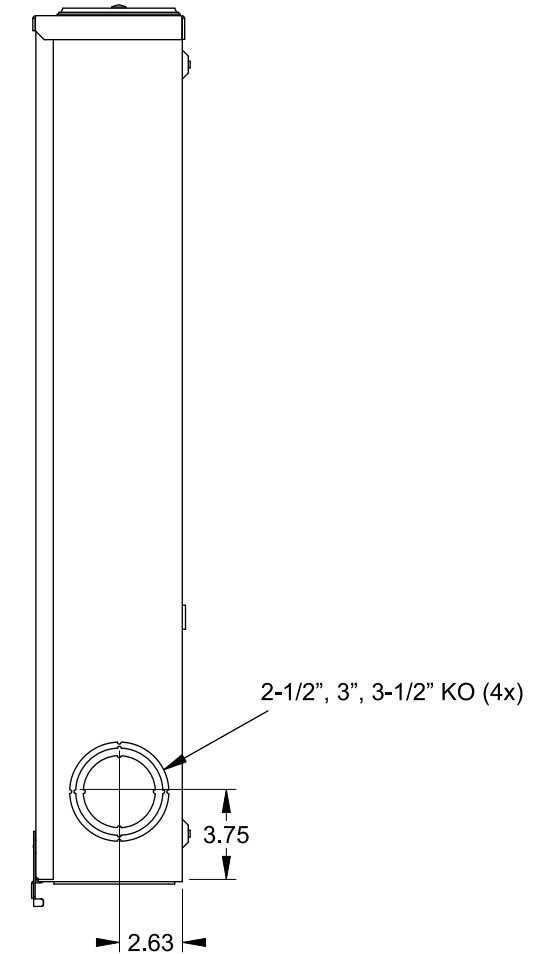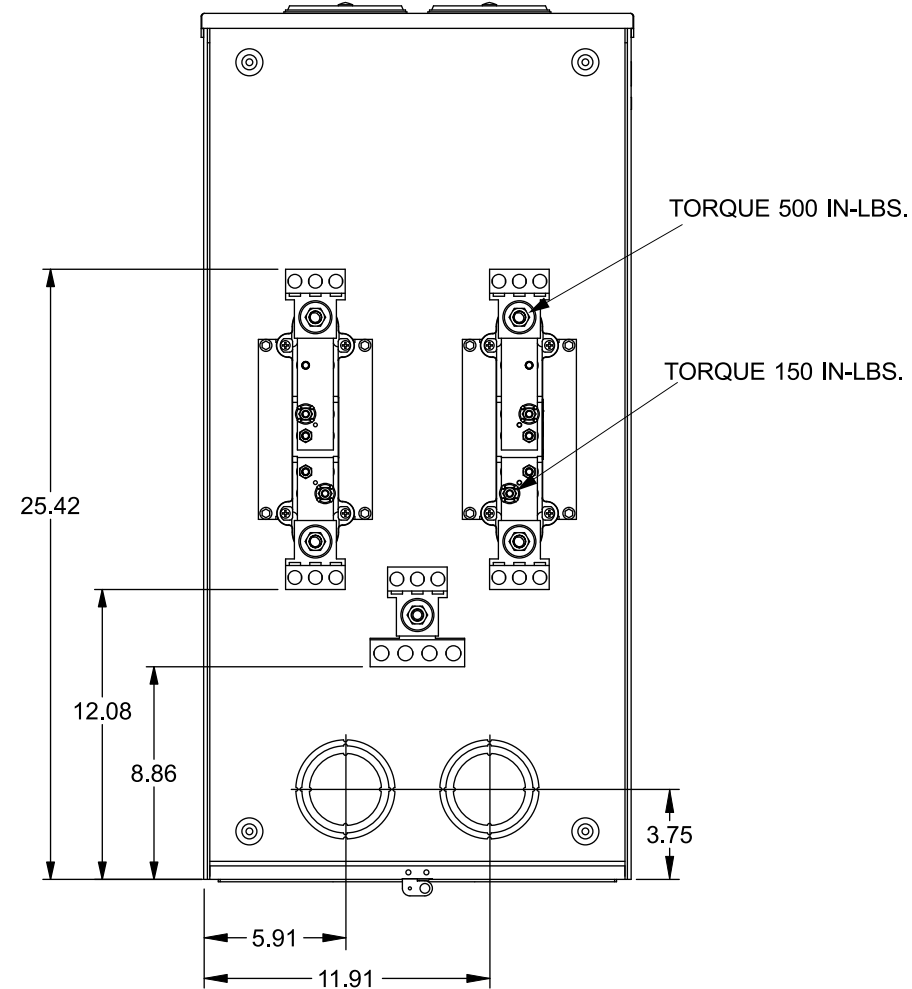

© 2018 Copyright Siemens Industry, Inc.

**TALON**  
**Meter Socket**

Description: **480A Cont, 4 Terminal, K-4UT, 300V AC, Painted Steel Enclosure**

KAM 10/10/18 | DO NOT SCALE DRAWING | Dwg No: **9810-9549**