


Catalog Number: SJ102AX

Features and Ratings

- Ring Type Meter Socket
- 135A Continuous, 135A Max., 600V AC
- Outdoor Enclosure (Type 3R)
- Painted Steel Enclosure
- 1 Phase, 3 Wire
- 4 Jaw Meter Socket
- Meter Socket Type UAT1
- Quad Bonded Neutral
- RX Type (Small) Hub Opening
- For Overhead Service Only

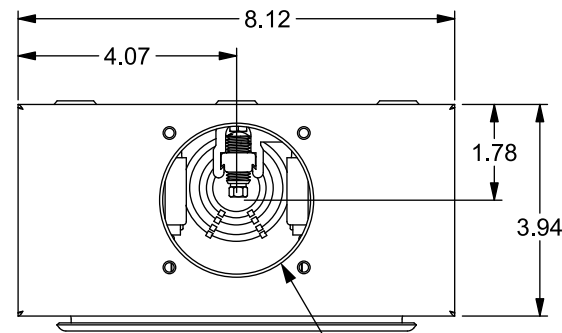

TYPE RX (SMALL) HUB OPENING

Accessories

CONDUIT HUBS (RX Type)	
TRADE SIZE	CATALOG No.
1-1/4 INCH	EC38597
1-1/2 INCH	EC38598
2 INCH	EC38599
2-1/2 INCH	EC38600

Hub Cover Plate	EC38595
-----------------	---------





Meter Opening Cover Plate
Cat No: H659-0162
5th Jaw Kit
Cat. No: EC659-0121

Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
LINE, LOAD, NEUTRAL*	2/0 - 14 AWG	50 IN.-LBS.
GROUND	#2 - 14 AWG	50 IN.-LBS.

* External Hex Drive 5/16"

VIEW SHOWN WITH COVER REMOVED

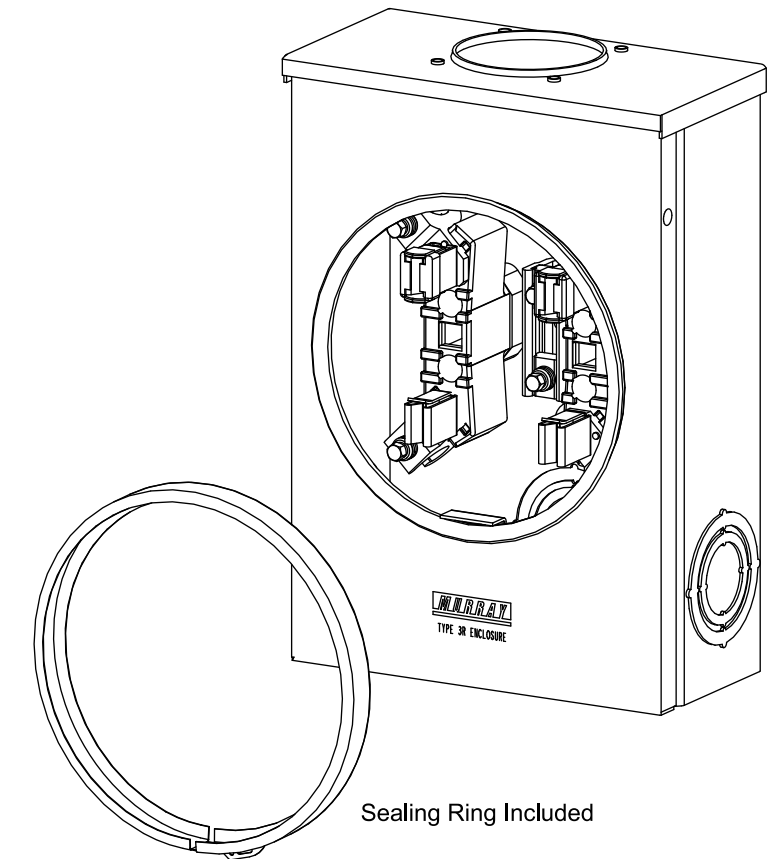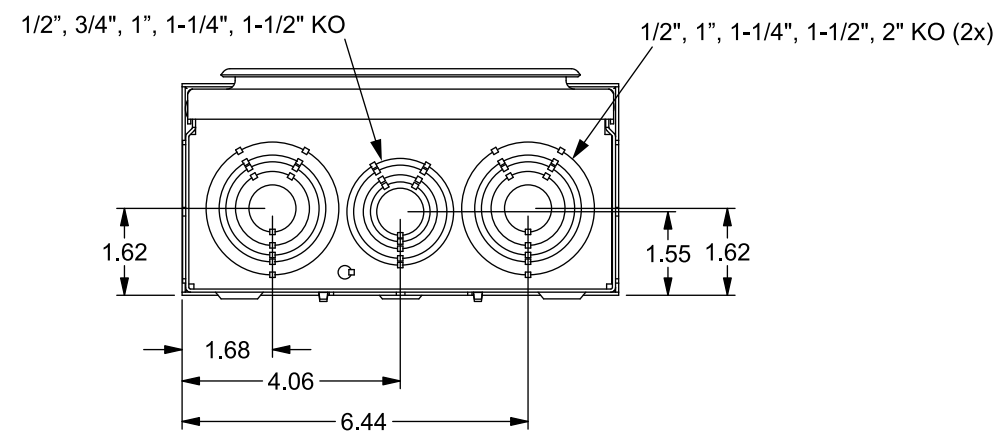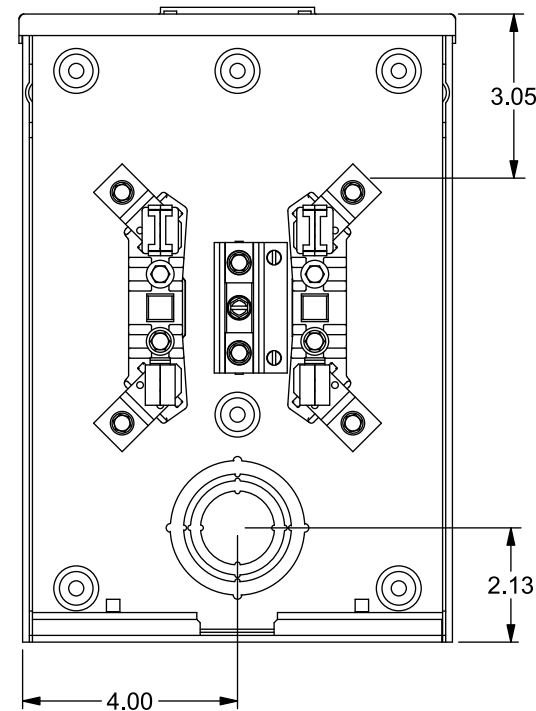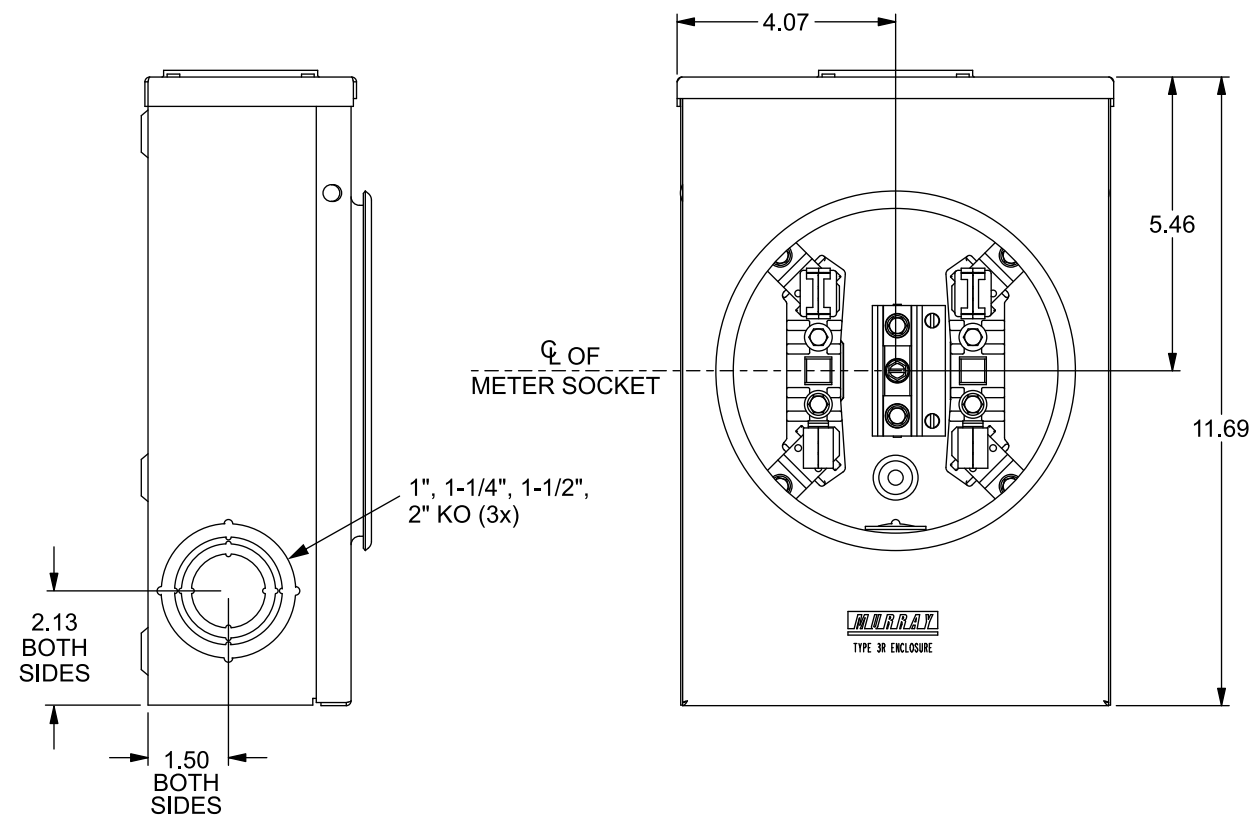

Sealing Ring Included

© 2019 Copyright Siemens Industry, Inc.

MURRAY Murray Electrical Products
Siemens Industry, Inc.

Meter Socket

Description: 135A Cont, 4 Jaw, UAT1,
600V AC, Painted Steel Enclosure

KAM 4/23/19 DO NOT SCALE DRAWING Dwg. No. **SJ102AX**