

Catalog Number: UA2313-0G

Features and Ratings

- Ringless Type Meter Socket
- 150A Continuous, 150A Max, 2 Position, 200Amp Overall
- Outdoor Enclosure (Type 3R)
- Painted G90 Steel
- 1 Phase, 3 Wire, 600V AC
- 4 Jaw
- For Overhead or Underground Service
- RX Hub Opening

Accessories

Meter Opening Cover Plate
Cat No: H659-0162

5th Jaw Kit
Cat. No: 659-0121


CONDUIT HUBS (RX Type)	
TRADE SIZE	CATALOG No.
1-1/4 INCH	EC38597 or H38597-2
1-1/2 INCH	EC38598 or H38598-2
2 INCH	EC38599 or H38599-2
2-1/2 INCH	EC38600 or H38600-2
Hub Cover Plate	EC38595 or H38595-1

Connectors, Wire Sizes and Torques



CONNECTOR	WIRE SIZE	TORQUE
LINE, NEUTRAL*	#6 - 350 kcmil	250 IN.-LBS.
LOAD, NEUTRAL	#6 - 350 kcmil	250 IN.-LBS.
GROUND	#14 - 2 AWG	50 IN.-LBS.

* External Hex Drive 1/2"
* Internal Hex Drive 5/16"


WIRE BENDING SPACE PROVIDED FOR 350 kcmil WIRE

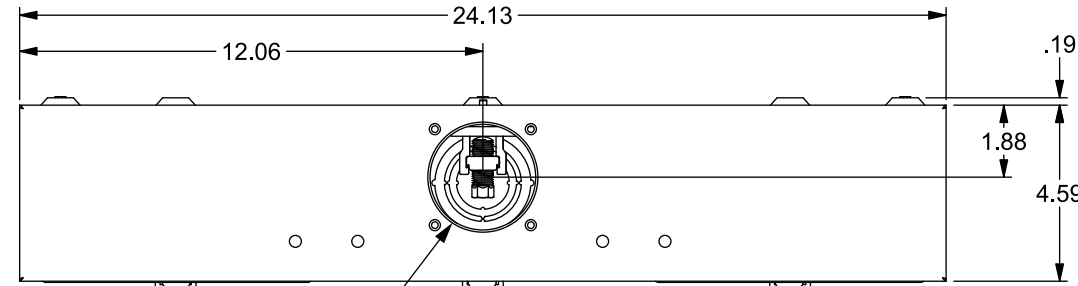

RX Type (Small) Hub Opening

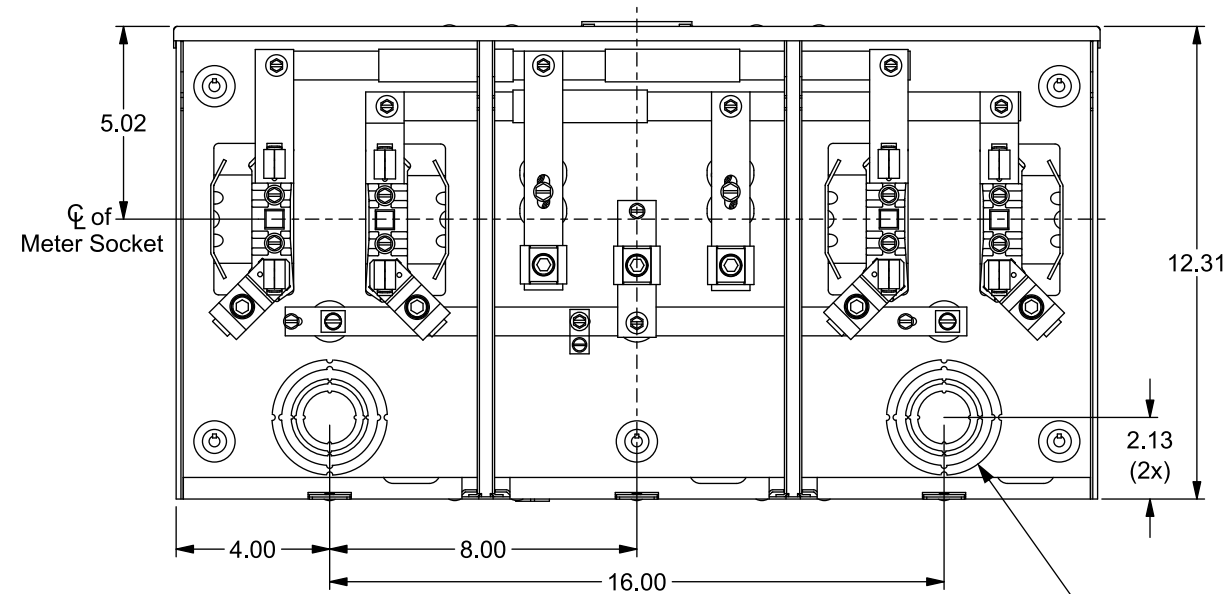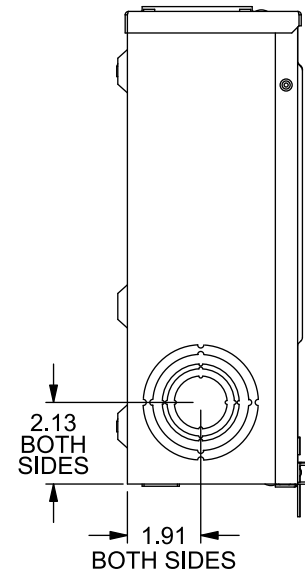


1", 1-1/4", 1-1/2", 2", 2-1/2", KO (4x)

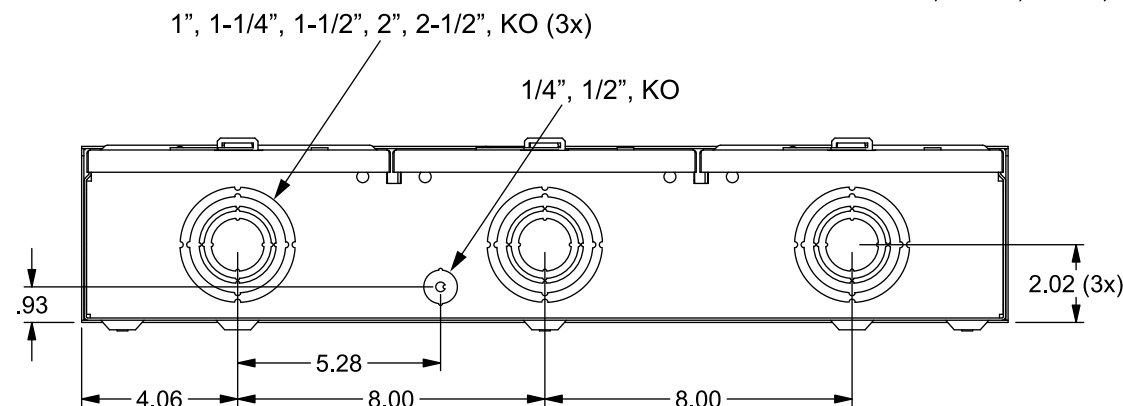

1", 1-1/4", 1-1/2", 2", 2-1/2", KO (3x)

1/4", 1/2", KO

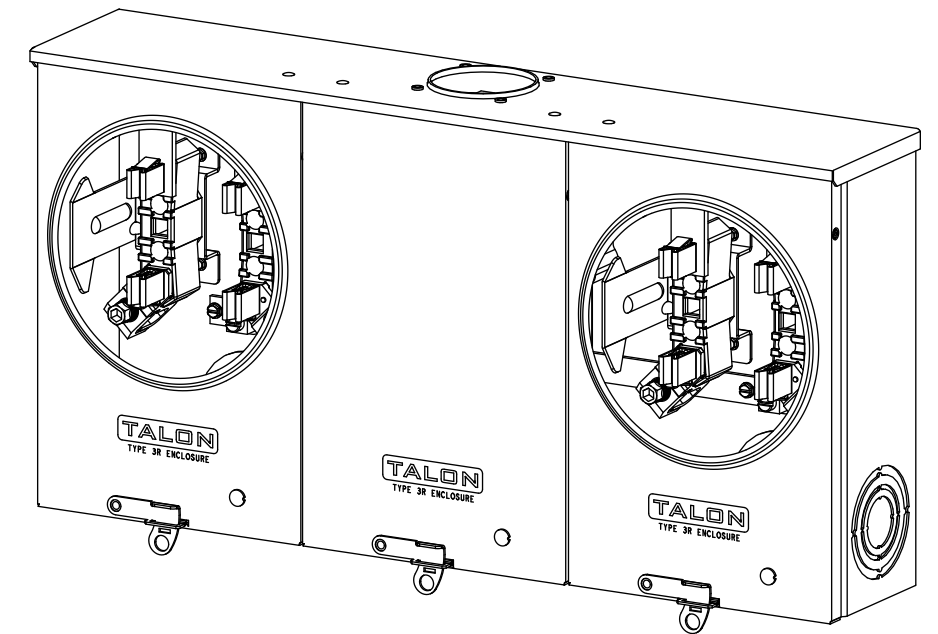

© 2019 Copyright Siemens Industry, Inc.

TALON

Multi-Position Metering

Description:
**150A Cont, 4 Jaw, A12, 600V AC,
2 Position, Painted G90 Steel**

KAM 5/28/19 DO NOT SCALE DRAWING Dwg No: **UA2313-0G**