

Terminal Blocks

8WA2 Terminals with Cage Clamps

Through-type terminals


Selection and ordering data

With insulating body of molded thermoplastic · Front connection with Cage Clamps

| Dimensions ²⁾ | IEC ratings uninterrupted current | IEC ratings insulation voltage | UL ratings current / voltage | Description | Color | Fig. No. | Height H | Depth D | Order No. | Price |
|--------------------------|---|--------------------------------------|------------------------------------|-------------|-------|----------|------------------|------------------|-----------|-------|
| | | | | | | | mm ²⁾ | mm ²⁾ | | |

Through-type terminals with 3 clamping points

Terminal size 2.5 mm² · Overall width 5.2 mm AWG 28-14 AWG 26-14

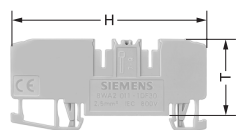


| | | | | | | |
|---------------|---------------|--|--------------------|------|------|--|
| 24 A 800 V | 15 A 600 V | Through-type terminal | light gray blue | 73.5 | 28.6 | 8WA2 011-1DF30 8WA2 011-1BF33 |
| | | Barrier | yellow ② | | | 8WA2 813 |
| | | Small partition | yellow ⑩ | | | 8WA2 836 |
| | | Retaining partition for link rail | light gray ⑫ | | | 8WA2 835 |

Terminal size 4 mm² · Overall width 6.2 mm AWG 28-12 AWG 26-12

| | | | | | | |
|---------------|---------------|--|--------------------|------|------|--|
| 32 A 800 V | 20 A 600 V | Through-type terminal | light gray blue | 79.5 | 28.6 | 8WA2 011-1DG30 8WA2 011-1BG33 |
| | | Barrier | yellow ② | | | 8WA2 813 |
| | | Small partition | yellow ⑩ | | | 8WA2 836 |
| | | Retaining partition for link rail | light gray ⑫ | | | 8WA2 835 |

Through-type terminals, 1-pole, with 4 clamping points

 Terminal size 2.5 mm² · Overall width 5.2 mm AWG 28-14 AWG 26-14




| | | | | | | |
|---------------|---------------|--|--------------------|--|--|--|
| 24 A 800 V | 10 A 300 V | Through-type terminal | light gray blue | | | 8WA2 011-1DF40 8WA2 011-1BF43 |
| | | Barrier | yellow ② | | | 8WA2 813 |
| | | Small partition | yellow ⑩ | | | 8WA2 836 |
| | | Retaining partition for link rail | light gray ⑫ | | | 8WA2 835 |


Two-tier terminals

Two-tier terminals, 1-/2-pole, with 4 clamping points

Terminal size 4 mm² · Overall width 6.2 mm AWG 28-12 AWG 26-12

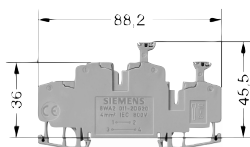

Design:

 

| | | | | | | |
|---------------|---------------|---|----------------------------------|--|--|--|
| 32 A 690 V | 20 A 600 V | 2-pole with 2 × 2 clamping points | light gray ¹⁾ blue | | | 8WA2 011-2DG20 8WA2 011-2BG23 |
| 32 A 800 V | 20 A 600 V | 1-pole with 1 × 4 clamping points | light gray blue | | | 8WA2 011-2DG40 8WA2 011-2BG43 |
| | | Barrier | yellow ③ | | | 8WA2 812 |
| | | Small partition | yellow ⑩ | | | 8WA2 836 |
| | | Retaining partition for link | light gray ⑫ | | | 8WA2 835 |
| | | Label holder (included in scope of supply of two-tier terminal, can also be used for through-type terminal) | light gray ⑦ | | | 8WA2 850 |

Linking accessories see page 15/13, other accessories see page 15/14, labelling accessories see page 15/40 - 43.

1) Included in the scope of delivery are 2 label holders, 2 additional holders can be added.
2) 25.4 mm = 1 inch