

 




 

# Terminal Blocks

## 8WA2 Terminals with Cage Clamps






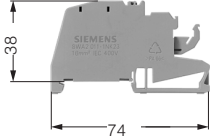

### N isolating terminals

#### Selection and ordering data

With insulating body of moulded thermoplastic · Front connection with Cage Clamps · 1-pole with one clamping point

Dimensions <sup>1)</sup>	IEC ratings uninterrupted current  IEC ratings insulation voltage	UL ratings current / voltage	Description	Color	Height H	Depth D	Order No.	Price
					mm <sup>1)</sup>	mm <sup>1)</sup>		
			<b>Terminal size 4 mm<sup>2</sup> · Overall width 6.2 mm</b>  AWG 28-12  AWG 26-12					
	32 A isolating gap 400 V	20 A 600 V	<b>N isolating terminal</b>	blue	68.5	31.0	<b>8WA2 011-1NG23</b>	
			<b>Terminal size 6 mm<sup>2</sup> · Overall width 8.2 mm</b>  AWG 24-10  AWG 24-10					
	41 A isolating gap 400 V	30 A 300 V	<b>N isolating terminal</b>	blue	71.0	31.0	<b>8WA2 011-1NH23</b>	
	41 A isolating gap 400 V	30 A 300 V	<b>N isolating terminal</b> high Insta terminal level, for mixing standard and Insta terminals on the standard mounting rail	blue	70.0	37.0	<b>8WA2 011-3JH10</b>	
			<b>Terminal size 16 mm<sup>2</sup> · Overall width 12 mm</b>  AWG 24-6					
	76 A isolating gap 400 V	65 A 600 V	<b>N isolating terminal</b>	blue	89.4	38	<b>8WA2 011-1NK20</b>	

#### Accessories

8WA2 843	8WA2 848		<b>N busbar support</b>	blue			<b>8WA2 843</b>	
			<b>Lockout</b>	yellow			<b>8WA2 848</b>	
8WA2 837		135 A	<b>N busbar end</b> for insertion into 8WA2 808 end retainer	blue			<b>8WA2 837</b>	
			<b>N busbar</b> 10 x 3 mm; tin-coated, 1000 mm long				<b>8WA2 842</b>	
8WA2 842		68 A 800 V	<b>Cover</b> for N busbar, 500 mm long	transparent			<b>8WA2 805</b>	
		63 A 600 V	<b>Supply terminal</b> <b>16 mm<sup>2</sup> / 16 AWG</b> with screw connection (the 8WA2 843 N busbar support is included in the scope of supply)	blue	Overall width 10 mm		<b>8WA2 011-1NK23</b>	
8WA2 805			<b>Supply terminal</b> <b>for 10 x 3 mm – and 6 x 6 mm – N busbars</b> up to 4 mm <sup>2</sup> / 12 AWG up to 25 mm <sup>2</sup> / 14 AWG up to 35 mm <sup>2</sup> / 12 AWG	bare			<b>8WA2 867</b> <b>8WA2 868</b> <b>8WA2 870</b>	
								
8WA2 011-1NK23								
								
8WA2 867/868/870								
								

Linking accessories see page 15/13, other accessories see page 15/14, labelling accessories see page 15/40 - 43.

1) 25.4 mm = 1 inch