

Terminal Blocks

8WA1 Terminals with Screw Connection

Two-tier terminals


Selection and ordering data

With insulating body of molded thermoplastic · With screw connections on both sides

Dimensions ³⁾	IEC ratings uninterrupted current IEC ratings insulation voltage	UL ratings current / voltage	Description	Color	Order No.	Price
--------------------------	---	------------------------------------	-------------	-------	-----------	-------

Two-tier terminal, 2-pole with 2 electrically separated connections

Terminal size 4 · Assembly width 6.5 mm  AWG 18-10  AWG 18-10

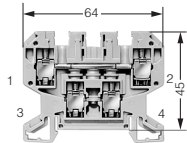


32 A 690 V	30 A 600 VB	Two-tier terminal	beige blue
with end plates 800 V			

8WA1 011-2DG11
8WA1 011-2BG11

Two-tier terminal, 1-pole

Terminal size 4 · Assembly width 6.5 mm  AWG 18-10  AWG 18-10

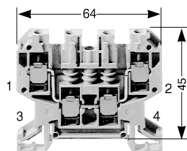

32 A 690 V	30 A 600 V	Two-tier terminal	beige blue
with end plates 800 V			

8WA1 011-6DG11
8WA1 011-6BG11

Accessories

Rated voltage		Rated uninterrupted current	Description	Design	Fig. No.	Order No.	Price
Between link rails		-	End plate	width 1.5 mm	①	8WA1 817	
with small partition	400 V 450 V	-	Barrier	width 1.5 mm	②	8WA1 823	
with end plate or barrier	800 V 900 V	-	Cover	with warning arrow white, for inscription transparent	⑩	8WA1 811 8WA1 862 8WA1 822-7AX01	
For top tier with 2-pole terminals							
with open disconnecting link	500 V 600 V	32 A	Link rail for	2 terminals 3 terminals 4 terminals 10 terminals	④	8WA1 850 8WA1 851 8WA1 852 8WA1 853	
with solder tags bent up and down in alternating arrangement	400 V 450 V	-	Small partition		③	8WA1 825	
with terminals side by side with solder tag and insulated plugs	250 V 300 V	32 A	Bridge for link rails		⑤	8WA1 822-7VG00	
		32 A	Disconnecting link ¹⁾		⑥	8WA1 865	
		10 A	Test socket 2.3 mm dia.		⑦	8WA1 854	
		18 A	Solder tag		⑧	8WA7 41	
		18 A	Tab connector 6.3-0.8 split ²⁾		⑨	8WA1 890	
For bottom tier with 1- and 2-pole terminals							
		32 A	Link rail for	2 terminals 10 terminals	④	8WA1 835 8WA1 838	
		-	Small partition		③	8WA1 825	
		32 A	Bridge for link rails		⑤	8WA1 822-7VG01	
		10 A	Test socket 2.3 mm dia. and matching spacing sleeve		⑦	8WA1 884 8WA1 822-7VH11	

Labelling accessories see page 15/40 - 43.

1) The terminals must be fitted with end plates and joined together.

2) For voltages up to 250 V. On size 4 terminals, one or two tab connectors can be fitted.