

MOTOR OPERATOR 24-60 V DC ACCESSORY FOR: 3VA6
150/250 3VA5 250








| Model | |
|--|------------------------------------|
| Product brand name | SETRON |
| Product designation | Accessories |
| Design of the product | Motorized operating mechanism (MO) |
| accessories | Motorized operating mechanism (MO) |
| Mechanical Design | |
| Rated control supply voltage U_s with DC | 24 V |
| Height | 75 mm |
| Width | 104.6 mm |
| Depth | 132 mm |
| Net weight | 941 g |
| Connectable conductor cross-section / solid / minimum | 1.5 mm ² |
| Connectable conductor cross-section / solid / maximum | 2.5 mm ² |
| Connectable conductor cross-section / finely stranded / with core end processing / minimum | 1.5 mm ² |
| Connectable conductor cross-section / finely stranded / with core end processing / maximum | 2.5 mm ² |

Connections according IEC

Wire stripping length

7 mm

Certificates

| General Product Approval | EMC | Declaration of Conformity | other | | |
|--|---|--|--|---|-------------------------------|
|  CSA |  UL |  EAC |  RCM |  EG-Konf. | Miscellaneous |

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9277-0HA10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9277-0HA10>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9277-0HA10

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

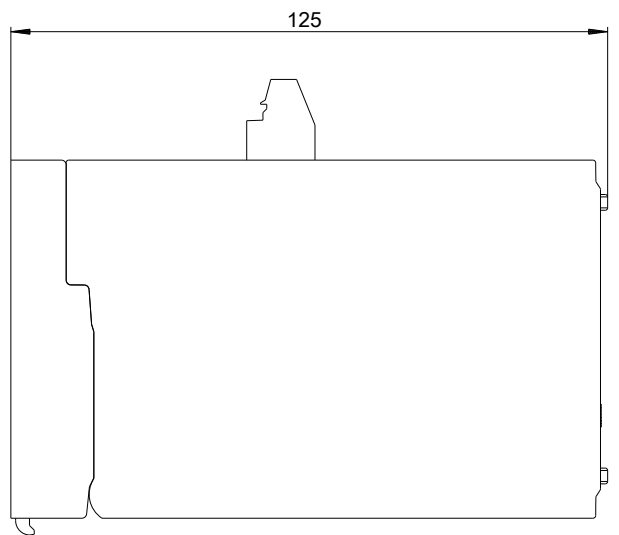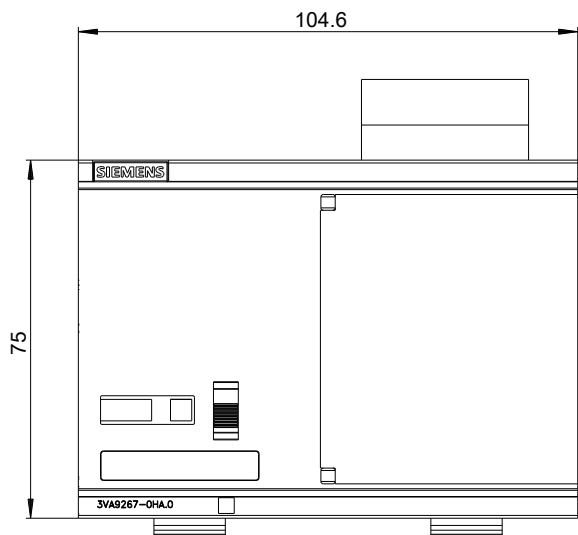

last modified:

11/17/2017