


Catalog Number: 40405P-93MR

## Features and Ratings

- Ringless Lever Bypass Type Meter Socket
- 200A Continuous, 200A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 1 Phase, 3 Wire
- 5 Jaw Meter Socket
- For Underground Service

## Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
LINE	#4-300kcmil	275 IN.-LBS.
LOAD	#6-350kcmil	275 IN.-LBS.
G1	#14-1/0 AWG	50 IN.-LBS.

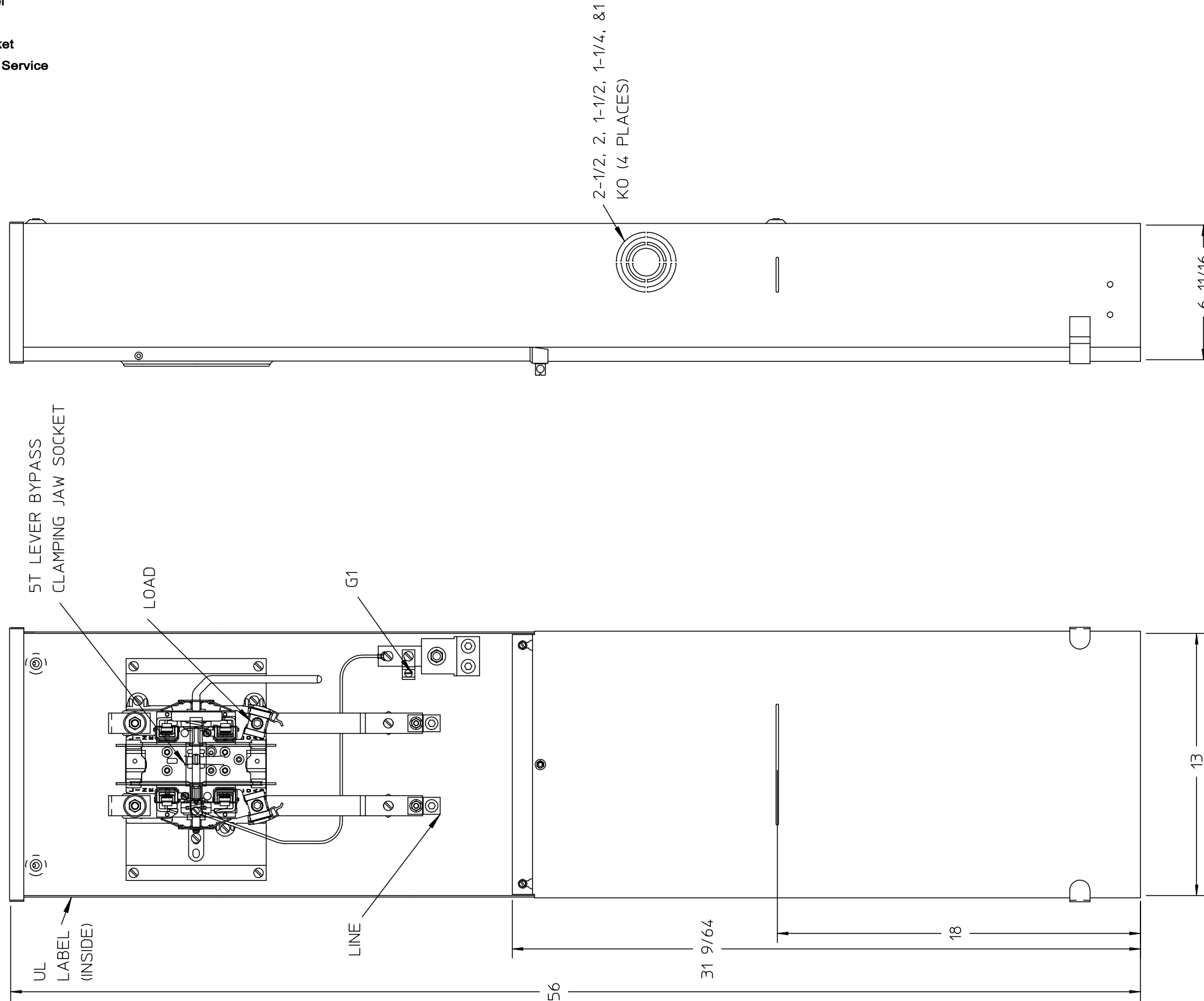

© 2015 Copyright Siemens Industry, Inc.

**TALON**  
**METER PEDESTAL**

Description:

200A SKT/PED LBP 5T

11/18/14 KP DO NOT SCALE DRAWING Dwg No: 40405P-93MR